

Product data sheet

Specifications

SQUARE D

 Green Premium™



Safety switch, general duty, fusible, 30A, 2 pole, 3hp, 120VAC, NEMA 1, neutral factory installed

D211N

Product availability : Stock - Normally stocked in distribution facility

Price* : 90.00 USD

Main

Product	Single Throw Safety Switch
Duty Rating	General duty
Device Application	Residential
Disconnect Type	Fusible disconnect switch
Factory Installed Neutral	Neutral/earth strip 2 x 16 mm ² 5 x 6 mm ²
Phase	3 phase
Number of Poles	2
Current Rating	30 A
Voltage Rating	120 V AC
Enclosure Rating NEMA	NEMA 1
Motor power hp	0.5 hp at 120 V AC 60 Hz for 1 phase motors 2 hp at 120 V AC 60 Hz for 1 phase motors 1.5 hp at 240 V AC 60 Hz for 1 phase motors 3 hp at 240 V AC 60 Hz for 1 phase motors

Complementary

Short Circuit Current Rating	10 kA plug
Fuse type	Plug
Mounting Type	Surface
Electrical Connection	Lugs
Wiring configuration	3-wire
Wire Size	AWG 14...AWG 6 copper AWG 12...AWG 6 aluminium
Tightening torque	30 lbf.in (3.39 N.m) 0.00...0.02 in ² (2.08...13.3 mm ²) (AWG 14...AWG 6)
Depth	3.63 in (92.20 mm)
Width	7.25 in (184.15 mm)
Height	9.25 in (234.95 mm)
Net Weight	16.01 lb(US) (7.26 kg)

Environment

Certifications	UL listed file E2875
-----------------------	----------------------

* Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Ordering and shipping details

Category	00006-D & DU SW, NEMA1, 30-200A
Discount Schedule	DE1A
GTIN	785901460329
Returnability	Yes
Country of origin	MX

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	5.50 in (13.97 cm)
Package 1 Width	7.00 in (17.78 cm)
Package 1 Length	9.50 in (24.13 cm)
Package 1 Weight	4.17 lb(US) (1.892 kg)
Unit Type of Package 2	CAR
Number of Units in Package 2	5
Package 2 Height	9.80 in (24.892 cm)
Package 2 Width	8.40 in (21.336 cm)
Package 2 Length	19.00 in (48.26 cm)
Package 2 Weight	22.25 lb(US) (10.092 kg)
Unit Type of Package 3	PAL
Number of Units in Package 3	150
Package 3 Height	40.00 in (101.6 cm)
Package 3 Width	40.00 in (101.6 cm)
Package 3 Length	48.00 in (121.92 cm)
Package 3 Weight	668.00 lb(US) (302.999 kg)


Offer Sustainability

Sustainable offer status	Green Premium product
California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov
REACH Regulation	REACH Declaration
EU RoHS Directive	Compliant EU RoHS Declaration
Mercury free	Yes
China RoHS Regulation	China RoHS declaration Product out of China RoHS scope. Substance declaration for your information.
RoHS exemption information	Yes
Environmental Disclosure	Product Environmental Profile
PVC free	Yes

Contractual warranty

Warranty	18 months
----------	-----------


Dimensions

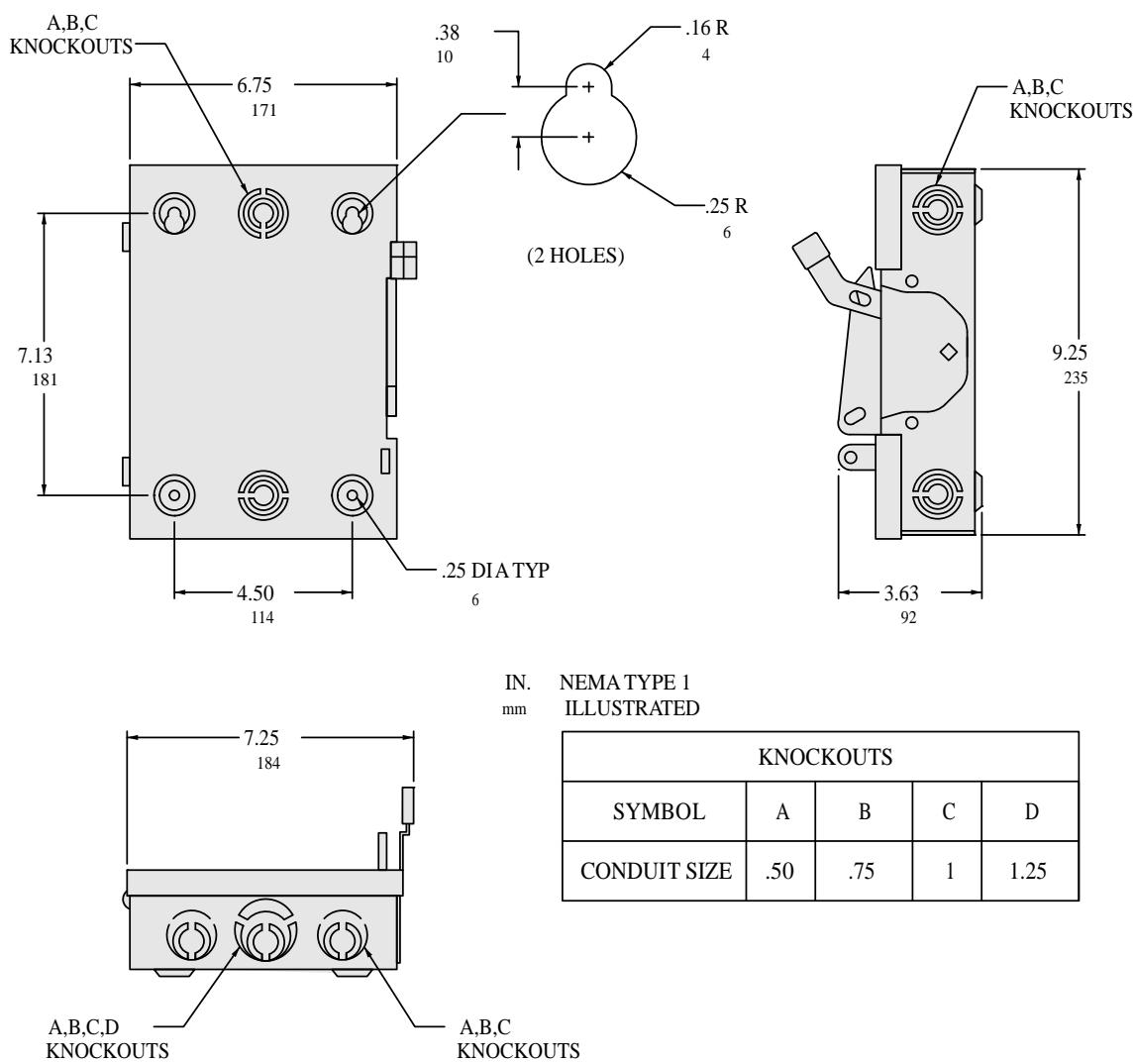

ALL DIMENSIONS ARE APPROXIMATE. REFER TO TECHNICAL DRAWINGS AND DOCUMENTS

Wiring Diagram

FUSIBLE

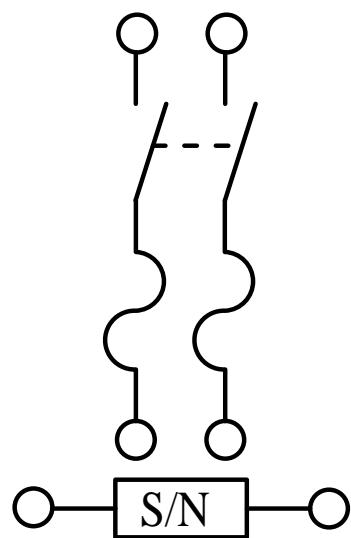

D211N

D221N

Recommended replacement(s)