

Product data sheet

Specifications

SQUARE D



Mini circuit breaker, E-Frame, 30A, 3 pole, 480Y/277 VAC, 25 kA max, bolt on

EDB34030

Product availability : Stock - Normally stocked in distribution facility

Main

Range of Product	125 A Frame EDB-EGB-EJB
Product or Component Type	Miniature circuit-breaker
Device short name	EDB
Module type	E-Frame
Trip unit rating	875 A

Complementary

Line Rated Current	30 A
Maximum operating voltage	480Y/277 V AC
AWG gauge	AWG 12...AWG 6 aluminium AWG 14...AWG 6 copper
Breaking capacity	18 kA 277 V AC 25 kA 240 V AC 18 kA 480Y/277 V AC 25 kA 120 V AC 25 kA 120/240 V AC
Circuit breaker application	HACR rated HID rated
Electrical connection	Lugs aluminium
Holding Current	270 A
Local signalling	Trip indicator
Mounting Mode	Bolt-on
Number of poles	3
Number of spaces	3
Number of spaces required	3
Product destination	NF panelboard
Protection Type	Overload Short-circuit
Trip unit technology	Thermal-magnetic
Breaking capacity code	D
Tightening torque	30.09 lbf.in (3.4 N.m) 0.00...0.02 in ² (2.5...16 mm ²) (AWG 14...AWG 6)
Height	5.66 in (143.76 mm)
Width	2.94 in (74.68 mm)

Depth	4.05 in (102.87 mm)
Net Weight	4 lb(US) (1.81 kg)

Environment

Product Certifications	cULus
Ambient air temperature for operation	104 °F (40 °C)

Ordering and shipping details

Category	00931-EDB CIRCUIT BREAKERS
Discount Schedule	DE2
GTIN	785901875260
Returnability	Yes
Country of origin	MX

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	4.50 in (11.43 cm)
Package 1 Width	6.10 in (15.494 cm)
Package 1 Length	9.70 in (24.638 cm)
Package 1 Weight	3.75 lb(US) (1.701 kg)


Offer Sustainability

REACH Regulation	REACH Declaration
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Mercury free	Yes
China RoHS Regulation	China RoHS declaration Product out of China RoHS scope. Substance declaration for your information.
RoHS exemption information	Yes

Contractual warranty

Warranty	18 months
----------	-----------

Dimensions

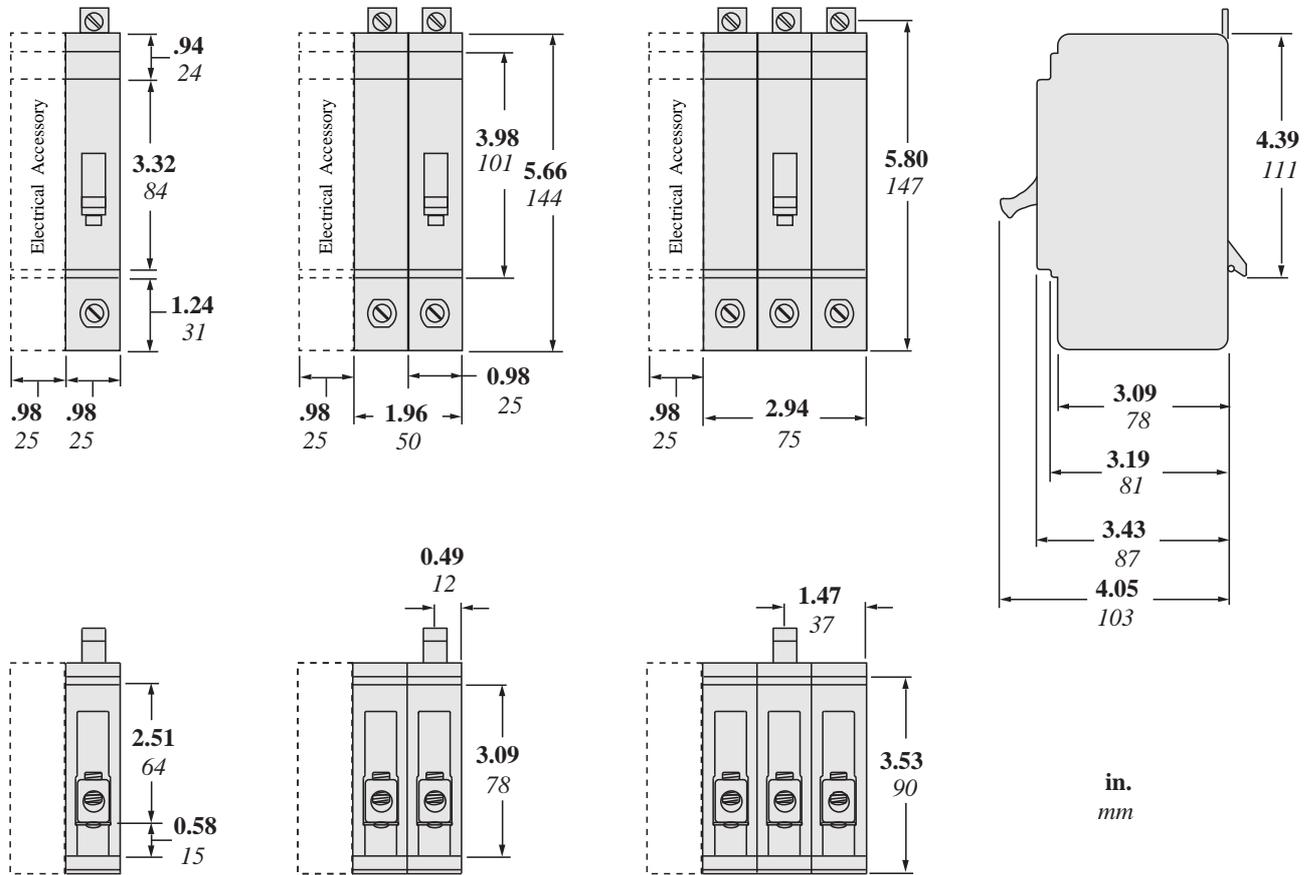

All dimensions are approximate.
 Also see technical drawings and/or documentation.

Recommended replacement(s)