

# Product data sheet

Specifications

SQUARE D



Mini circuit breaker, E-Frame, 40A, 3 pole, 480Y/277VAC, 25kA max, bolt on, shunt trip

EDB34040SA

Product availability : Stock - Normally stocked in distribution facility

**Price\* : 1,424.00 USD**

## Main

Range of Product	125 A Frame EDB-EGB-EJB
Product or Component Type	Miniature circuit-breaker
Device short name	EDB
Module type	E-Frame
Trip unit rating	1800 A

## Complementary

Line Rated Current	40 A
Maximum operating voltage	480Y/277 V AC
AWG gauge	AWG 12...AWG 2/0 aluminium AWG 14...AWG 2/0 copper
Breaking capacity	18 kA 277 V AC 25 kA 240 V AC 18 kA 480Y/277 V AC 25 kA 120 V AC 25 kA 120/240 V AC
Circuit breaker application	HID rated HACR rated
Electrical connection	Lugs aluminium
Holding Current	630 A
Local signalling	Trip indicator
Mounting Mode	Bolt-on
Number of poles	3
Number of spaces	4
Number of spaces required	4
Product destination	NF panelboard
Protection Type	Overload Short-circuit
Device Composition	Shunt trip
Trip unit technology	Thermal-magnetic
Breaking capacity code	D
Tightening torque	34.52 lbf.in (3.9 N.m) 0.00...0.01 in <sup>2</sup> (2.5...6 mm <sup>2</sup> ) (AWG 14...AWG 10) 49.56 lbf.in (5.6 N.m) 0.02...0.11 in <sup>2</sup> (10...70 mm <sup>2</sup> ) (AWG 8...AWG 2/0)

\* Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Height	5.66 in (143.76 mm)
Width	3.92 in (99.57 mm)
Depth	4.05 in (102.87 mm)
Net Weight	4 lb(US) (1.81 kg)

## Environment

Product Certifications	cULus
Ambient Air Temperature for Operation	104 °F (40 °C)

## Ordering and shipping details

Category	00931-EDB CIRCUIT BREAKERS
Discount Schedule	DE2
GTIN	785901103318
Returnability	No
Country of origin	MX

## Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	5.70 in (14.478 cm)
Package 1 Width	6.40 in (16.256 cm)
Package 1 Length	10.00 in (25.4 cm)
Package 1 Weight	4.21 lb(US) (1.91 kg)


## Offer Sustainability

REACH Regulation	<a href="#">REACH Declaration</a>
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) <a href="#">EU RoHS Declaration</a>
Mercury free	Yes
China RoHS Regulation	<a href="#">China RoHS declaration</a> Product out of China RoHS scope. Substance declaration for your information.
RoHS exemption information	Yes

## Contractual warranty

Warranty	18 months
----------	-----------

**Dimensions**

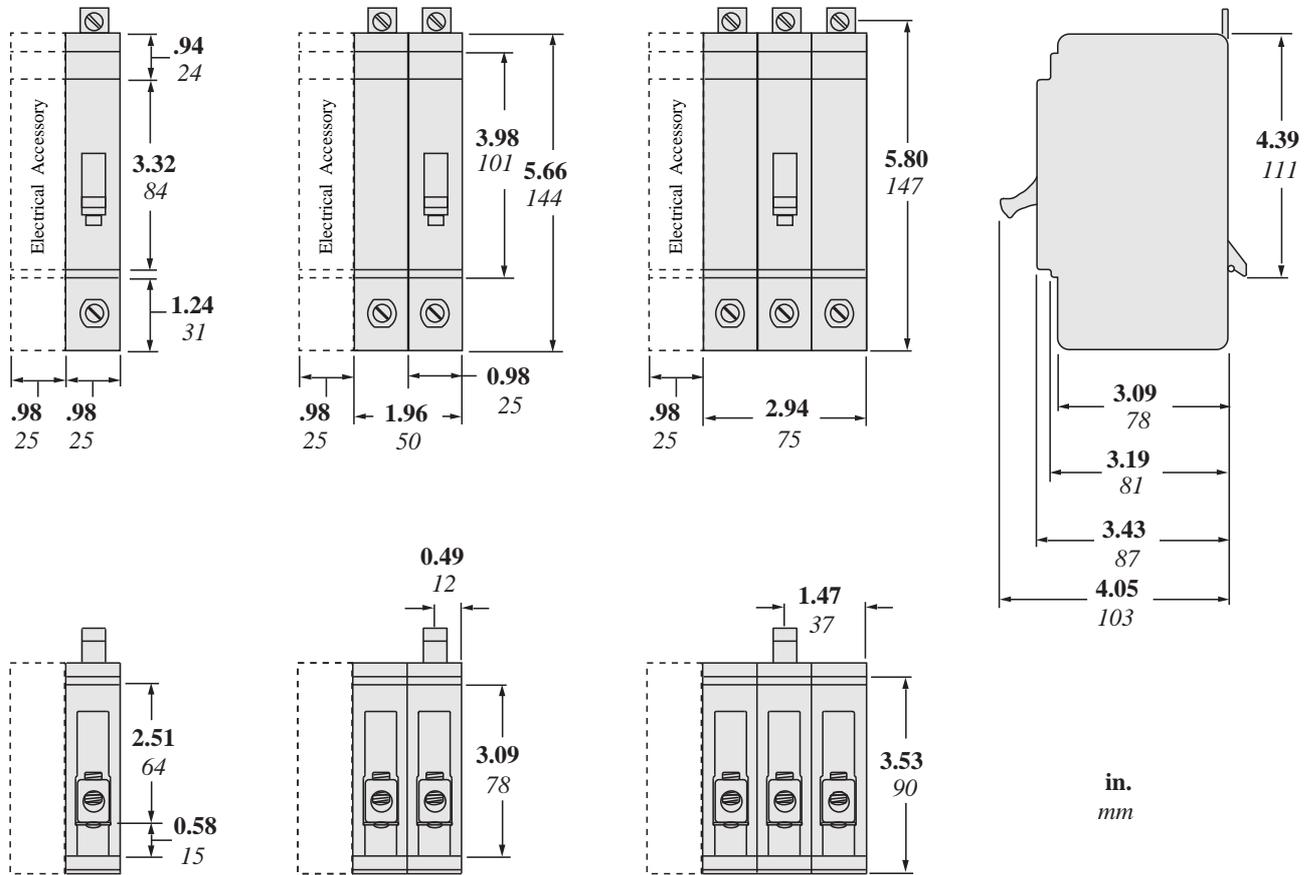


All dimensions are approximate.  
 Also see technical drawings and/or documentation.

Wiring Diagram

---

Shunt Trip /  
Disparo en derivación /  
Déclencheur shunt

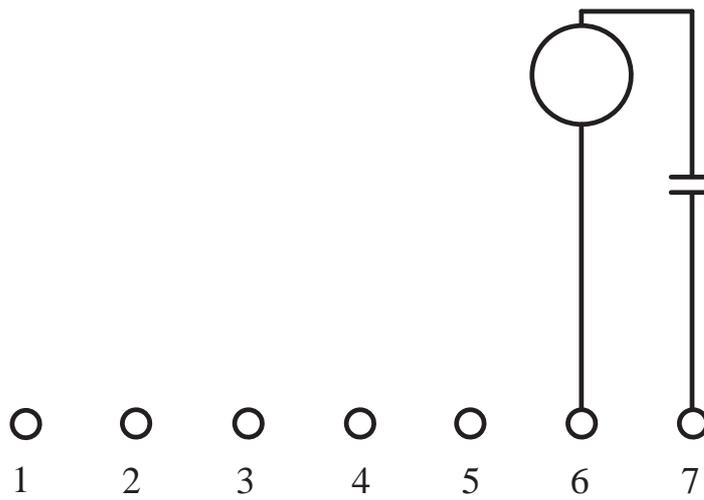

Recommended replacement(s)