

Product data sheet

Specifications

SQUARE D

Green Premium™



Circuit breaker, LA, 350A, 3 pole, 600VAC, 22kA, 250VDC, 10kA, lugs, unit mount

LAL36350

Product availability : Stock - Normally stocked in distribution facility

Price* : 4,619.00 USD

Main

Product or Component Type Circuit breaker

Trip Unit Technology Thermal-magnetic

Complementary

Line Rated Current 350 A

Number of Poles 3P

Mounting Mode Unit mount

Magnetic Hold Current 1750 A

Magnetic Tripping Current 3500 A

Electrical connection Lugs load
Lugs line

Terminal identifier AL400LA

Tightening torque 115.06 lbf.in (13 N.m) 0.07...0.47 in² (42...304 mm²) (AWG 1...600 kcmil)
115.06 lbf.in (13 N.m) 0.07...0.20 in² (42...127 mm²) (AWG 1...250 kcmil)

Height 11 in (279.40 mm)

Width 6 in (152.40 mm)

Depth 5.84 in (148.34 mm)

Circuit breaker application HACR rated

Environment

Certifications UL Listed
IEC
CSA

Ordering and shipping details

Category 00935-LAL/LHL BRKR, SW, MAG-GARD

Discount Schedule DE2

GTIN 785901426820

Returnability Yes

Country of origin MX

* Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	9.30 in (23.622 cm)
Package 1 Width	11.60 in (29.464 cm)
Package 1 Length	17.40 in (44.196 cm)
Package 1 Weight	16.20 lb(US) (7.348 kg)

Offer Sustainability

Sustainable offer status	Green Premium product
California proposition 65	WARNING: This product can expose you to chemicals including: DINP, which is known to the State of California to cause cancer, and DIDP, which is known to the State of California to cause birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov
REACH Regulation	REACH Declaration
EU RoHS Directive	Compliant EU RoHS Declaration
Mercury free	Yes
China RoHS Regulation	China RoHS declaration Product out of China RoHS scope. Substance declaration for your information.
RoHS exemption information	Yes
Environmental Disclosure	Product Environmental Profile
PVC free	Yes
Halogen content performance	Halogen free plastic parts product



Contractual warranty

Warranty	18 months
----------	-----------

Dimensions

Electrical Clearance / Wire Bending Space

Wire bending space is based upon the maximum wire size of the terminal, and NEC article 430-10. Wire bending space for the bottom is the same as the top wire bending space.

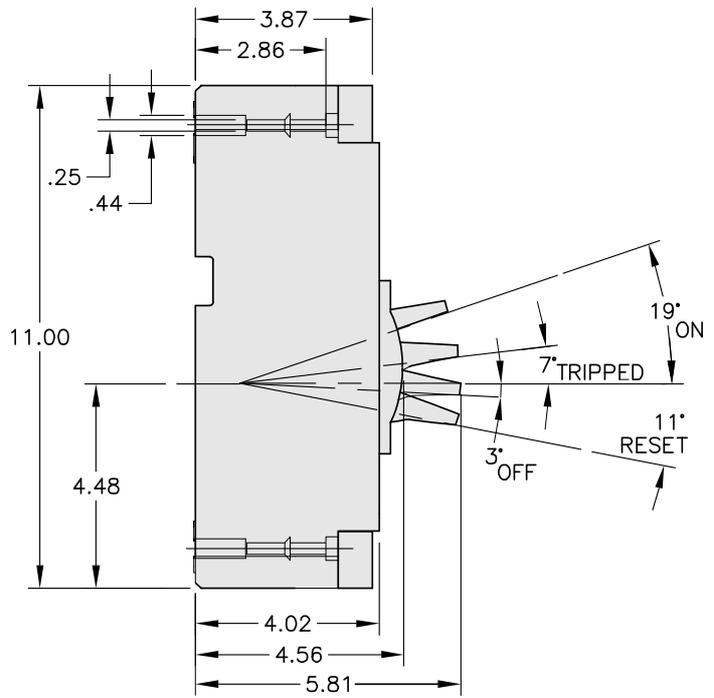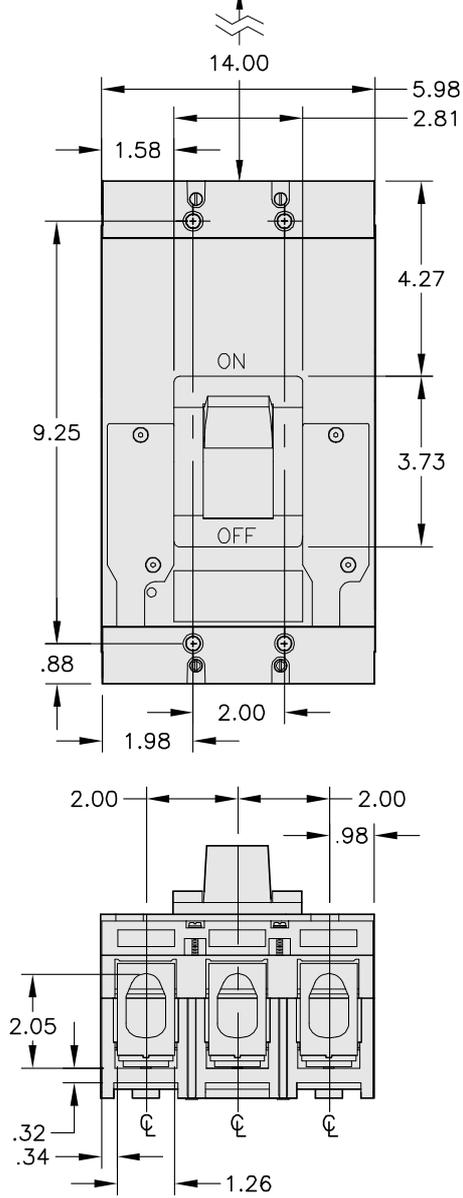

ALL DIMENSIONS ARE APPROXIMATE.
 ALSO SEE CAD, TECHNICAL DRAWINGS, AND TECHNICAL DOCUMENTATION

Recommended replacement(s)