

# Product data sheet

Specifications

SQUARE D

Green Premium™



## Mini circuit breaker, QO, 15A, 1 pole, 120/240VAC, 10kA, plug in mount

QO115

**Product availability : Stock - Normally stocked in distribution facility**

### Main

Product	Miniature circuit-breaker
Range	QO
Current Rating	15 A
Voltage Rating	120/240 V AC 120 V AC
Mounting Type	Plug-in
Number of Poles	1P
Circuit Breaker Type	Standard
Ratings	HACR and Switching Duty rated
Electrical Connection	Pressure plate

### Complementary

Interrupt Rating	10 kA 120/240 V AC 50/60 Hz 10 kA 120 V AC 50/60 Hz
Number of Panel Spaces	1
Wire Size	AWG 14...AWG 8 copper or aluminium
Tightening Torque	44.25 lbf.in (5 N.m) 0.02...0.04 in <sup>2</sup> (10...25 mm <sup>2</sup> ) (AWG 8...AWG 2)
Height	2.99 in (76 mm)
Width	0.75 in (19 mm)
Depth	2.91 in (74 mm)
Net Weight	0.30 lb(US) (0.136 kg)

### Environment

Certifications	UL Listed CSA
Ambient Rating	104 °F (40 °C)

### Ordering and shipping details

Category	00004-QO,QOT 10-30A 1P;10-60A 2P
Discount Schedule	DE2A
GTIN	785901400066

Returnability	Yes
Country of origin	US

## Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	3.00 in (7.62 cm)
Package 1 Width	0.70 in (1.778 cm)
Package 1 Length	3.30 in (8.382 cm)
Package 1 Weight	4.80 oz (136.078 g)
Unit Type of Package 2	BB1
Number of Units in Package 2	10
Package 2 Height	3.30 in (8.382 cm)
Package 2 Width	0.70 in (1.778 cm)
Package 2 Length	7.70 in (19.558 cm)
Package 2 Weight	2.74 lb(US) (1.243 kg)
Unit Type of Package 3	CAR
Number of Units in Package 3	100
Package 3 Height	8.20 in (20.828 cm)
Package 3 Width	6.70 in (17.018 cm)
Package 3 Length	17.40 in (44.196 cm)
Package 3 Weight	28.60 lb(US) (12.973 kg)


## Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	<a href="#">REACH Declaration</a>
EU RoHS Directive	Compliant <a href="#">EU RoHS Declaration</a>
Toxic heavy metal free	Yes
Mercury free	Yes
China RoHS Regulation	<a href="#">China RoHS declaration</a> Product out of China RoHS scope. Substance declaration for your information.
RoHS exemption information	<a href="#">Yes</a>
Halogen content performance	Halogen free product

## Contractual warranty

Warranty	18 months
----------	-----------

**Dimensions**

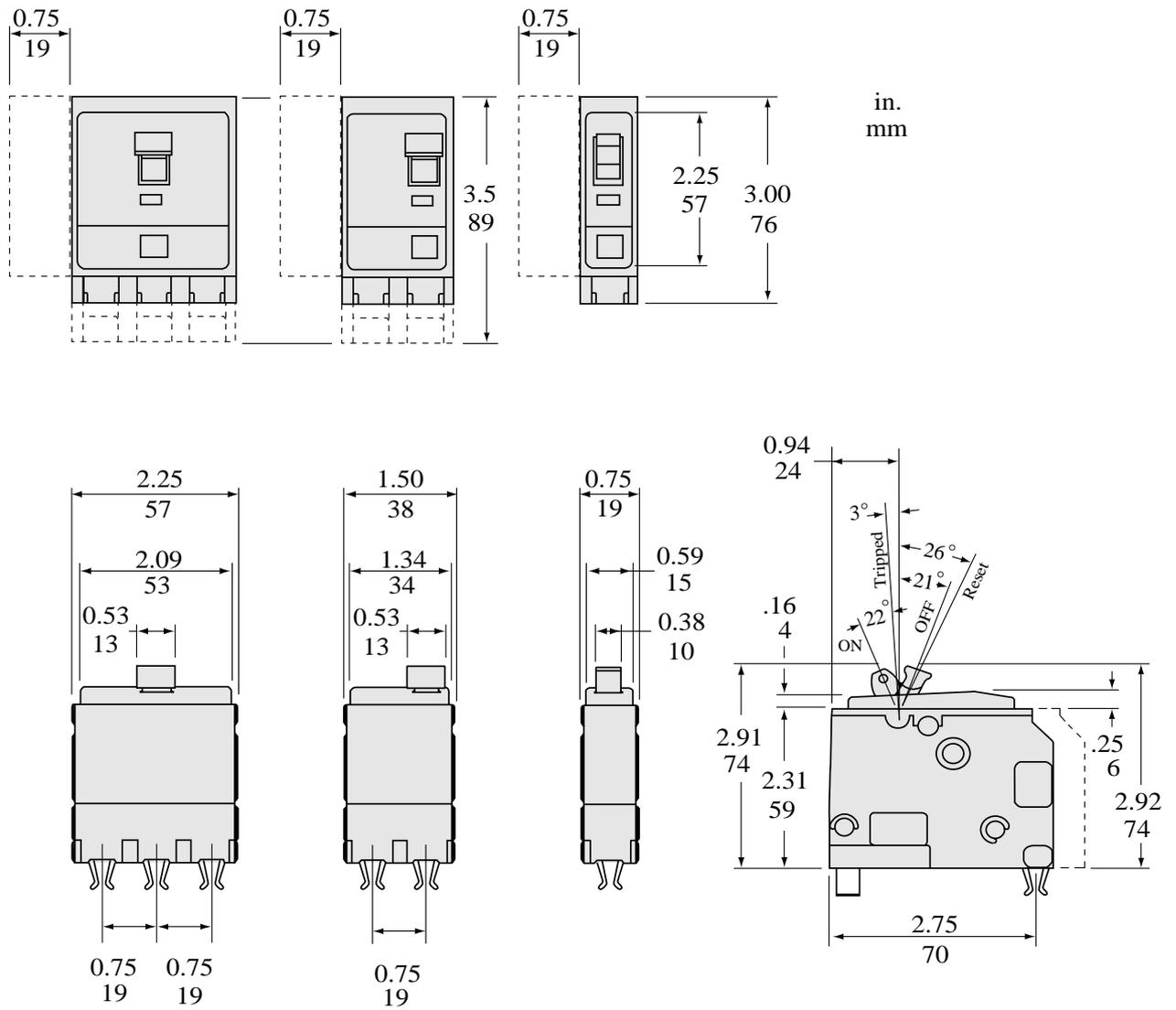

Dimensions are approximate. Refer to technical documentation, dimension drawings, and/or CAD for additional detail.

**Recommended replacement(s)**