

Product data sheet

Specifications

SQUARE D

Green Premium™



Enclosed molded case switch, QO, 60A, 2 pole, 240VAC, 22kA, air conditioning, NEMA 3R

QO200TR

Product availability : Stock - Normally stocked in distribution facility

Main

Product Type Enclosed molded case switch
Weatherproof enclosure

Range of Product QO

Complementary

Current Rating 60 A

Interrupt Rating 22 kA 240 V AC

Number of Phases 1 phase

Enclosure Rating NEMA 3R outdoor

Breaker Compatibility Circuit breaker QO 2P

For Use With air conditioner

Product Certifications UL Listed

Indoor/Outdoor Use Enclosed outdoor

Surface Finish Baked enamel Gray

Voltage Rating 240 V AC

Ambient Air Temperature for Operation 104 °F (40 °C)

Height 6.50 in (165 mm)

Width 4.65 in (118 mm)

Depth 3.90 in (99 mm)

Product Weight 3.00 lb(US) (1.361 kg)

Ordering and shipping details

Category 00044-A/C DISC & PULL-OUTS

Discount Schedule DE2A

GTIN 785901535966

Returnability Yes

Country of origin MX

Packing Units

Unit Type of Package 1 PCE

Number of Units in Package 1	1
Package 1 Height	3.50 in (8.89 cm)
Package 1 Width	4.20 in (10.668 cm)
Package 1 Length	6.50 in (16.51 cm)
Package 1 Weight	3.00 lb(US) (1.361 kg)
Unit Type of Package 2	CAR
Number of Units in Package 2	10
Package 2 Height	7.10 in (18.034 cm)
Package 2 Width	9.80 in (24.892 cm)
Package 2 Length	19.80 in (50.292 cm)
Package 2 Weight	30.35 lb(US) (13.767 kg)
Unit Type of Package 3	PAL
Number of Units in Package 3	400
Package 3 Height	42.00 in (106.68 cm)
Package 3 Width	40.00 in (101.6 cm)
Package 3 Length	48.00 in (121.92 cm)
Package 3 Weight	1270.00 lb(US) (576.062 kg)


Offer Sustainability

Sustainable offer status	Green Premium product
California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Compliant EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
China RoHS Regulation	China RoHS declaration Pro-active China RoHS declaration (out of China RoHS legal scope)
RoHS exemption information	Yes
Environmental Disclosure	Product Environmental Profile


Contractual warranty

Warranty	18 months
-----------------	-----------

Dimensions

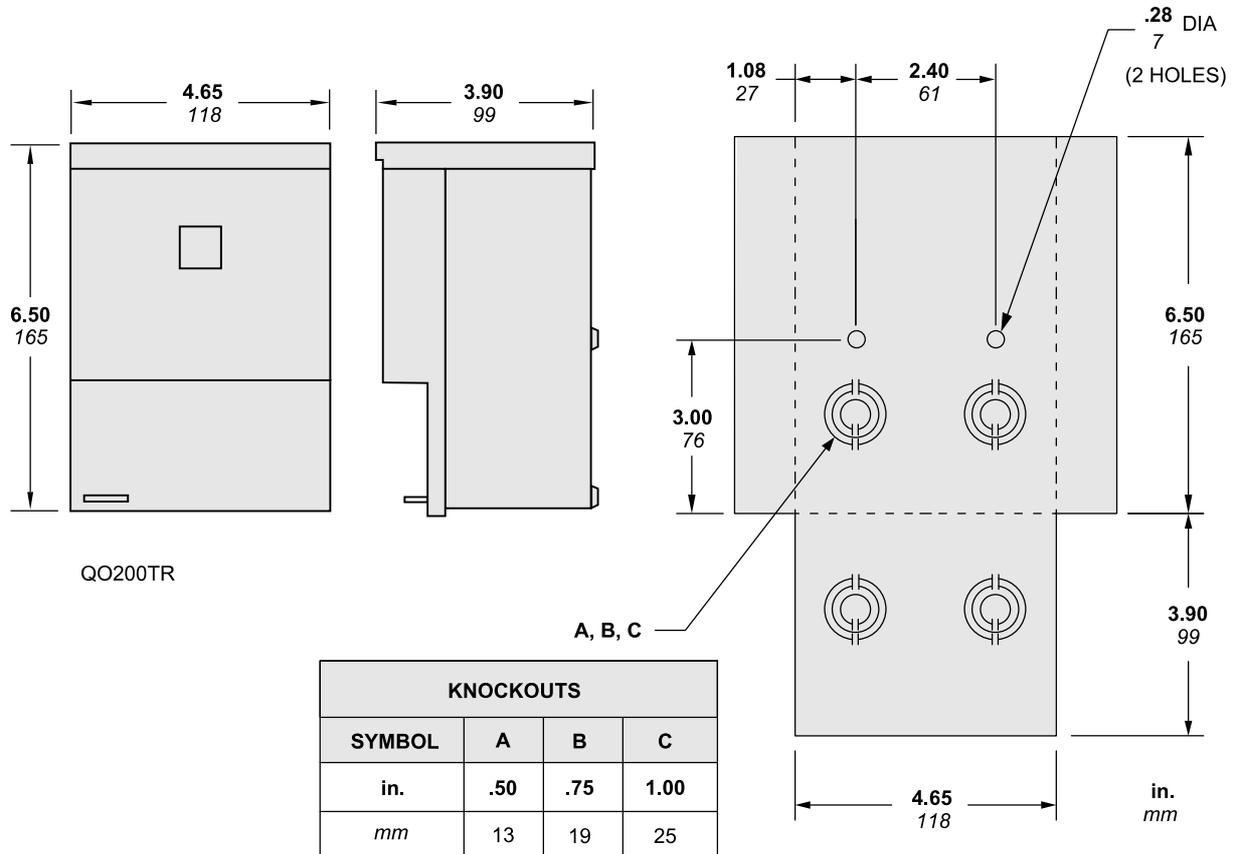

Wiring Diagram

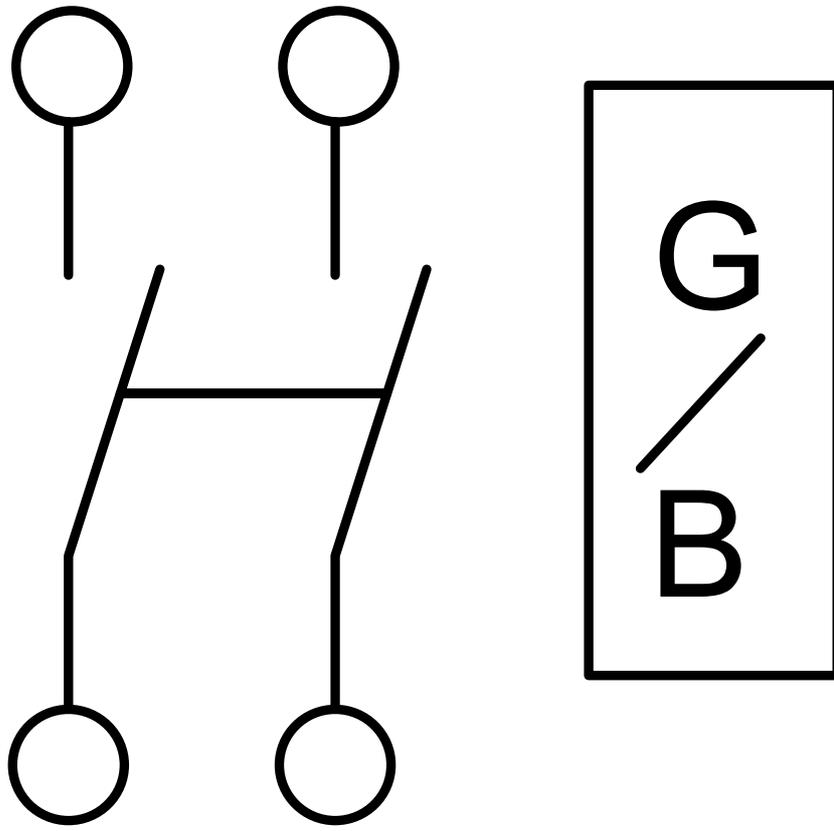

240VAC

Recommended replacement(s)