

Enclosures **CF Series**

Polycarbonate Enclosure 5 x 3 x 3 Inches CF Series Slim with Opaque Lift Off Cover



**Catalog
Number**

CFPC533

UPC

785928564642


DESCRIPTION

5H x 3W x 3D Inches Polycarbonate CF Series Slim Enclosure with Opaque Lift Off Cover is ideal for compact or portable control or simply as a small junction box. This stream lines series features unobstructed sidewalls, captive cover screws and a full range of sizes.

APPLICATION

- For use in many MRO and OEM applications
- Slim design allows easy installation of pushbuttons and switches in machine control applications with tight or dense space requirements
- Used in compact or portable control systems or for use as an Operator Interface Enclosure in both indoor and outdoor environments
- Used as general Junction Enclosures or termination point enclosures in an electrical system
- Used indoors or outdoors

FEATURES

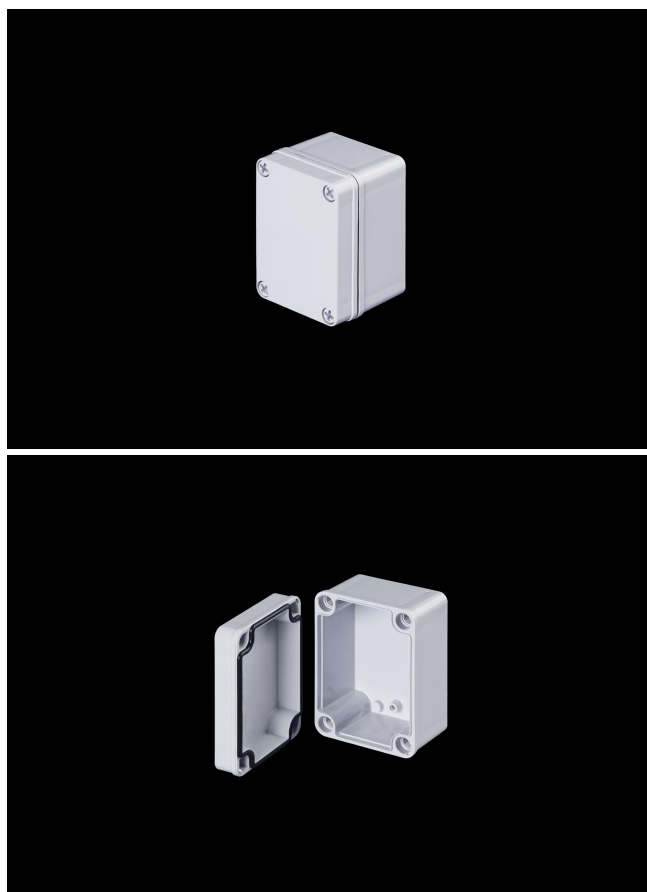

- Memory retaining continuous polyurethane gasket
- Corrosion resistant polycarbonate
- Submersible; non corrosive; environmental design
- High Impact Resistance

General Information

Color	Gray
Cover Type	Opaque
Mounting Type	Wall Mount
Material	Polycarbonate
Cover Screw Size	Custom
Cover Screw Recommended Torque	16-20 in-lbs
Cover Screw Material	Polycarbonate
Installation Mounting Torque	25-30 in-lbs Max
Metal Inserts	
Gasket Material	Poured In Place (PIP) Polyurethane Seamless
Country of Origin	USA

DIMENSIONS

Height (in)	5
Width (in)	3
Depth (in)	3
Height (mm)	127
Width (mm)	76.2
Depth (mm)	76.2
Usable Depth (in)	3.26
Usable Depth (mm)	82.8

STANDARDS

NEMA 10250; UL 50; UL 50e; cULus Listed File
UL508A #E64358

CSA Std. C22.2 cULus Listed File
#E64358

Type 1; 3R; 4; 4X; 6P; 12

IEC 60529; UL Listed IP66; IP68
#E362920

Temperature Range °F -40°F to +248°F

Temperature Range °C -40°C to +120°C

Flammability Rating UL94-5VA

Outdoor Exposure UL746c (f1) Rated

CE Certified