

Accessories **Replacement Cover**

Fiberglass Opaque Replacement Cover with Viewing Window for Diamond Shield 10 x 8 Inches

**Catalog
Number**

DSW1008CVR

UPC

785928911460

DESCRIPTION


10H x 8W Inches Diamond Shield Series
Fiberglass Enclosure Cover Only with Viewing
Window. To be used as a replacement cover

APPLICATION

- Suited for high-end and harsh industrial applications
- Used indoors or outdoors
- Innovative internal panel management capabilities
- Used in highly corrosive areas
- Panel mounting in the cover for use as an Operator Interface Enclosures in industrial equipment control stations

FEATURES

- Flush bonded window replacement cover for Diamond Shield Series
- High temperature; flame retardant; non corrosive; environmental designs
- Results in an environmentally sealed; environmentally sound space
- High impact resistance
- Double insulated material no incidental electrical contact
- Solid construction in a lightweight design

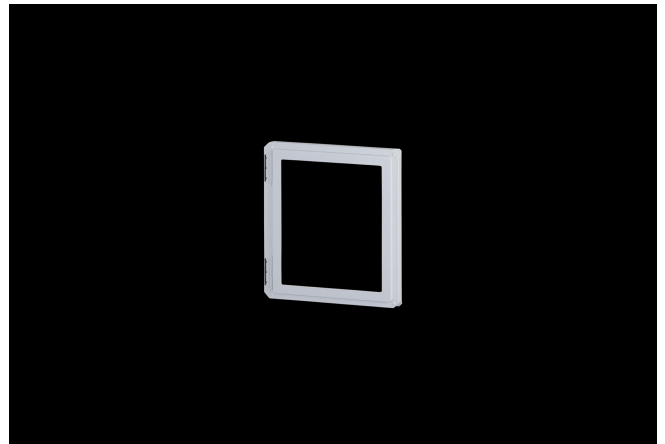

- UV resistant

General Information

Color	Gray
Cover Type	Window
Material	Fiberglass
Cover Screw Size	#10-32 x 1-1/4
Cover Screw Recommended Torque	20-24 in-lbs
Cover Screw Material	304 SS
Gasket Material	Poured In Place (PIP) Polyurethane Seamless
Country of Origin	USA

DIMENSIONS

Height (in)	11.42
Width (in)	9.8
Height (mm)	290.068
Width (mm)	248.92

STANDARDS

Temperature Range °F	-76°F to +274°F
Temperature Range °C	-60°C to +134°C
Window Temperature Range °F	-26°F to +170°F
Window Temperature Range °C	-32°C to +76°C
Flammability Rating	UL94-5VA
Outdoor Exposure UL746c	(f1) Rated