





810601

SD Series Micrometer Adjustable Click Wrench, 160 - 800 Nm

 
 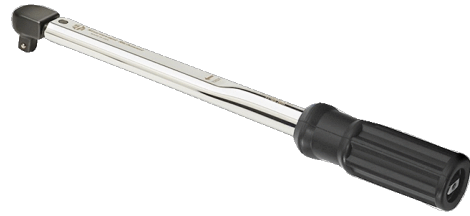


PRODUCT DETAILS

- Torque value is adjusted by rotating the grip
- Our tools change from the top of the scale to the bottom in the fewest number of turns
- Grip lock makes locking in the torque value fast, easy, and secure
- Ball-bearing rock-over assembly assures smooth operation, enhances repeatability, and increases wrench service life
- Accuracy of +/- 4% of Indicated Value from 20% to 100% of rated capacity
- Meets or exceeds requirements of ASME B107.300-2010 and ISO 6789
- Design provides a strong audible and tactile pulse when the set torque is achieved
- Flattened case provides the mechanism with superior support resulting in a wrench that is easier to calibrate and one that holds calibration longer
- Ratchet is built for durability
- Ratchet replacement is fast and easy when needed
- All tools up to 250 ft-lb, or 300 Nm, capacity come with a rugged, custom-molded plastic case
- Includes FREE tabulated calibration certificate.
- PLEASE NOTE: See below for manuals & details drawings; click the drop down menu, click on specific product PDF, click the download button

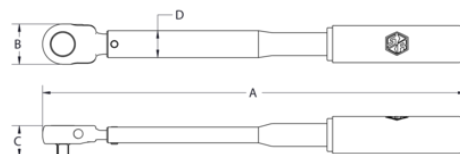

PRODUCT ATTRIBUTES

Product	MODEL	 N·m	 Nm	A	B	C	D
810601	6 SD 800 NM	100-600 N·m	5 N·m	39.2 in	2.7 in	2.0 in	2.0 in