

OPTIONS & ACCESSORIES
LIBERTY® SERIES
 PORTABLE CAPSTAN WINCHES

TECHNICAL DRAWINGS & SPECIFICATIONS
LIBERTY® SERIES
 PORTABLE CAPSTAN WINCHES



Product Shown:
 3CP1S-HM

Liberty Capstan Hitch Mounts - sold separately


Model 3CP1S-HM

- Compatible with 3CP1S-AFS 1,000 pound capacity Liberty Capstan winch only
- Heavy-duty (ASTM-grade steel) construction
- For use on vehicles with 2-inch hitch receiver
- Hitch mount includes standard receiver clevis and cotter pins
- Red powder-coat finish
- Weighs approximately 26 pounds for easy handling


Model 3CP2S-HM

- Compatible with both 3CP1S-AFS 1,000 pound capacity and 3CP2S-AFS 2,000 pound capacity Liberty Capstan winches
- Heavy-duty (ASTM-grade steel) construction
- For use on vehicles with 2 1/2-inch hitch receiver
- Hitch includes standard receiver clevis and cotter pins
- Red powder-coat finish
- Weighs approximately 45 pounds for easy handling

Model 3CP1S-HM*

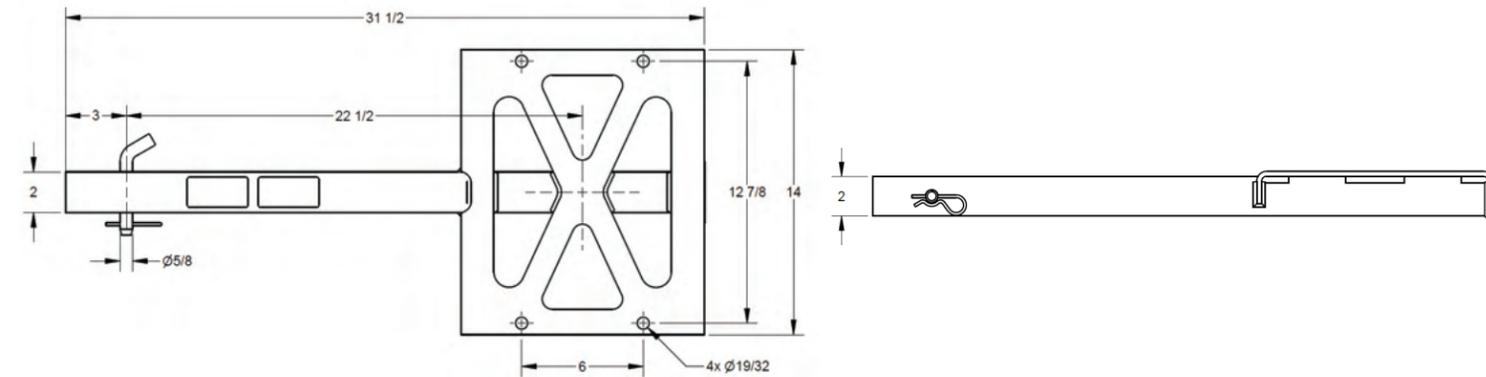

Model 3CP2S-HM*

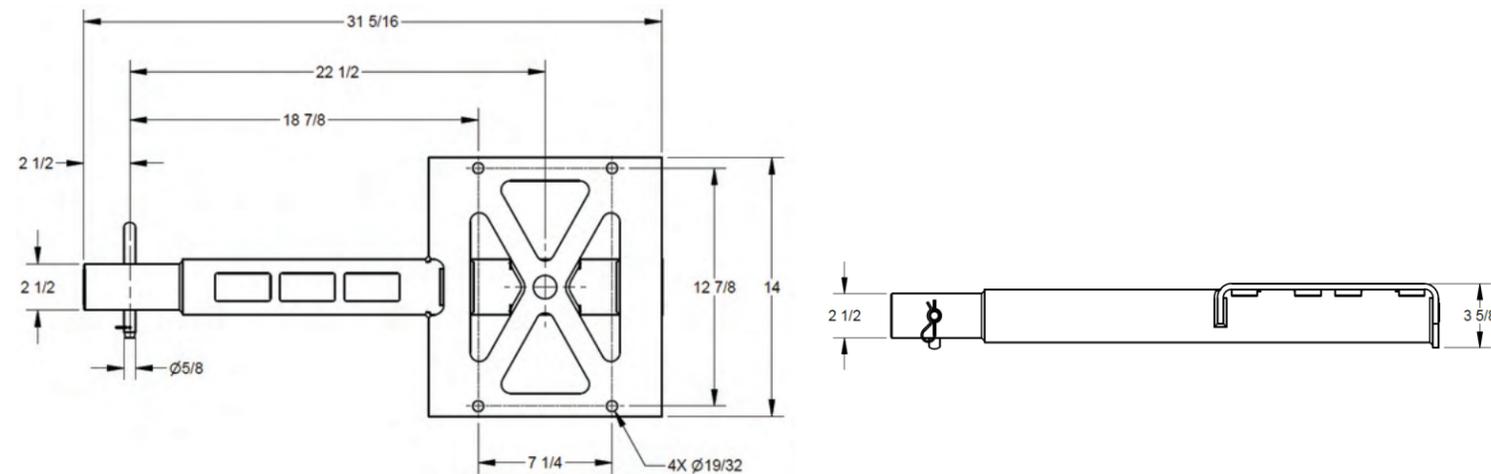

Synthetic Rope Assemblies—sold separately

Samson Synthetic rope assemblies are for use with Thern Liberty Capstan series winches only. For additional rope assemblies, contact the factory.

Rope Diameter (in) (mm)	Rope Lengths Available
1/2 12.7	300 ft. (91.4 m.), 600 ft. (182.9 m.), 1200 ft. (365.8 m.)
5/8 15.9	300 ft. (91.4 m.), 600 ft. (182.9 m.), 1200 ft. (365.8 m.)
3/4 19.1	300 ft. (91.4 m.), 600 ft. (182.9 m.), 1200 ft. (365.8 m.)

NOTICE: These products are not for lifting people or things over people.

Refer to technical pages for detailed performance information.

* Dimensions given in inches.