

52®/53® Series Liquidtight Fittings and Flexible Metallic Conduits

Straight Grounding Fittings



CAT. NO.			CONDUIT SIZE	DIMENSIONS (IN.)			GROUND WIRE (AWG)
STEEL INSULATED	STEEL NON-INSULATED	ALUMINUM NON-INSULATED		A	B	C	
5331GR**	5231GR*	5231ALGR*	3/8"	1 1/32	1 1/2	9/16	#14-#8
5332GR*	5232GR*	5232ALGR*	1/2"	1 3/8	1 7/8	9/16	#14-#8
5333GR*	5233GR*	5233ALGR*	3/4"	1 21/32	1 3/4	9/16	#14-#4
5334GR*	5234GR*	5234ALGR*	1"	1 7/8	2 1/8	3/4	#14-#4
5335GR	5235GR	—	1 1/4"	2 1/4	2 1/2	13/16	#8-1/0
5336GR	5236GR	—	1 1/2"	3 1/4	2 11/16	13/16	#4-2/0
5337GR	5237GR	—	2"	3 13/16	3 1/8	7/8	#4-2/0
5338GR	5238GR	—	2 1/2"	4 1/8	4 1/8	1	#2-4/0
5339GR	5239GR	—	3"	5 5/8	4 3/4	1	#2-4/0
5340GR	5240GR	—	4"	6 1/8	4 1/2	1 1/8	#2-4/0
5385GR	5285GR	—	5"	8 3/8	7	1 1/8	#2-4/0
5386GR	—	—	6"	8 17/32	8 1/2	2	#2-4/0




Note: Revolver® Grounding Device available on sizes 3/8"-1" only. To order Revolver® Grounding Device separately, use Catalog Nos. 38GR-TB for 3/8", 12GR-TB for 1/2", 34GR-TB for 3/4" and 1GR-TB for 1".


90° Angle Grounding Fittings



CAT. NO.			CONDUIT SIZE	DIMENSIONS (IN.)			GROUND WIRE (AWG)
STEEL INSULATED	STEEL NON-INSULATED	ALUMINUM NON-INSULATED		A	B	C	
5351GR**	5251GR**	5251ALGR*	3/8"	1 1/32	1 1/4	9/16	#14-#8
5352GR*	5252GR*	5252ALGR*	1/2"	1 3/8	1 7/8	9/16	#14-#8
5353GR*	5253GR*	5253ALGR*	3/4"	1 21/32	1 3/4	9/16	#14-#4
5354GR*	5254GR*	5254ALGR*	1"	1 7/8	2 1/8	3/4	#14-#4
5355GR*	5255GR	—	1 1/4"	2 1/4	2 1/2	13/16	#8-1/0
5356GR	5256GR	—	1 1/2"	3 1/4	2 15/16	13/16	#4-2/0
5357GR	5257GR	—	2"	3 13/16	3 1/8	7/8	#4-2/0
5358GR	5258GR	—	2 1/2"	4 1/8	8 1/8	1	#2-4/0
5359GR	5259GR	—	3"	5 5/8	10 1/4	1	#2-4/0
5360GR	5260GR	—	4"	6 1/8	12 5/8	1 1/8	#2-4/0

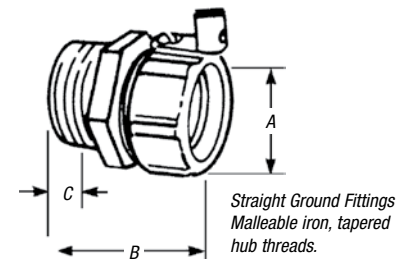


Straight Ground Fittings
Malleable iron, tapered hub threads.

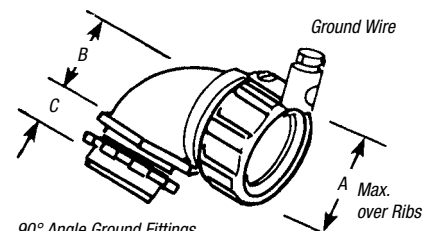

90° Angle Ground Fittings
Malleable iron tapered hub threads.

45° Angle Grounding Fittings

CAT. NO.		CONDUIT SIZE	DIMENSIONS (IN.)			GROUND WIRE (AWG)
INSULATED	NON-INSULATED		A	B	C	
5341GR**	5241GR**	3/8"	1 1/32	1 1/8	9/16	#14-#8
5342GR*	5242GR*	1/2"	1 3/8	1 7/8	9/16	#14-#8
5343GR*	5243GR*	3/4"	1 21/32	2 1/8	9/16	#14-#4
5344GR*	5244GR*	1"	1 7/8	2 1/4	3/4	#14-#4
5345GR	5245GR	1 1/4"	2 1/4	2 3/4	13/16	#8-1/0
5346GR	5246GR	1 1/2"	3 1/4	3 3/8	13/16	#4-2/0
5347GR	5247GR	2"	3 13/16	3 3/8	7/8	#4-2/0
5348GR	5248GR	2 1/2"	4 1/8	4 1/4	1	#2-4/0
5349GR	5249GR	3"	5 5/8	4 3/4	1	#2-4/0
5350GR	5250GR	4"	6 1/8	4 3/4	1 1/8	#2-4/0

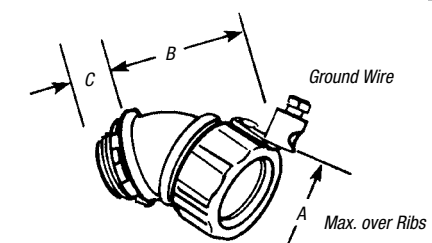

45° Angle Ground Fittings
Malleable iron, tapered hub threads.

* 3/8"-1" fittings include Revolver® grounding device. For sizes 1 1/4" and up, fittings are supplied with a copper mechanical lug.

** 3/4" conduit fittings have 1/2" trade size hub. With safe-edge ground cone (through 4") and double bevel sealing ring (through 2").

UL Listed liquidtight; and CSA Certified watertight. Suitable for hazardous locations use in Class I, Div. 2; Class II, Div. 1 and 2; Class III, Div. 1 and 2, where general purpose equipment is specifically permitted per NEC®. Available with DURA-PLATE® Finish. UL File No. E 3060 CSA File No. 638