




Actual

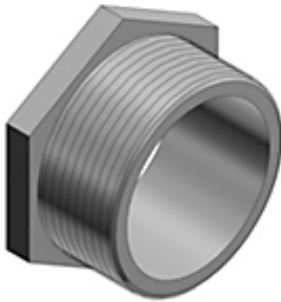

Representative

**Project:** Anixter  
**Location:** Nisku

**Catalog Number:** 847  
**Product ID:** 7TAD013130R0013  
**UPC Number:** 78621000847  
**EAN Number:** 05414363146667  
**Status:** A

2 Inch Chase Nipple, Malleable Iron for Use with Rigid/IMC Conduit

#### North American Specifications (UNSPSC)

UNSPSC	39131718 Electrical conduit nipple
IGCC	5753 Electrical conduit nipple
Type	Chase Conduit Nipple
Application	To Effectively Bush Factory or Field-Punched, Cut, or Drilled Holes In Metal Boxes or Enclosures. To Couple Boxes Back-to-Back
Standard	UL E23018, CSA
Material	Malleable Iron
Trade Size	2 in

#### European Specifications (ETIM)

ETIM	EC001469 Protective hose adapter
With outer thread	Y
Thread size outer thread metric	53
Material housing	Other
Material quality	Other
Surface protection	Untreated
Model	Straight
Material sealing	No sealing

#### Packaging

Inner Quantity	5
Inner Dimensions (inches)	6.2x4.7x4.4
Outer Quantity	50
Outer Dimensions (inches)	21.7x9.9x7
Weight Uom	39.5 lbs. per 100

#### Documents / Support Tools

Technical Drawing / Data Sheet	WSD-001846
Catalog Page	Available on Website

#### Header

3D Model	Available on Website
----------	----------------------