

Hook-and-Loop Fasteners

Available in UL94V-2 rated material.

F0, FOL, FOS and FOR Series Hook-and-Loop Fasteners


- High-quality Hook-and-Loop Fasteners
- Reusable — great for frequently changed bundles
- Wide bearing surface — ideal for data and fiber optic cable
- Sizes available to accommodate varying bundle diameters
- Flame-retardant and colored material available

STD. PKG. CAT. NO.	MIN. TENSILE STRENGTH LBS./N	MAX. BUNDLE DIA. IN./MM	LENGTH IN./MM	WIDTH IN./MM	STD. PKG. QTY.
F0 Series Slotted Loop Ties*					
F0200-40-0	40/177.9	2.0/50.80	9/228.6	.50/12.7	10
F0200-50-0	50/222.4	2.0/50.80	9/228.6	.75/19.05	10
F0350-40-0	50/222.4	3.5/88.90	13/330.2	.50/12.7	10
F0350-50-0	50/222.4	3.5/88.90	13/330.2	.75/19.05	10
FOL Series Buckle Ties					
FOL300-50-0	50/222.4	3.0/76.20	12/304.8	.75	10
FOL500-50-0	50/222.4	5.0/127.0	18/457.2	.75	10
FOS Series Strip Ties					
FOS150-50-0	50/222.4	1.5/38.10	6/152.4	.75	10
FOS320-50-0	50/222.4	3.2/81.28	12/304.8	.75	10
FOS500-50-0	50/222.4	5.0/127.00	18/457.2	.75	10
FOR Series Rolled Hook and Loop					
FOR180-50-0	50/222.4	Various	180/4572	.75	1

- $\frac{1}{16}$ " strap thickness
 - Black is standard color.
 - Multiple colors available for identifying specific bundles
- *Add suffix "FR" for UL94V-2 rated flame-retardant material, after color choice.
Contact Customer Service for availability and delivery.

Mounting bases for use with hook-and-loop fasteners.

Nylon 6.6 Mounting Bases

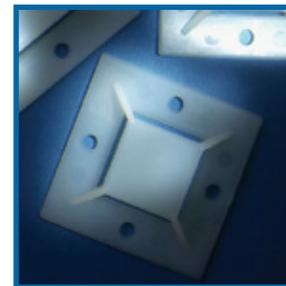

BULK PKG. CAT. NO.	DESCRIPTION	SCREW SIZE	MAXIMUM TIE WIDTH ACCOM.	BULK PKG. QTY.
TC368	2" x 2" Screw Mounted	#8	.75/19.05	500
TC368A	2" x 2" Adhesive Mounted	#8	.75/19.05	500

-40° F to 176° F (-40° C to 80° C)

- Natural nylon color.

Note: See expiration date on TC368A package. Periodically check product for adhesion and replace as needed.
Product is for wire management only and is not intended for use as a primary support of wire, cable, etc.