



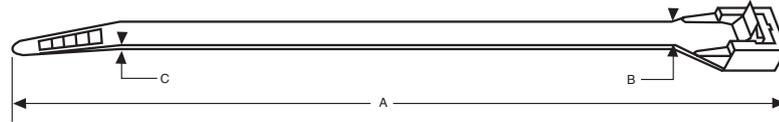

### Releasable Cable Ties

Temporarily fastens wires, cables and hoses.

- Extended releasable tab in the head makes for easy release and reusability.
- Great for temporary work or where frequent servicing is required.
- Ultraviolet black (UVB) ties resist harmful light rays – primarily for outdoor use.

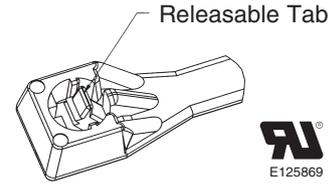


Length	Color	Part #	Pkg Qty	DoubleLock®	Tensile Strength	Length A	Width B	Thickness C	Bundle Dia. Max.	UL
8"	Natural	47-108	25/bag	—	50 lb	8.00"	0.17"	0.05"	1.75"	UR
	UVB	47-108UVB	25/bag	—	50 lb	8.00"	0.17"	0.05"	1.75"	UR
16"	UVB	47-115UVB	4/bag	—	175 lb	15.25"	0.52"	0.09"	4"	UR
22"	UVB	47-121UVB	3/bag	—	175 lb	21.50"	0.52"	0.09"	6"	UR
28"	UVB	47-127UVB	3/bag	—	175 lb	27.75"	0.52"	0.09"	8"	UR



### Mounting Cable Ties

Secures bundles to walls, studs or other surfaces easily.

- Accepts #10 screws.
- Ultraviolet black (UVB) ties resist harmful light rays – primarily for outdoor use.

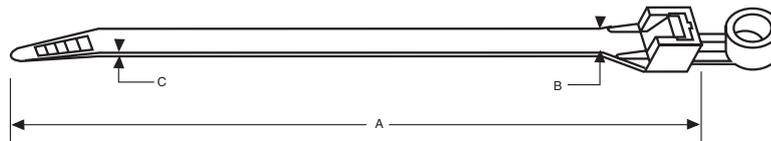

Length	Color	Part #	Pkg Qty	DoubleLock®	Tensile Strength	Length A	Width B	Thickness C	Bundle Dia. Max.	UL
8"	Natural	45-308MT	20/bag	—	50 lb	8.63"	0.17"	0.055"	2"	UR
	Natural	48-308	100/bag	—	50 lb	8.63"	0.17"	0.050"	2"	UR
	UVB	45-308MTUVB	15/bag	—	50 lb	8.63"	0.17"	0.055"	2"	UR
	UVB	48-308UVB	100/bag	—	50 lb	8.63"	0.17"	0.055"	2"	UR
	Gray	45-308MTG	15/bag	—	50 lb	8.63"	0.17"	0.055"	2"	UR