

DATA SHEET



Three Phase Induction Motor - Squirrel Cage

Customer : Dealers Industrial Equipment 800-469-3110
Customer reference : 14829289

Product line : W40 JP Pump High Efficiency Three-Phase Product code : 14829289
Catalog # : 04036OP3EFP286JPV-W4

Frame	: 284/6JP	Locked rotor time	: 18s (cold) 10s (hot)
Output	: 40 HP (30 kW)	Temperature rise	: 80 K
Poles	: 2	Duty cycle	: Cont.(S1)
Frequency	: 60 Hz	Ambient temperature	: -20°C to +40°C
Rated voltage	: 208-230/460 V	Altitude	: 1000 m.a.s.l.
Rated current	: 104-94.4/47.2 A	Protection degree	: IP23
L. R. Amperes	: 637-576/288 A	Cooling method	: IC01 - ODP
LRC	: 6.1x(Code G)	Mounting	: W-6
No load current	: 24.1-28.0/14.0 A	Rotation ¹	: Both (CW and CCW)
Rated speed	: 3535 rpm	Starting method	: Direct On Line
Slip	: 1.81 %	Approx. weight ³	: 359 lb
Rated torque	: 58.6 ft.lb		
Locked rotor torque	: 170 %		
Breakdown torque	: 250 %		
Insulation class	: F		
Service factor	: 1.15		
Moment of inertia (J)	: 1.91 sq.ft.lb		
Design	: B		

Output	25%	50%	75%	100%	Foundation loads
Efficiency (%)	90.8	91.0	91.7	91.7	Max. traction
Power Factor	0.54	0.78	0.86	0.87	Max. compression

	Drive end	Non drive end
Bearing type	: 6311 Z C3	6211 Z C3
Sealing	: Without Bearing Seal	Without Bearing Seal
Lubrication interval	: 11517 h	14226 h
Lubricant amount	: 18 g	11 g
Lubricant type	: Mobil Polyrex EM	

Notes
downloaded from <http://dealerselectric.com>

This revision replaces and cancel the previous one, which must be eliminated.
(1) Looking the motor from the shaft end.
(2) Measured at 1m and with tolerance of +3dB(A).
(3) Approximate weight subject to changes after manufacturing process.
(4) At 100% of full load.

These are average values based on tests with sinusoidal power supply, subject to the tolerances stipulated in NEMA MG-1.

Rev.	Changes Summary	Performed	Checked	Date
Performed by		Page 1 / 2 Revision		
Checked by				
Date	16/04/2019			

LOAD PERFORMANCE CURVE

Three Phase Induction Motor - Squirrel Cage




Customer : Dealers Industrial Equipment 800-469-3110
Customer reference : 14829289

Product line : W40 JP Pump High Efficiency
Three-Phase

Product code : 14829289

Catalog # : 04036OP3EFP286JPV-W4

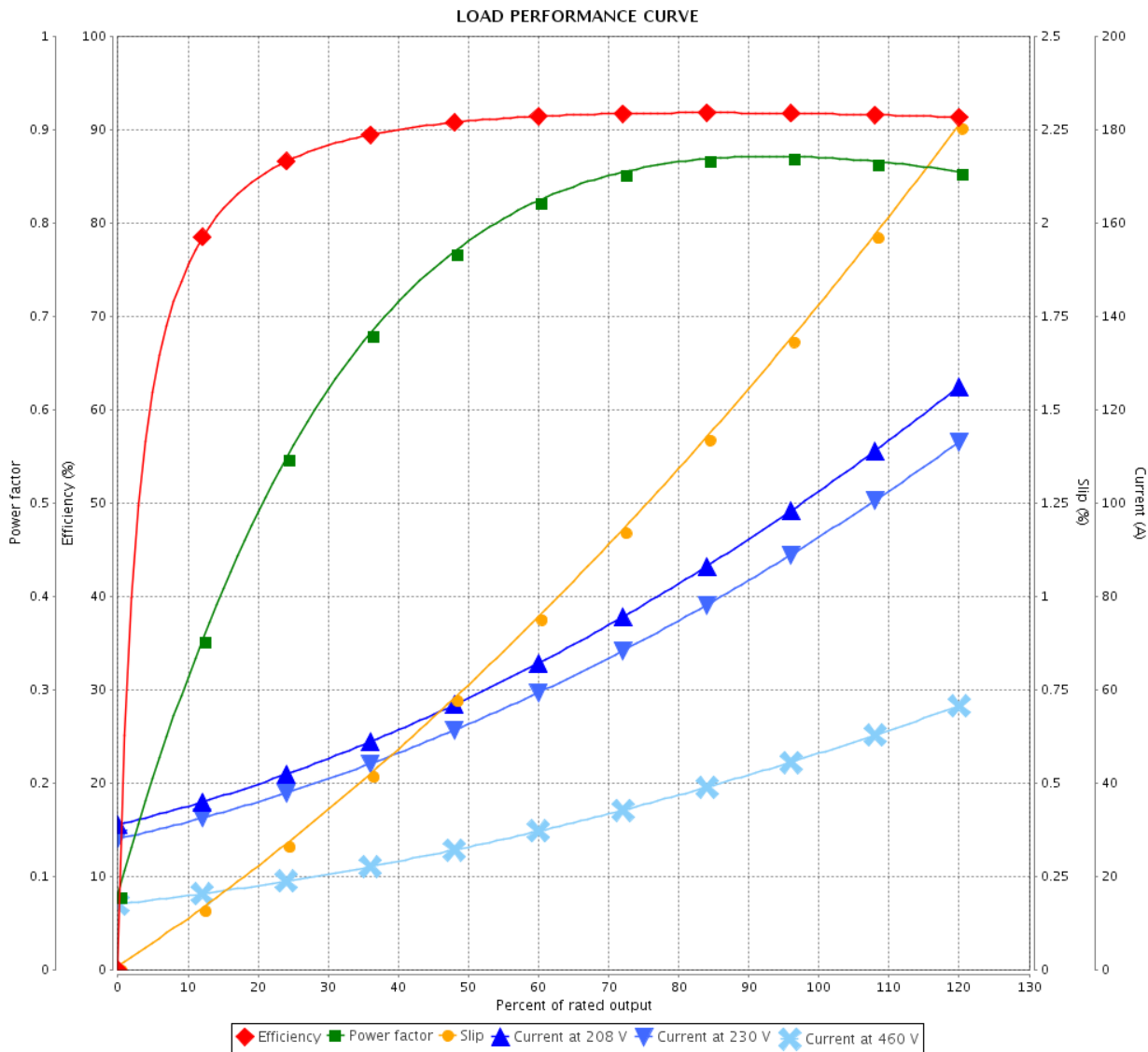

Performance : 208-230/460 V 60 Hz 2P

Rated current : 104-94.4/47.2 A
LRC : 6.1
Rated torque : 58.6 ft.lb
Locked rotor torque : 170 %
Breakdown torque : 250 %
Rated speed : 3535 rpm

Moment of inertia (J) : 1.91 sq.ft.lb
Duty cycle : Cont.(S1)
Insulation class : F
Service factor : 1.15
Temperature rise : 80 K
Design : B

Rev.	Changes Summary		Performed	Checked	Date
Performed by				Page	Revision
Checked by				2 / 2	
Date					

