



Zyklop Speed Ratchet



Small return angle

The fine 72 tooth ratchet mechanism has a low return angle of 5°. This short stroke allows fast and precise work in small spaces.



Swivel ratchet head


The ratchet head pivots freely and locks at 0°, 15° and 90°, making it possible to work in confined spaces with ample hand clearance.



Simple direction change

Rotating the large thumbwheel quickly changes rotation from clockwise to counterclockwise from any position of the ratchet head.

Wera Speed Ratchets		
Part Number	Description	Price
0500350055	Wera Zyklop Speed ratchet, 1/4 inch drive, with locking swivel head and ergonomic grip handle. Manufacturer part number 003500.	\$81.00
0500355055	Wera Zyklop Speed ratchet, 3/8 inch drive, with locking swivel head and ergonomic grip handle. Manufacturer part number 003550.	\$90.00
0500360055	Wera Zyklop Speed ratchet, 1/2 inch drive, with locking swivel head and ergonomic grip handle. Manufacturer part number 003600.	\$99.00

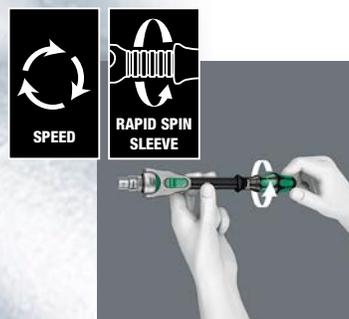

Unbelievably fast


The gyrating mass design along with the Kraftform handle and free-turning sleeve allow for rapid rotation when used as a screwdriver.



Zyklop Speed Ratchet and Socket Sets



1/4 inch Drive Imperial Ratchet Sets

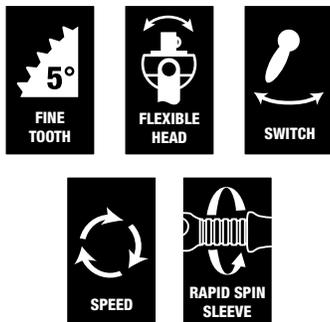

1/4 inch Drive Imperial Ratchet Sets		
Part Number	Description	Price
05003535055	Wera driver bit and socket set with Zyklop Speed ratchet, 1/4 inch drive, SAE. 41 pieces. Sturdy metal case included. Manufacturer part number: 003535.	\$285.00

Note: Screwdriver bits and bit-holders are warranted against manufacturer defect.

Wera driver bit and socket set with Zyklop Speed ratchet, 1/4 inch drive, SAE, 41 pieces. Includes the pieces listed in the table below.



05003535055 Contents		
	1/4 Zyklop Speed ratchet	
	Sliding T-handle	1/4 x 110
	6-point socket, 23mm long	3/16, 7/32, 1/4, 9/32, 5/16, 11/32, 3/8, 7/16, 1/2, 9/16
	Wobble extension	1/4 x 56
	Universal joint	1/4 x 35.5
	Lockable extension	1/4 x 150, 1/4 x 75
	Bit adaptor	1/4 x 37
	Slotted bit, 25mm long	0.6 x 4.5, 1.0 x 5.5, 1.2 x 8.0
	Hex-Plus bit, 25mm long	5/64, 3/32, 1/8, 9/64, 5/32, 3/16, 7/32
	Phillips bit, 25mm long	PH1, PH2, PH3
	Posidriv® bit, 25mm long	PZ1, PZ2, PZ3
	Torx® bit, 25mm long	TX8, TX9, TX10, TX15, TX20, TX25, TX30, TX40


Note: Fractional dimensions are in inches. Whole and decimal dimensions are in millimeters.



Zyklop Speed Ratchet and Socket Sets



1/4 inch Drive Metric Ratchet Sets

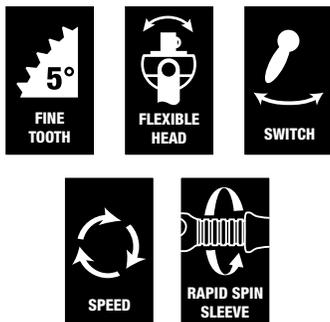

1/4 inch Drive Metric Ratchet Sets		
Part Number	Description	Price
05003533055	Wera driver bit and socket set with Zyklop Speed ratchet, 1/4 inch drive, metric. 42 pieces. Sturdy metal case included. Manufacturer part number 003533.	\$302.00
05051045055	Wera driver bit and socket set with Zyklop Speed ratchet, 1/4 inch drive, metric, 26 pieces. Durable cloth pouch included. Manufacturer part number 051045.	\$134.00

Note: Screwdriver bits and bit-holders are warranted against manufacturer defect only.



Wera driver bit and socket set with Zyklop Speed ratchet, 1/4 inch drive, metric, 42 pieces. Includes the pieces listed in the table below.

05003533055 Contents		
	1/4 Zyklop Speed ratchet	
	Sliding T-handle	1/4 x 110
	6-point socket, 23mm long	4, 4.5, 5, 5.5, 6, 7, 8, 9, 10, 11, 12, 13, 14
	Wobble extension	1/4 x 56
	Universal joint	1/4 x 35.5
	Lockable extension	1/4 x 75, 1/4 x 150
	Bit adaptor	1/4 x 37
	Slotted bit, 25mm long	0.6 x 4.5, 1.0 x 5.5, 1.2 x 8
	Hex-Plus bit, 25mm long	3, 4, 5, 6, 8
	Phillips bit, 25mm long	PH1, PH2, PH3
	Posidriv® bit, 25mm long	PZ1, PZ2, PZ3
	Torx® bit, 25mm long	TX8, TX9, TX10, TX15, TX20, TX25, TX30, TX40

Note: Fractional dimensions are in inches. Whole and decimal dimensions are in millimeters.



Wera driver bit and socket set with Zyklop Speed ratchet, 1/4 inch drive, metric, 26 pieces. Includes the pieces listed in the table below.

05051045055 Contents		
	1/4 Zyklop Speed ratchet	
	6-point socket	5.5, 6, 7, 8, 10, 12, 13
	Lockable extension	1/4 x 150
	Bit adaptor	1/4 x 37
	Slotted bit	1.0 x 5.5 x 50
	Hex-Plus bit, 50mm long	3, 4, 5, 6
	Phillips bit, 50mm long	PH1, PH2, PH3
	Posidriv® bit, 50mm long	PZ1, PZ2
	Torx® bit, 50mm long	TX10, TX15, TX20, TX25, TX30, TX40

Note: Fractional dimensions are in inches. Whole and decimal dimensions are in millimeters.