



Zyklop Speed Ratchet



Small return angle

The fine 72 tooth ratchet mechanism has a low return angle of 5°. This short stroke allows fast and precise work in small spaces.



Swivel ratchet head


The ratchet head pivots freely and locks at 0°, 15° and 90°, making it possible to work in confined spaces with ample hand clearance.



Simple direction change

Rotating the large thumbwheel quickly changes rotation from clockwise to counterclockwise from any position of the ratchet head.

Wera Speed Ratchets		
Part Number	Description	Price
0500350055	Wera Zyklop Speed ratchet, 1/4 inch drive, with locking swivel head and ergonomic grip handle. Manufacturer part number 003500.	\$81.00
0500355055	Wera Zyklop Speed ratchet, 3/8 inch drive, with locking swivel head and ergonomic grip handle. Manufacturer part number 003550.	\$90.00
0500360055	Wera Zyklop Speed ratchet, 1/2 inch drive, with locking swivel head and ergonomic grip handle. Manufacturer part number 003600.	\$99.00

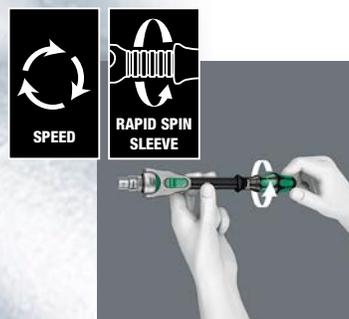

Unbelievably fast


The gyrating mass design along with the Kraftform handle and free-turning sleeve allow for rapid rotation when used as a screwdriver.



Zyklop Speed Ratchet and Socket Sets



1/2 inch Drive Ratchet Sets

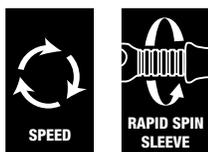

1/2 inch Drive Ratchet Sets		
Part Number	Description	Price
05003647055	Wera driver bit and socket set with Zyklop Speed ratchet, 1/2 inch drive, SAE. 38 pieces. Sturdy metal case included. Manufacturer part number 003647.	\$501.00
05003645055	Wera driver bit and socket set with Zyklop Speed ratchet, 1/2 inch drive, metric. 37 pieces. Sturdy metal case included. Manufacturer part number 003645.	\$495.00

Note: Screwdriver bits and bit-holders are warranted against manufacturer defect.



Wera driver bit and socket set with Zyklop Speed ratchet, 1/2 inch drive, SAE, 38 pieces. Includes the pieces listed in the table below.



Wera driver bit and socket set with Zyklop Speed ratchet, 1/2 inch drive, metric, 37 pieces. Includes the pieces listed in the table below.

05003647055 Contents		
	1/2 Zyklop Speed ratchet	
	Sliding T-handle	1/2 x 10
	6-point socket	3/8 x 37, 7/16 x 37, 1/2 x 37, 9/16 x 37, 19/32 x 37, 5/8 x 37, 11/16 x 37, 3/4 x 37, 25/32 x 37, 13/16 x 37, 7/8 x 37, 15/16 x 37, 31/32 x 37, 1 x 40, 1-1/16 x 40, 1-1/8 x 40, 1-3/16 x 42, 1-1/4 x 42
	Wobble extension	1/2 x 52
	Universal joint	1/2 x 69
	Lockable extension	1/2 x 250, 1/2 x 125
	Bit adapter	5/16 x 1/2 x 50
	Hex-Plus bit, 30mm long	7/32, 1/4, 5/16, 3/8
	Phillips bit, 35mm long	PH3 x 32
	Posidriv® bit, 35mm long	PZ3 x 32
	Torx® bit, 35mm long	TX20, TX25, TX30, TX40, TX45, TX50, TX55

05003645055 Contents		
	1/2 Zyklop Speed ratchet	
	Sliding T-handle	1/2 x 250
	6-point socket	10 x 37, 11 x 37, 12 x 37, 13 x 37, 14 x 37, 15 x 37, 16 x 37, 17 x 37, 18 x 37, 19 x 37, 20 x 37, 21 x 37, 22 x 37, 24 x 37, 27 x 42, 30 x 42, 32 x 42
	Wobble extension	1/2 x 52
	Universal joint	1/2 x 69
	Lockable extension	1/2 x 250, 1/2 x 125
	Bit adapter	5/16 x 1/2 x 50
	Hex-Plus bit, 30mm long	5, 6, 8, 10
	Phillips bit, 30mm long	PH3 x 32
	Posidriv® bit, 30mm long	PZ3 x 32
	Torx® bit, 35mm long	TX20, TX25, TX30, TX40, TX45, TX50, TX55

Note: Fractional dimensions are in inches. Whole and decimal dimensions are in millimeters.