



Zyklop Mini Ratchet

The Wera Zyklop mini bit ratchet is designed for easy, flexible fastening using 1/4" bits and sockets. Its compact design features a small 6° return angle, a thumbwheel for quick operation and a switch lever for convenient direction change. It's constructed of chrome vanadium steel with a brushed chrome-plated finish for corrosion protection.

Wera Zyklop Mini Bit Ratchet		
Part Number	Description	Price
05073230055	Wera Zyklop Mini bit ratchet, 1/4 inch drive, 6 degree return angle. Adapter for 1/4-inch sockets included. Manufacturer part number 073230.	\$38.50



Thumbwheel




Switch Lever



Small return angle



Wera Zyklop Mini Bit Ratchet Sets

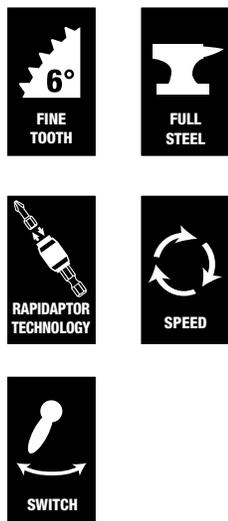

Zyklop Mini Bit Ratchet Sets		
Part Number	Description	Price
05073220055	Wera Tool-Check driver bit and socket set with Zyklop Mini bit ratchet, 1/4 inch drive, metric. 38 pieces. Plastic case included. Manufacturer part number 073220.	\$108.00
TW-DB-SET-28R	Wera Bit-Check driver bit set with Zyklop Mini bit ratchet, 1/4 inch drive, SAE. 31 pieces. Plastic case included. Manufacturer part number 346293.	\$81.00

Note: Screwdriver bits are warranted against manufacturer defect.



Wera Tool-Check driver bit and socket set with Zyklop Mini bit ratchet, 1/4 inch drive, SAE, 38 pieces. Includes the pieces listed in the table below.

Wera Bit-Check driver bit set with Zyklop Mini bit ratchet, 1/4 inch drive, SAE, 31 pieces. Includes the pieces listed in the table below.

05073220055 Contents		
Zyklop Mini bit ratchet		
	Rapidaptor bit holder	1/4 x 50
	1/4 socket adaptor	1/4 x 25
	Slotted	1.0 x 5.5 x 25
	Hex-Plus bit, 25mm long	3, 4, 5, 6, 8
	Phillips bit, 25mm long	(2) PH1, (3) PH2, PH3
	Torx® bit, 25mm long	TX10, TX15, TX20, TX25, TX30, TX40
	Tamper-proof Torx® bit, 25mm long	TX10, TX15, TX20, TX25, TX30
	Posidriv® bit, 25mm long	PZ1, (3) PZ2, PZ3
	6-point socket	5.5, 6.0, 7.0, 8.0 10.0, 12.0, 13.0

TW-DB-SET-28R Contents		
Zyklop Mini bit ratchet		
	1/4 Rapidaptor bit holder	1/4 x 50
	1/4 socket adaptor	1/4 x 25
	Phillips bit, 25mm long	(2) PH1, (3) PH2, PH3
	Torx® bit, 25mm long	TX10, TX15, TX20, TX25, TX30, TX40
	Tamper-proof Torx® bit, 25mm long	TX10, TX15, TX20, TX25, TX30
	Slotted bit	1.0 x 5.5 x 25
	Hex-Plus bit, 25mm long	3/32, 1/8, 5/32, 3/16, 1/4
	Square bit, 25mm long	#1, (3) #2, #3

Note: Fractional dimensions are in inches. Whole and decimal dimensions are in millimeters.