



Wesco Industrial Products, Inc.

1250 Welsh Rd

North Wales, PA 19454

Phone: 800.445.5681 • Fax: 800.346.5511

Email: info@wescomfg.com

PART NO. 260035, WESCO® FORK STACKER MODEL



- **1-year warranty.**
- 1" thick x 3" wide x 25" long forks.
- Adjustable span up to 25".
- 15" load center.
- 25.5" overall width; 40" depth.
- Base leg span - 15" inside, 21" outside.
- Forks lower to ground.
- **Wesco® manufactured hydraulic Stacker Jack, over 35 year of proven quality.**

[Specifications](#) | [Stacker Low Profile Outrigger Option](#)

Specifications

PART NUMBER	260035
MODEL	SFL-56-25
CAPACITY	1000 lb
TYPE	Standard
LIFT HEIGHT	56"
WIDTH FORKS	3"
LENGTH FORKS	25"
THICKNESS FORKS	1"
LOAD CENTER	15"
INSIDE BASE LEG	15"



OUTSIDE BASE LEG

21"

ADJUSTABLE FORK SPAN

up to 25"

OVERALL WIDTH

25.5"

OVERALL HEIGHT

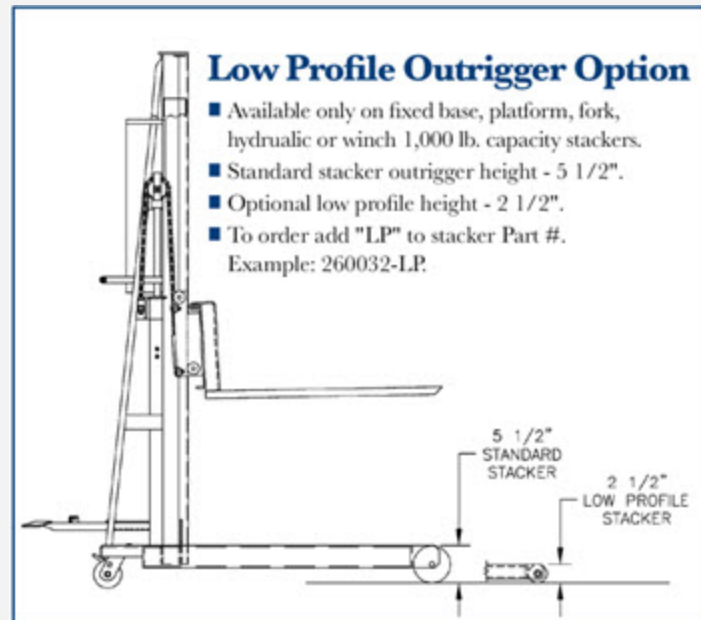
75"

OVERALL DEPTH

44.5"

WEIGHT

265 lb

MADE IN THE USA**Stacker Low Profile Outrigger Option****STACKER LOW PROFILE OUTRIGGER OPTION**

Stacker Low Profile Outrigger Option