



1250 Welsh Rd

North Wales, PA 19454

Phone: 800.445.5681 • Fax: 800.346.5511

Email: info@wescomfg.com

PART NO. 260036, WESCO® FORK STACKER MODEL



- **1-year warranty.**
- 1" thick x 3" wide x 25" long forks.
- Adjustable span up to 25".
- 15" load center.
- 25.5" overall width; 40" depth.
- Base leg span - 15" inside, 21" outside.
- Forks lower to ground.
- **Wesco® manufactured hydraulic Stacker Jack, over 35 years of proven quality.**

[Specifications](#) | [Stacker Low Profile Outrigger Option](#)

Specifications

PART NUMBER	260036
MODEL	SFL-64-25
CAPACITY	1000 lb
TYPE	Standard
LIFT HEIGHT	64"
WIDTH FORKS	3"
LENGTH FORKS	25"
THICKNESS FORKS	1"
LOAD CENTER	15"
INSIDE BASE LEG	15"




OUTSIDE BASE LEG	21"
ADJUSTABLE FORK SPAN	up to 25"
OVERALL WIDTH	25.5"
OVERALL HEIGHT	83"
OVERALL DEPTH	44.5"
WEIGHT	273 lb

MADE IN THE USA



Stacker Low Profile Outrigger Option

STACKER LOW PROFILE OUTRIGGER OPTION

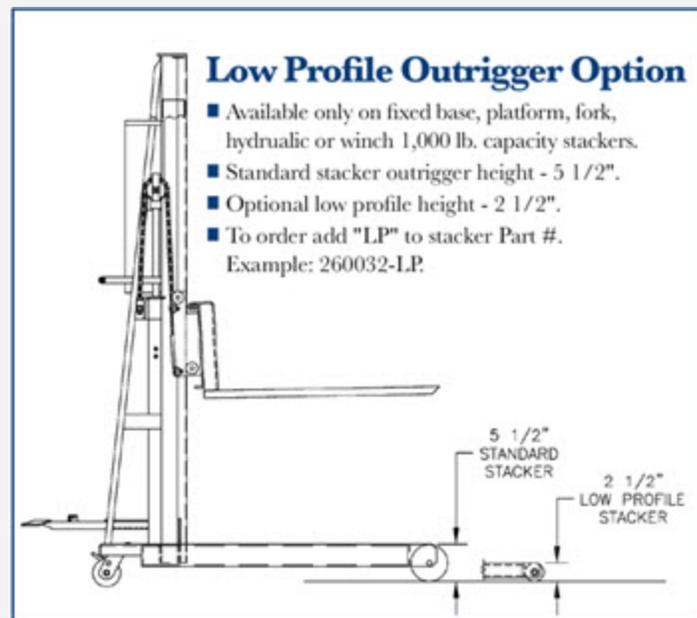

Stacker Low Profile Outrigger Option