



1250 Welsh Rd

North Wales, PA 19454

Phone: 800.445.5681 • **Fax:** 800.346.5511**Email:** info@wescomfg.com

PART NO. 260047, WESCO® FORK STACKER MODEL



- **1-year warranty.**
- 1" thick x 3" wide x 25" long forks.
- Adjustable span up to 25".
- 15" load center.
- 25.5" overall width; 40" depth.
- Base leg span - 15" inside, 21" outside.
- Forks lower to ground.
- **Wesco® manufactured hydraulic Stacker Jack, over 35 year of proven quality.**

[Specifications](#) | [Stacker Low Profile Outrigger Option](#)

Specifications

PART NUMBER	260047
MODEL	ESFL-56-25
CAPACITY	1000 lb
TYPE	Economy
LIFT HEIGHT	56"
WIDTH FORKS	3"
LENGTH FORKS	25"
THICKNESS FORKS	1"
LOAD CENTER	15"
INSIDE BASE LEG	15"




OUTSIDE BASE LEG	21"
ADJUSTABLE FORK SPAN	up to 25"
OVERALL WIDTH	25.5"
OVERALL HEIGHT	72"
OVERALL DEPTH	44"
WEIGHT	258 lb

MADE IN THE USA



Stacker Low Profile Outrigger Option

STACKER LOW PROFILE OUTRIGGER OPTION

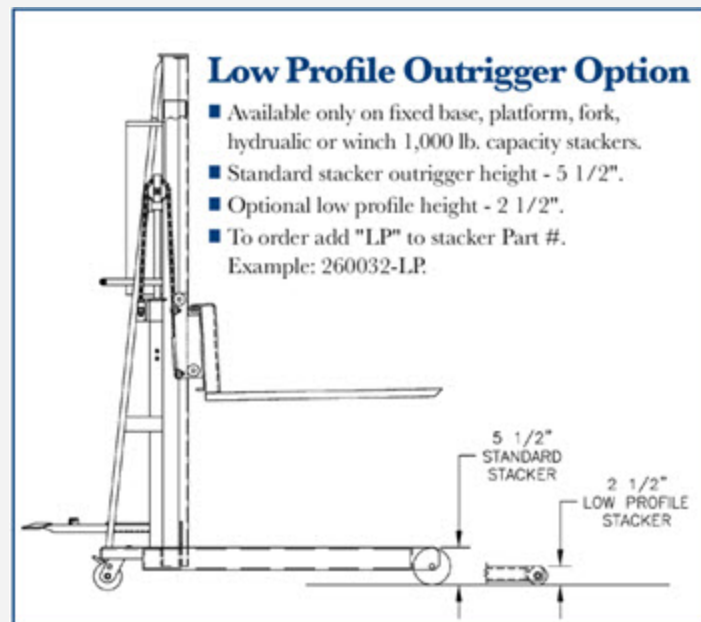

Stacker Low Profile Outrigger Option