



1250 Welsh Rd

North Wales, PA 19454

Phone: 800.445.5681 • Fax: 800.346.5511

Email: info@wescomfg.com

PART NO. 260049, WESCO® FORK STACKER MODEL



- **1-year warranty.**
- 1" thick x 3" wide x 25" long forks.
- Adjustable span up to 25".
- 15" load center.
- 25.5" overall width; 40" depth.
- Base leg span - 15" inside, 21" outside.
- Forks lower to ground.
- **Wesco® manufactured hydraulic Stacker Jack, over 35 year of proven quality.**

[Specifications](#) | [Stacker Low Profile Outrigger Option](#)

Specifications

| | |
|------------------------|------------|
| PART NUMBER | 260049 |
| MODEL | ESFL-76-25 |
| CAPACITY | 1000 lb |
| TYPE | Economy |
| LIFT HEIGHT | 76" |
| WIDTH FORKS | 3" |
| LENGTH FORKS | 25" |
| THICKNESS FORKS | 1" |
| LOAD CENTER | 15" |
| INSIDE BASE LEG | 15" |




| | |
|-----------------------------|-----------|
| OUTSIDE BASE LEG | 21" |
| ADJUSTABLE FORK SPAN | up to 25" |
| OVERALL WIDTH | 25.5" |
| OVERALL HEIGHT | 92" |
| OVERALL DEPTH | 44" |
| WEIGHT | 295 lb |

MADE IN THE USA



Stacker Low Profile Outrigger Option

STACKER LOW PROFILE OUTRIGGER OPTION

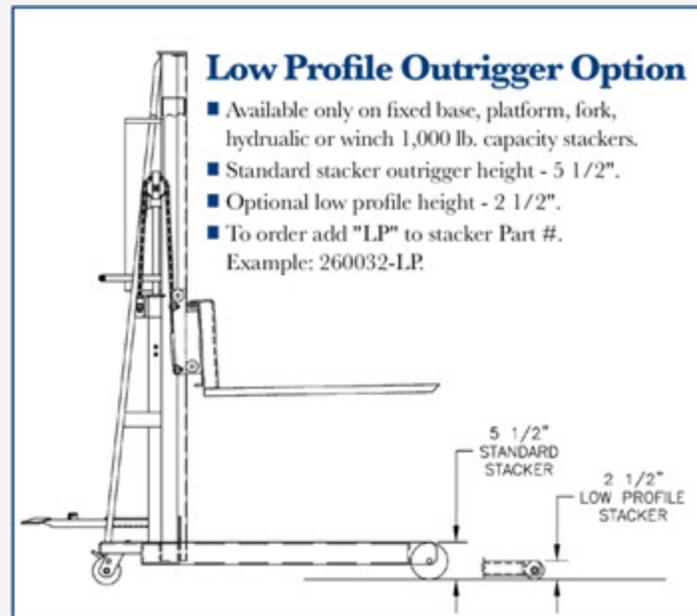

Stacker Low Profile Outrigger Option