



1250 Welsh Rd

North Wales, PA 19454

Phone: 800.445.5681 • Fax: 800.346.5511

Email: info@wescomfg.com

PART NO. 260050, WESCO® LARGE PLATFORM MODEL



- **1-year warranty.**
- Wesco® manufactured hydraulic Stacker Jack, over 35 year of proven quality.
- 30" deep x 32" wide heavy gauge platform with 5.25" lowered height.
- 18" load center.
- Base leg span - 25.5" inside, 32" outside.

[Video](#) | [Specifications](#) | [Stacker Low Profile Outrigger Option](#)

Video



Specifications




PART NUMBER	260050
MODEL	ESPL-60-3032
CAPACITY	1000 lb
TYPE	Economy
LIFT HEIGHT	60"
PLATFORM WIDTH	32"
PLATFORM LENGTH	30"
LOAD CENTER	18"
LOWERED HEIGHT	5.25"
INSIDE BASE LEG	25.5"
OUTSIDE BASE LEG	32"
OVERALL WIDTH	32"
OVERALL HEIGHT	72"
OVERALL DEPTH	44.5"
WEIGHT	265 lb

MADE IN THE USA



Stacker Low Profile Outrigger Option

STACKER LOW PROFILE OUTRIGGER OPTION

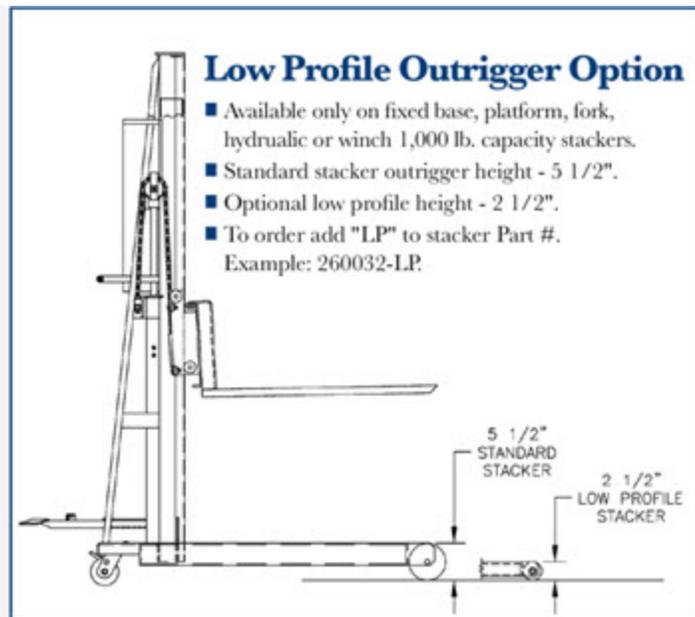

Stacker Low Profile Outrigger Option