



1250 Welsh Rd

North Wales, PA 19454

Phone: 800.445.5681 • **Fax:** 800.346.5511**Email:** info@wescomfg.com

PART NO. 260055, STRADDLE FORK STACKER MODEL



- **1-year warranty.**
- 1" thick x 3" wide x 30" long forks.
- Adjustable span up to 25".
- 18" load center.
- 32" overall width; 44" depth.
- Base leg span - 25.5" inside, 32" outside.
- Forks lower to ground.
- **Wesco® manufactured hydraulic Stacker Jack, over 35 year of proven quality.**

[Specifications](#) | [Stacker Low Profile Outrigger Option](#)

Specifications

PART NUMBER	260055
MODEL	ESFL-76-30S
CAPACITY	1000 lb
TYPE	Economy
LIFT HEIGHT	76"
WIDTH FORKS	3"
LENGTH FORKS	30"
THICKNESS FORKS	1"
LOAD CENTER	18"
INSIDE BASE LEG	25.5"




OUTSIDE BASE LEG	32"
ADJUSTABLE FORK SPAN	up to 25"
OVERALL WIDTH	32.5"
OVERALL HEIGHT	92"
OVERALL DEPTH	48"
WEIGHT	322 lb

MADE IN THE USA



Stacker Low Profile Outrigger Option

STACKER LOW PROFILE OUTRIGGER OPTION

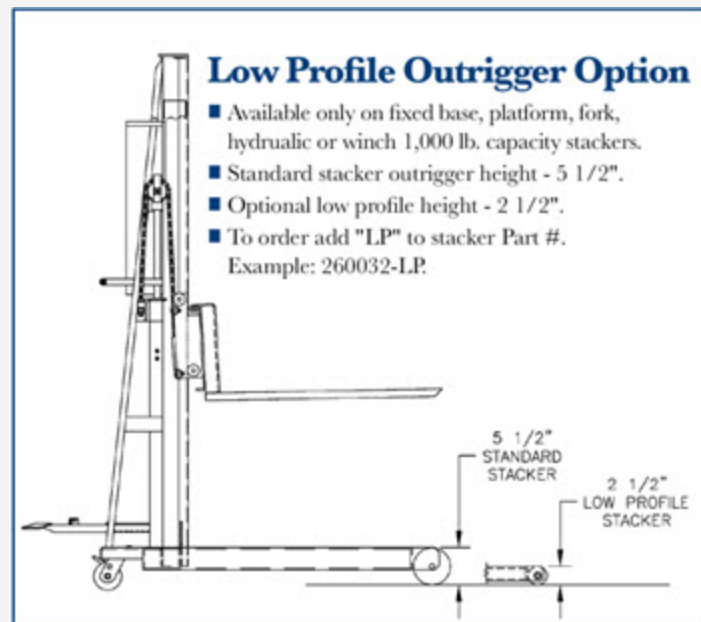

Stacker Low Profile Outrigger Option