




1250 Welsh Rd

North Wales, PA 19454

Phone: 800.445.5681 • Fax: 800.346.5511

Email: info@wescomfg.com

PART NO. 260075, WIDE STRADDLE FORK STACKER MODEL

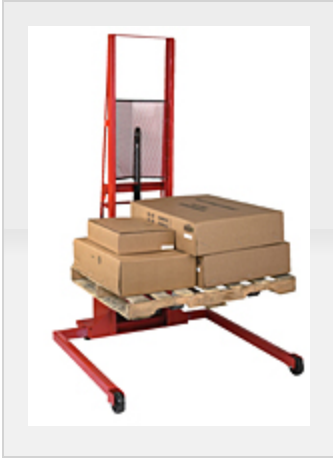

- **1-year warranty.**
- Base leg span - 42" inside, 48.75" outside.
- 1" thick by 3" wide by 30" long forks adjustable span.
- Overall width 48.75", depth 48.25".
- Forks lower to the ground.
- **Wesco® manufactured hydraulic Stacker Jack, over 35 year of proven quality.**

Specifications

PART NUMBER	260075
MODEL	ESFL-56-30-42S
CAPACITY	1000 lb
TYPE	Wide
LIFT HEIGHT	56"
WIDTH FORKS	3"
LENGTH FORKS	30"
THICKNESS FORKS	1"
LOAD CENTER	18"
INSIDE BASE LEG	42"
OUTSIDE BASE LEG	48.75"



ADJUSTABLE FORK SPAN	25"
OVERALL WIDTH	48.5"
OVERALL HEIGHT	72.5"
OVERALL DEPTH	49"
WEIGHT	352 lb

MADE IN THE USA

