




Wesco Industrial Products, Inc.

1250 Welsh Rd
North Wales, PA 19454

Phone: 800.445.5681 • **Fax:** 800.346.5511

Email: info@wescomfg.com

PART NO. 261025, 32" X 30" PLATFORM FIXED BASE POWERED STACKER

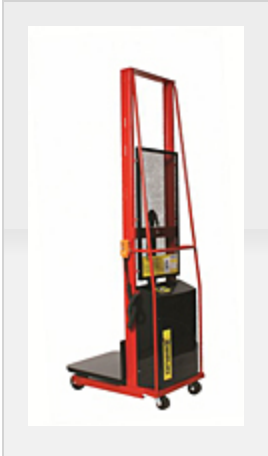

- 1-year warranty.
- Proven quality: Wesco® manufactured Hydraulic Cylinder.
- Battery and charger included.
- 110V AC models available. (Special order, NO cancellations or returns.)
- To order add AC to the end of the battery powered stacker part #.

Example:

Battery Powered #261025

110V AC Powered #261025AC

- Meets ANSI B56.10 specifications.
- Power Drive option available.

[Video](#) | [Specifications](#) | [5th Wheel Steering Option](#) | [Stacker Low Profile Outrigger Option](#)

Video



Specifications



PART NUMBER	261025
MODEL	PESPL-60-3032
TYPE	32" x 30" Platform Models
FRONT WHEEL	(2) 5" Phenolic
REAR SWIVEL CASTER	(2) 4" Phenolic
LIFT HEIGHT	60"
CAPACITY	1000 lb
PLATFORM WIDTH	32"
PLATFORM LENGTH	30"
LOAD CENTER	18"
LOWERED HEIGHT	5.75"
BASE LEG (ID/OD)	25.5"/32"
OVERALL WIDTH	32"
OVERALL HEIGHT	72"
OVERALL DEPTH	43.5"
WEIGHT	404 lb
MADE IN THE USA	

5th Wheel Steering Option

5TH WHEEL STEERING OPTION




5th Wheel Steering Option for easier mobility & precision steering in confined areas
Available only on 1,500 and 2,000 lb models.
8" locking polyurethane wheels. Spring loaded handle. Can be field installed.
Order as separate option under Part # 261099

Look

5th wheel steering option

Stacker Low Profile Outrigger Option

STACKER LOW PROFILE OUTRIGGER OPTION

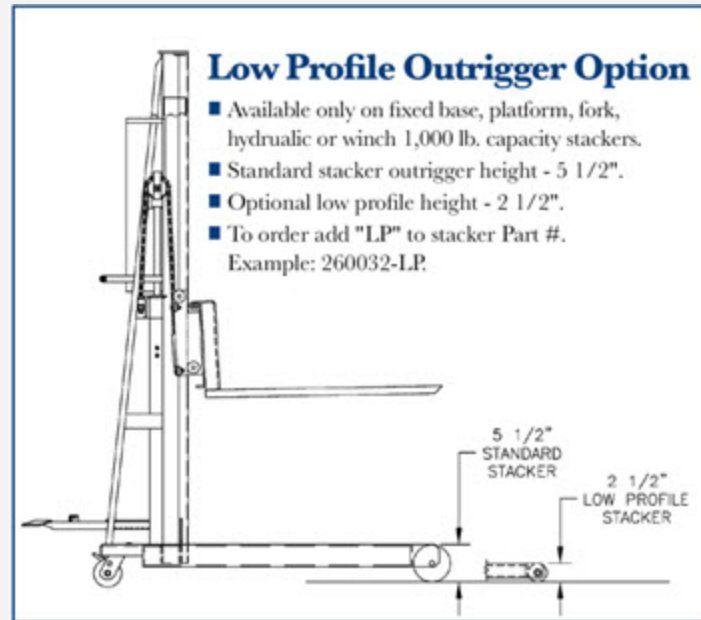

Stacker Low Profile Outrigger Option