



1250 Welsh Rd

North Wales, PA 19454

Phone: 800.445.5681 • Fax: 800.346.5511

Email: info@wescomfg.com

PART NO. 261030, 3" X 25" FORK FIXED BASE POWERED STACKER



- 1-year warranty.
- Proven quality: Wesco® manufactured Hydraulic Cylinder.
- Battery and charger included.
- Forks lower to floor on all models.
- 5" Phenolic wheels on front, 4" swivel on rear
- 110V AC models available. (Special order, NO cancellations or returns.)
- To order add AC to the end of the battery powered stacker part #.

Example:

Battery Powered #261030

110V AC Powered #261030AC

- Meets ANSI B56.10 specifications.
- Power Drive option available.

[Video](#) | [Specifications](#) | [5th Wheel Steering Option](#) | [Stacker Low Profile Outtrigger Option](#)

Video



Specifications



PART NUMBER	261030
MODEL	PESFL-76-25
TYPE	Fork Models
FRONT WHEEL	(2) 5" Phenolic
REAR SWIVEL CASTER	(2) 4" Phenolic
LIFT HEIGHT	76"
CAPACITY	1000 lb
WIDTH FORKS	3"
LENGTH FORKS	25"
LOAD CENTER	15"
BASE LEG (ID/OD)	15"/21"
OVERALL WIDTH	25.5"
OVERALL HEIGHT	92"
OVERALL DEPTH	44.5"
WEIGHT	489 lb

MADE IN THE USA

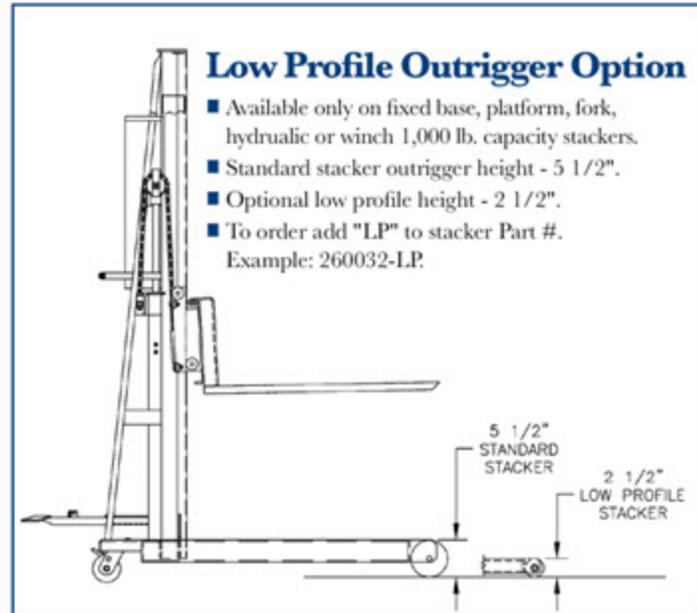


5th Wheel Steering Option

5TH WHEEL STEERING OPTION



5th Wheel Steering Option for easier mobility & precision steering in confined areas. Available only on 1,500 and 2,000 lb models. 8" locking polyurethane wheels. Spring loader handle. Can be field installed. Order as separate option under Part # 261099

Stacker Low Profile Outrigger Option**STACKER LOW PROFILE OUTRIGGER OPTION**

Stacker Low Profile Outrigger Option