




Wesco Industrial Products, Inc.

1250 Welsh Rd
North Wales, PA 19454
Phone: 800.445.5681 • **Fax:** 800.346.5511
Email: info@wescomfg.com

PART NO. 261073, 30" X 32" PLATFORM 36" O.D. FIXED BASE LIFT POWERED STACK

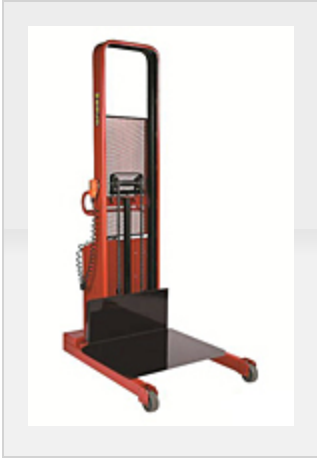

- 1-year warranty.
- Proven quality: Wesco® manufactured Hydraulic Cylinder.
- Meets ANSI B56.10 specifications.
- Battery and charger included.
- Platform lowered height 6".
- Reinforced frame and base
- Double chain, lift support.
- Heavy-duty pump.
- Ergonomic "D" handles.
- 5th wheel and power drive options available.
- 110V AC models available (Special order no cancellations or returns).
- To order add AC to the end of the battery powered stacker part #.

Example:

Battery Powered #261073
110V AC Powered #261073AC

[Video](#) | [Specifications](#) | [5th Wheel Steering Option](#)

Video



Specifications

PART NUMBER	261073
MODEL	PSPL-80-3032-30S-1.5K
LIFT HEIGHT	80"
CAPACITY	1500 lb
PLATFORM WIDTH	30"
PLATFORM LENGTH	32"
LOAD CENTER	18"
BASE LEG (ID/OD)	30"/36"
OVERALL HEIGHT	94"
WEIGHT	534 lb
MADE IN THE USA	

5th Wheel Steering Option

5TH WHEEL STEERING OPTION	 5th Wheel Steering Option for easier mobility & precision steering in confined areas. Available only on 1,500 and 2,000 lb models. 8" locking polyurethane wheels. Spring loaded handle. Can be field installed. Order as separate option under Part # 261099 Look 5th wheel steering option
---------------------------	--