




Wesco Industrial Products, Inc.

1250 Welsh Rd
North Wales, PA 19454

Phone: 800.445.5681 • **Fax:** 800.346.5511

Email: info@wescomfg.com

PART NO. 273204, BATTERY OPERATED VALUE LIFT STACKER

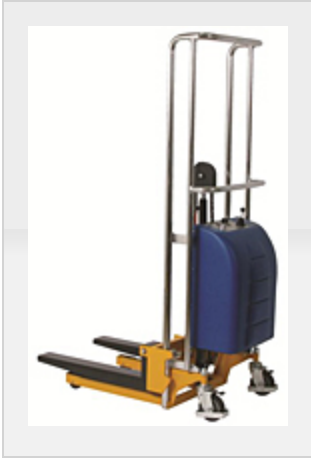

- Adjustable 4" wide x 25.5" long forks.
- Two 5" polyurethane swivel casters with brake and two 3" polyurethane rigid wheels.
- Lift height 59".
- Chrome plated rails and handles.
- UL approved charger.
- Sealed maintenance-free battery.
- Keyed on/off switch.
- Raise/lower control.
- **#272942 Optional Platform fits both Manual and Electric Value Lift Stackers. Optional, removable 22"**
- Adjustable fork width 8.25" to 21.5"

Specifications

PART NUMBER	273204
MODEL	VLP-59
CAPACITY	880 lb
BATTERY	12 V 80 Ah Sealed
SWIVEL CASTER	(2) 5" Locking Polyurethane
LOAD WHEEL	(2) 3" Rigid Polyurethane
LIFT HEIGHT	3.5" to 59"
LOWERED HEIGHT	3.5"
WIDTH FORKS	4"
LENGTH FORKS	25.5"
LOAD CENTER	12.75"



OVERALL WIDTH	22.5"
OVERALL HEIGHT	68"
OVERALL DEPTH	44"
WEIGHT	280 lb