

NEMA 12 and 13 Small Continuous Hinge Wall-Mount



Applications

Intended for use as electrical junction boxes, terminal wiring boxes, and instrument housings. Hinged door provides convenient access. Provides protection from dust, dirt, oil, and water.



Construction

- Bodies fabricated from 14-gauge steel
- Doors fabricated from 16-gauge steel
- Continuously-welded seams ground smooth, less knockouts or holes
- Lids are sealed with closed-cell oil-resistant neoprene gasket
- External mounting plates on top and bottom of enclosure
- Weldnuts provided for mounting optional subpanels securely on models 6 x 4 in [152 x 102 mm] and larger
- External screw clamps are quick and easy to operate
- Standard continuous hinge
- Grounding provisions provided
- Uses WAN12RA clamp

Finish


- ANSI 61 gray polyester powder light texture inside and out over phosphatized surfaces

Listings

- UL 50, 12 and 13 [UL Files E6924]
- NEMA/EEMAC 12 and 13
- JIC EL-1-71



Dimensions

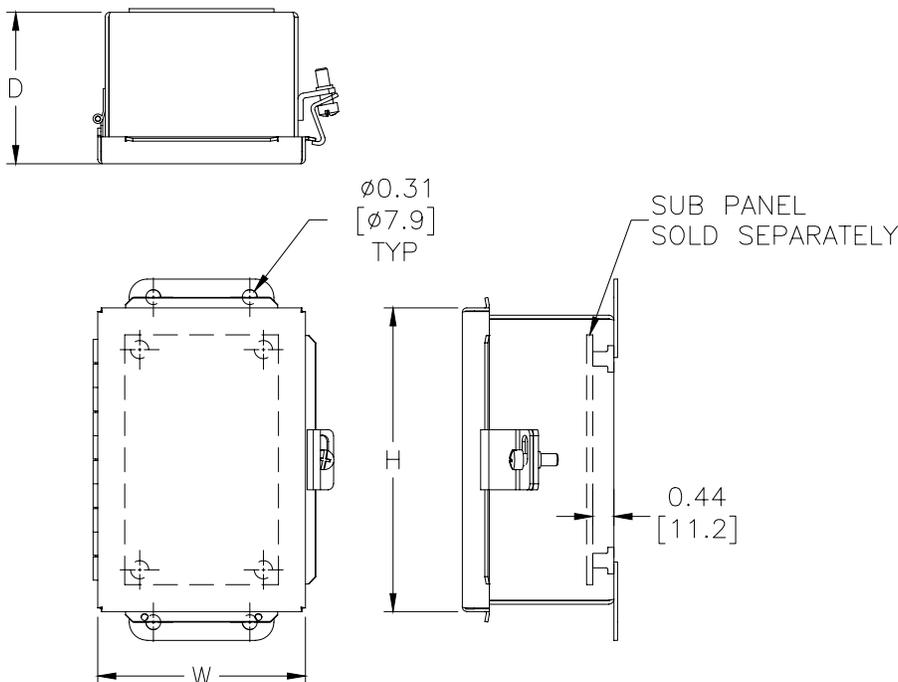

NOTES:

1. PANELS ARE 14GA STEEL.
2. PANEL SCREWS ARE #10-32 PAN HEAD.
3. TWO CLAMPS ARE USED IF $W=8$ " OR MORE.

NEMA 12 and 13 Small Continuous Hinge Wall-Mount



Shipping Schedule

Same day 1 - 5 days 1 - 7 days 1 - 15 days 1 - 20 days

Color indicates shipping lead time in business days.

NEMA 12 and 13 Small Continuous Hinge Wall-Mount

Part Number	Price	Enclosure SizeHxWxD	Painted Steel Subpanel	Stainless Steel Subpanel	Galvanized Steel Subpanel
B040403CH	\$63.00	4.31 x 4.31 x 3.14 [109 x 109 x 80]	—	—	—
B040404CH	\$65.00	4.31 x 4.31 x 4.14 [109 x 109 x 105]	—	—	—
B060403CH	\$72.00	6.31 x 4.31 x 3.14 [160 x 109 x 80]	P0604	P0604SS	P0604G
B060404CH	\$76.00	6.31 x 4.31 x 4.14 [160 x 109 x 105]	P0604	P0604SS	P0604G
B060604CH	\$81.00	6.31 x 6.31 x 4.14 [160 x 160 x 105]	P0606	P0606SS	P0606G
B080603CH	\$86.00	8.31 x 6.31 x 3.64 [211 x 160 x 92]	P0806	P0806SS	P0806G
B080606CH	\$102.00	8.31 x 6.31 x 6.14 [211 x 160 x 156]	P0806	P0806SS	P0806G
B080804CH	\$98.00	8.31 x 8.31 x 4.14 [211 x 211 x 105]	P0808	—	P0808G
B100804CH	\$107.00	10.31 x 8.31 x 4.14 [262 x 211 x 105]	P1008	P1008SS	P1008G
B100804CHS	\$106.00	8.31 x 10.31 x 4.14 [211 x 262 x 105]	P1008	P1008SS	P1008G
B100806CH	\$121.00	10.31 x 8.31 x 6.14 [262 x 211 x 156]	P1008	P1008SS	P1008G
B101006CH	\$133.00	10.31 x 10.31 x 6.14 [262 x 262 x 156]	P1010	—	P1010G
B120604CH	\$107.00	12.31 x 6.31 x 4.14 [313 x 160 x 105]	P1206	—	P1206G
B121005CH	\$137.00	12.31 x 10.31 x 5.14 [313 x 262 x 131]	P1210	P1210SS	P1210G
B121005CHS	\$135.00	10.31 x 12.31 x 5.14 [262 x 313 x 131]	P1210	P1210SS	P1210G
B121008CH	\$167.00	12.31 x 10.31 x 8.14 [313 x 262 x 207]	P1210	P1210SS	P1210G
B121206CH	\$159.00	12.31 x 12.31 x 6.14 [313 x 313 x 156]	P1212	P1212SS	P1212G
B140806CH	\$146.00	14.31 x 8.31 x 6.14 [363 x 211 x 156]	P1408	—	P1408G
B141206CH	\$176.00	14.31 x 12.31 x 6.14 [363 x 313 x 156]	P1412	P1412SS	P1412G
B141206CHS	\$171.00	12.31 x 14.31 x 6.14 [313 x 363 x 156]	P1412	P1412SS	P1412G
B141208CH	\$198.00	14.31 x 12.31 x 8.14 [363 x 313 x 207]	P1412	P1412SS	P1412G
B161006CH	\$175.00	16.31 x 10.31 x 6.14 [414 x 262 x 156]	P1610	—	P1610G
B161406CH	\$204.00	16.31 x 14.31 x 6.14 [414 x 363 x 156]	P1614	P1614SS	P1614G
B161406CHS	\$202.00	14.31 x 16.31 x 6.14 [363 x 414 x 156]	P1614	P1614SS	P1614G
B161408CH	\$226.00	16.31 x 14.31 x 8.14 [414 x 363 x 207]	P1614	P1614SS	P1614G
B161410CH	\$256.00	16.31 x 14.31 x 10.14 [414 x 363 x 258]	P1614	P1614SS	P1614G

Notes: Subpanels must be ordered separately.

Dimensions in inches [millimeters].

Letters in table correspond to letters on dimensional drawings.

Enclosure Subpanels



Subpanels

Subpanels are not included with most enclosures and must be purchased separately.

The specifications table for each enclosure family list the part number of the subpanel that goes with each enclosure.

Subpanels for Small NEMA 12 (B) and NEMA 4 (BN4) Enclosures

- 14-gauge (painted, stainless, and galvanized)
- Painted steel subpanels are white polyester powder over phosphatized surfaces
- Galvanized subpanels have a conductive finish (no paint)
- Subpanels fit the following enclosures: B, B_CH, BN4, BN4_CH, BN4_CHQT, BN4_SS, BN4_CHSS, BN4_CHSSA, BN4_CHQTSS, BN4_CHQTSSA ("_" refers to dimensions).



Shipping Schedule

Same day 1 - 5 days 1 - 7 days 1 - 15 days 1 - 20 days

Color indicates shipping lead time in business days.

Subpanels for B and BN4 Enclosures

Painted Steel	Price	304 Stainless Steel	Price	Galvanized	Price	Nominal Enclosure Size HxW	Subpanel Size AxB
P0604	\$5.00	P0604SS	\$16.75	P0604G	\$5.00	6 x 4	4.88 x 2.88 [124 x 73]
P0606	\$6.00	P0606SS	\$20.50	P0606G	\$6.00	6 x 6	4.88 x 4.88 [124 x 124]
P0806	\$6.75	P0806SS	\$24.50	P0806G	\$6.75	8 x 6	6.88 x 4.88 [175 x 124]
P0808	\$8.00	—	—	P0808G	\$8.00	8 x 8	6.88 x 6.88 [175 x 175]
P1008	\$8.75	P1008SS	\$35.50	P1008G	\$8.75	10 x 8	8.88 x 6.88 [226 x 175]
P1010	\$11.00	—	—	P1010G	\$11.00	10 x 10	8.88 x 8.88 [226 x 226]
P1206	\$8.75	—	—	P1206G	\$8.75	12 x 6	10.88 x 4.88 [276 x 124]
P1210	\$12.75	P1210SS	\$50.00	P1210G	\$12.75	12 x 10	10.88 x 8.88 [276 x 226]
P1212	\$15.00	P1212SS	\$58.00	P1212G	\$15.00	12 x 12	10.88 x 10.88 [276 x 276]
P1408	\$12.00	—	—	P1408G	\$12.00	14 x 8	12.88 x 6.88 [327 x 175]
P1412	\$16.50	P1412SS	\$67.00	P1412G	\$16.50	14 x 12	12.88 x 10.88 [327 x 276]
P1610	\$16.25	—	—	P1610G	\$16.25	16 x 10	14.88 x 8.88 [378 x 226]
P1614	\$22.00	P1614SS	\$88.00	P1614G	\$22.00	16 x 14	14.88 x 12.88 [378 x 327]

Notes: Dimensions in inches [millimeters].
Letters in table correspond to letters on dimensional drawing.

Dimensions

