

# NEMA 4, 4X, 12, and 13 Aluminum Lift-Off Cover Wall-Mount



## Applications

Designed as an instrument housing or junction box for electrical, electronic, or pneumatic components. It is ideal for applications where a lightweight, corrosion resistant enclosure is required.

## Construction

- Bodies and doors fabricated from 0.08 in [2mm] thick 5052-H32 aluminum
- Continuously-welded seams ground smooth
- Closed-cell oil-resistant neoprene gasket
- External mounting plate, top and bottom of enclosure
- Weldnuts are provided to secure optional subpanel
- Stainless steel screws and clamps on four sides of cover to assure water tight seal
- Optional subpanels and terminal kits must be ordered separately
- Grounding provisions provided
- Uses WABN4JIC clamp

## Finish

- Exterior and doors of enclosures have a smooth-grained finish

## Listings

- UL 50, 4, 4X, 12, and 13
- NEMA/EEMAC 4, 4X, 12, and 13
- JIC EL-1-71
- UL File E6924, E23553



Note: For current listings, please see [www.automationdirect.com](http://www.automationdirect.com)

## Shipping Schedule

Same day 1 - 5 days 1 - 7 days 1 - 15 days 1 - 20 days

Color indicates shipping lead time in business days.

## NEMA 4, 4X, 12, and 13 Aluminum Lift-Off Cover Wall-Mount Enclosures


| Part Number                 | Price    | Enclosure SizeHxWxD                    | Painted Steel Subpanel | Stainless Steel Subpanel | Galvanized Subpanel    |
|-----------------------------|----------|----------------------------------------|------------------------|--------------------------|------------------------|
| <a href="#">BN4060403AL</a> | \$201.00 | 6.31 x 4.31 x 3.26 [160 x 109 x 83]    | <a href="#">P0604</a>  | <a href="#">P0604SS</a>  | <a href="#">P0604G</a> |
| <a href="#">BN4060604AL</a> | \$225.00 | 6.31 x 6.31 x 4.26 [160 x 160 x 108]   | <a href="#">P0606</a>  | <a href="#">P0606SS</a>  | <a href="#">P0606G</a> |
| <a href="#">BN4080603AL</a> | \$235.00 | 8.31 x 6.31 x 3.76 [211 x 160 x 96]    | <a href="#">P0806</a>  | <a href="#">P0806SS</a>  | <a href="#">P0806G</a> |
| <a href="#">BN4100804AL</a> | \$253.00 | 10.31 x 8.31 x 4.26 [262 x 211 x 108]  | <a href="#">P1008</a>  | <a href="#">P1008SS</a>  | <a href="#">P1008G</a> |
| <a href="#">BN4121005AL</a> | \$339.00 | 12.31 x 10.31 x 5.26 [313 x 262 x 134] | <a href="#">P1210</a>  | <a href="#">P1210SS</a>  | <a href="#">P1210G</a> |
| <a href="#">BN4141206AL</a> | \$412.00 | 14.31 x 12.31 x 6.26 [363 x 313 x 159] | <a href="#">P1412</a>  | <a href="#">P1412SS</a>  | <a href="#">P1412G</a> |
| <a href="#">BN4161406AL</a> | \$421.00 | 16.31 x 14.31 x 6.26 [414 x 363 x 159] | <a href="#">P1614</a>  | <a href="#">P1614SS</a>  | <a href="#">P1614G</a> |

Notes: Subpanels must be ordered separately.  
Dimensions in inches [millimeters].  
Letters in table correspond to letters on dimensional drawings.

# NEMA 4, 4X, 12, and 13 Aluminum Lift-Off Cover Wall-Mount



## Dimensions

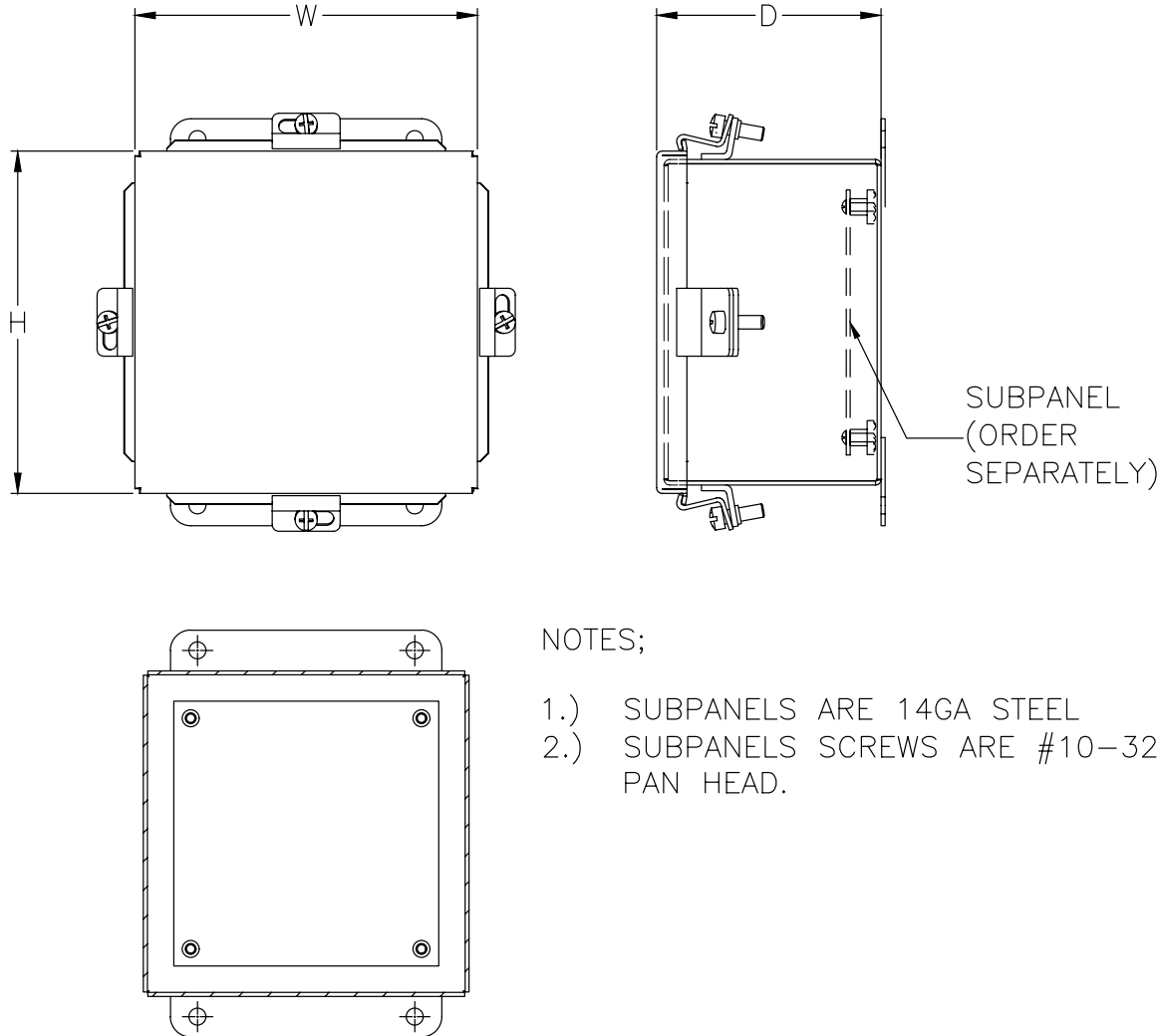

# Enclosure Subpanels



## Subpanels

Subpanels are not included with most enclosures and must be purchased separately.

The specifications table for each enclosure family list the part number of the subpanel that goes with each enclosure.

## Subpanels for Small NEMA 12 (B) and NEMA 4 (BN4) Enclosures

- 14-gauge (painted, stainless, and galvanized)
- Painted steel subpanels are white polyester powder over phosphatized surfaces
- Galvanized subpanels have a conductive finish (no paint)
- Subpanels fit the following enclosures: B, B\_CH, BN4, BN4\_CH, BN4\_CHQT, BN4\_SS, BN4\_CHSS, BN4\_CHSSA, BN4\_CHQTSS, BN4\_CHQTSSA ("\_" refers to dimensions).



### Shipping Schedule

Same day 1 - 5 days 1 - 7 days 1 - 15 days 1 - 20 days

Color indicates shipping lead time in business days.

### Subpanels for B and BN4 Enclosures

| Painted Steel                | Price   | 304 Stainless Steel            | Price   | Galvanized                    | Price   | Nominal Enclosure Size HxW | Subpanel Size AxH         |
|------------------------------|---------|--------------------------------|---------|-------------------------------|---------|----------------------------|---------------------------|
| <a href="#"><u>P0604</u></a> | \$5.00  | <a href="#"><u>P0604SS</u></a> | \$16.75 | <a href="#"><u>P0604G</u></a> | \$5.00  | 6 x 4                      | 4.88 x 2.88 [124 x 73]    |
| <a href="#"><u>P0606</u></a> | \$6.00  | <a href="#"><u>P0606SS</u></a> | \$20.50 | <a href="#"><u>P0606G</u></a> | \$6.00  | 6 x 6                      | 4.88 x 4.88 [124 x 124]   |
| <a href="#"><u>P0806</u></a> | \$6.75  | <a href="#"><u>P0806SS</u></a> | \$24.50 | <a href="#"><u>P0806G</u></a> | \$6.75  | 8 x 6                      | 6.88 x 4.88 [175 x 124]   |
| <a href="#"><u>P0808</u></a> | \$8.00  | —                              | —       | <a href="#"><u>P0808G</u></a> | \$8.00  | 8 x 8                      | 6.88 x 6.88 [175 x 175]   |
| <a href="#"><u>P1008</u></a> | \$8.75  | <a href="#"><u>P1008SS</u></a> | \$35.50 | <a href="#"><u>P1008G</u></a> | \$8.75  | 10 x 8                     | 8.88 x 6.88 [226 x 175]   |
| <a href="#"><u>P1010</u></a> | \$11.00 | —                              | —       | <a href="#"><u>P1010G</u></a> | \$11.00 | 10 x 10                    | 8.88 x 8.88 [226 x 226]   |
| <a href="#"><u>P1206</u></a> | \$8.75  | —                              | —       | <a href="#"><u>P1206G</u></a> | \$8.75  | 12 x 6                     | 10.88 x 4.88 [276 x 124]  |
| <a href="#"><u>P1210</u></a> | \$12.75 | <a href="#"><u>P1210SS</u></a> | \$50.00 | <a href="#"><u>P1210G</u></a> | \$12.75 | 12 x 10                    | 10.88 x 8.88 [276 x 226]  |
| <a href="#"><u>P1212</u></a> | \$15.00 | <a href="#"><u>P1212SS</u></a> | \$58.00 | <a href="#"><u>P1212G</u></a> | \$15.00 | 12 x 12                    | 10.88 x 10.88 [276 x 276] |
| <a href="#"><u>P1408</u></a> | \$12.00 | —                              | —       | <a href="#"><u>P1408G</u></a> | \$12.00 | 14 x 8                     | 12.88 x 6.88 [327 x 175]  |
| <a href="#"><u>P1412</u></a> | \$16.50 | <a href="#"><u>P1412SS</u></a> | \$67.00 | <a href="#"><u>P1412G</u></a> | \$16.50 | 14 x 12                    | 12.88 x 10.88 [327 x 276] |
| <a href="#"><u>P1610</u></a> | \$16.25 | —                              | —       | <a href="#"><u>P1610G</u></a> | \$16.25 | 16 x 10                    | 14.88 x 8.88 [378 x 226]  |
| <a href="#"><u>P1614</u></a> | \$22.00 | <a href="#"><u>P1614SS</u></a> | \$88.00 | <a href="#"><u>P1614G</u></a> | \$22.00 | 16 x 14                    | 14.88 x 12.88 [378 x 327] |

Notes: Dimensions in inches [millimeters].

Letters in table correspond to letters on dimensional drawing.

## Dimensions

