

# NEMA 1 Medium Single-Door Wall-Mount with 1/4-Turn Latch



## Applications

Designed for use in control and instrumentation applications in areas that do not require oil-tight and dust-tight specifications.

## Construction

- Bodies and doors fabricated from 14-gauge steel
- Mounting holes on back of enclosure
- Collar studs provided for mounting optional subpanel
- Doors furnished standard with flush-mount quarter-turn style latch, which can be operated with a coin or screwdriver
- Doors secured by butt hinges
- Grounding provisions provided
- Uses N1C14 series latches

## Finish

- ANSI 61 gray polyester powder light texture inside and out over phosphatized surfaces
- Painted steel and perforated subpanels white polyester powder over phosphatized surfaces

## Listings

- UL 50, 1 [UL File E6924]
- NEMA/EEMAC 1



## Shipping Schedule

Same day 1 - 5 days 1 - 7 days 1 - 15 days 1 - 20 days

Color indicates shipping lead time in business days.

## NEMA 1 Medium Single-Door Wall-Mount with 1/4-Turn Latch

Part Number	Price	Enclosure Size HxWxD	Painted Steel Subpanel	Perforated Subpanel
<a href="#">N1C121606LP</a>	\$196.00	16.41 x 12.38 x 6.86 [417 x 314 x 174]	<a href="#">N1P1216L</a>	<a href="#">N1P1216LP</a>
<a href="#">N1C121608LP</a>	\$214.00	16.41 x 12.38 x 8.86 [417 x 314 x 225]	<a href="#">N1P1216L</a>	<a href="#">N1P1216LP</a>
<a href="#">N1C161606LP</a>	\$219.00	16.41 x 16.38 x 6.86 [417 x 416 x 174]	<a href="#">N1P1616</a>	<a href="#">N1P1616PP</a>
<a href="#">N1C162006LP</a>	\$242.00	20.41 x 16.38 x 6.86 [518 x 416 x 174]	<a href="#">N1P1620</a>	<a href="#">N1P1620PP</a>
<a href="#">N1C162008LP</a>	\$260.00	20.41 x 16.38 x 8.86 [518 x 416 x 225]	<a href="#">N1P1620</a>	<a href="#">N1P1620PP</a>
<a href="#">N1C162406LP</a>	\$264.00	24.41 x 16.38 x 6.86 [620 x 416 x 174]	<a href="#">N1P1624</a>	<a href="#">N1P1624PP</a>
<a href="#">N1C201606LP</a>	\$242.00	16.41 x 20.38 x 6.86 [417 x 518 x 174]	<a href="#">N1P2016</a>	<a href="#">N1P2016PP</a>
<a href="#">N1C202006LP</a>	\$266.00	20.41 x 20.38 x 6.86 [518 x 518 x 174]	<a href="#">N1P2020</a>	<a href="#">N1P2020PP</a>
<a href="#">N1C202008LP</a>	\$291.00	20.41 x 20.38 x 8.86 [518 x 518 x 225]	<a href="#">N1P2020</a>	<a href="#">N1P2020PP</a>
<a href="#">N1C202406LP</a>	\$295.00	24.41 x 20.38 x 6.86 [620 x 518 x 174]	<a href="#">N1P2024</a>	<a href="#">N1P2024PP</a>
<a href="#">N1C202408LP</a>	\$322.00	24.41 x 20.38 x 8.86 [620 x 518 x 225]	<a href="#">N1P2024</a>	<a href="#">N1P2024PP</a>
<a href="#">N1C202410LP</a>	\$340.00	24.41 x 20.38 x 10.86 [620 x 518 x 276]	<a href="#">N1P2024</a>	<a href="#">N1P2024PP</a>
<a href="#">N1C203006LP</a>	\$329.00	30.41 x 20.38 x 6.86 [772 x 518 x 174]	<a href="#">N1P2030</a>	<a href="#">N1P2030PP</a>
<a href="#">N1C242008LP</a>	\$322.00	20.41 x 24.37 x 8.86 [518 x 619 x 225]	<a href="#">N1P2420</a>	<a href="#">N1P2420PP</a>
<a href="#">N1C242406LP</a>	\$324.00	24.41 x 24.37 x 6.86 [620 x 619 x 174]	<a href="#">N1P2424</a>	<a href="#">N1P2424PP</a>
<a href="#">N1C242408LP</a>	\$341.00	24.41 x 24.37 x 8.86 [620 x 619 x 225]	<a href="#">N1P2424</a>	<a href="#">N1P2424PP</a>

Notes: Subpanels must be ordered separately.  
Dimensions in inches [millimeters].

Table continued on next page

# NEMA 1 Medium Single-Door Wall-Mount with 1/4-Turn Latch




Shipping Schedule				
Same day	1 - 5 days	1 - 7 days	1 - 15 days	1 - 20 days
Color indicates shipping lead time in business days.				

Table continued from previous page

NEMA 1 Medium Single-Door Wall-Mount with 1/4-Turn Latch				
Part Number	Price	Enclosure Size HxWxD	Painted Steel Subpanel	Perforated Subpanel
<a href="#">N1C242412LP</a>	\$364.00	24.41 x 24.37 x 12.86 [620 x 619 x 327]	<a href="#">N1P2424</a>	<a href="#">N1P2424PP</a>
<a href="#">N1C243006LP</a>	\$344.00	30.41 x 24.37 x 6.86 [772 x 619 x 174]	<a href="#">N1P2430</a>	<a href="#">N1P2430PP</a>
<a href="#">N1C243008LP</a>	\$366.00	30.41 x 24.37 x 8.86 [772 x 619 x 225]	<a href="#">N1P2430</a>	<a href="#">N1P2430PP</a>
<a href="#">N1C243010LP</a>	\$423.00	30.41 x 24.37 x 10.86 [772 x 619 x 276]	<a href="#">N1P2430</a>	<a href="#">N1P2430PP</a>
<a href="#">N1C243012LP</a>	\$434.00	30.41 x 24.37 x 12.86 [772 x 619 x 327]	<a href="#">N1P2430</a>	<a href="#">N1P2430PP</a>
<a href="#">N1C243606LP</a>	\$386.00	36.41 x 24.37 x 6.86 [925 x 619 x 174]	<a href="#">N1P2436</a>	<a href="#">N1P2436PP</a>
<a href="#">N1C243608LP</a>	\$428.00	36.41 x 24.37 x 8.86 [925 x 619 x 225]	<a href="#">N1P2436</a>	<a href="#">N1P2436PP</a>
<a href="#">N1C303008LP</a>	\$436.00	30.41 x 30.37 x 8.86 [772 x 771 x 225]	<a href="#">N1P3030</a>	<a href="#">N1P3030PP</a>
<a href="#">N1C303606LP</a>	\$439.00	36.41 x 30.37 x 6.86 [925 x 771 x 174]	<a href="#">N1P3036</a>	<a href="#">N1P3036PP</a>
<a href="#">N1C303608LP</a>	\$464.00	36.41 x 30.37 x 8.86 [925 x 771 x 225]	<a href="#">N1P3036</a>	<a href="#">N1P3036PP</a>
<a href="#">N1C303612LP</a>	\$547.00	36.41 x 30.37 x 12.86 [925 x 771 x 327]	<a href="#">N1P3036</a>	<a href="#">N1P3036PP</a>

Notes: Subpanels must be ordered separately.  
Dimensions in inches [millimeters].

## Dimensions

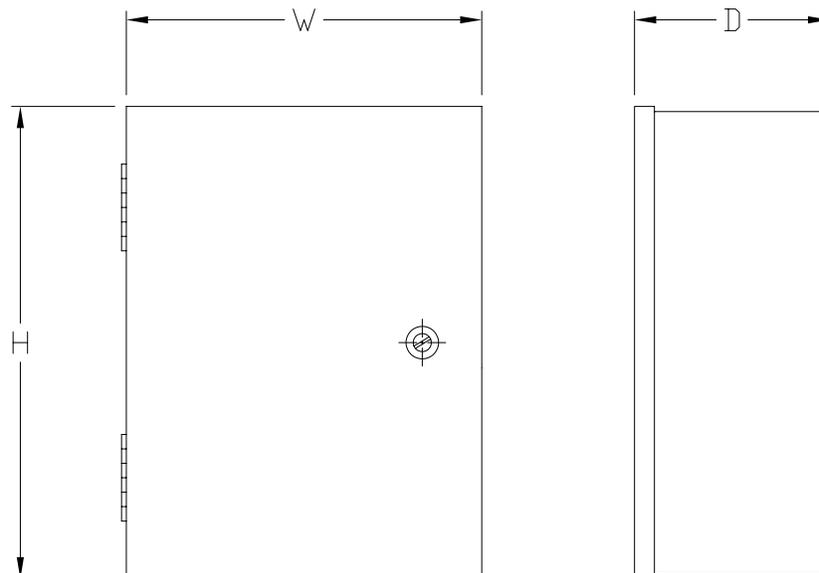

# Enclosure Subpanels



## Subpanels for Medium NEMA 1 Enclosures

- Painted steel and perforated subpanels are painted white polyester powder over phosphatized surfaces
- Panels listed fit NEMA 1 large (N1C) enclosures
- 14 gauge carbon steel
- Perforated panels have 0.13in [3 mm] diameter holes at 0.25in [6 mm] spacing



### Shipping Schedule

Same day	1 - 5 days	1 - 7 days	1 - 15 days	1 - 20 days
----------	------------	------------	-------------	-------------

Color indicates shipping lead time in business days.

### Subpanels for Medium NEMA 1 Enclosures

<i>Painted Steel</i>	<i>Price</i>	<i>Perforated</i>	<i>Price</i>	<i>Steel Gauge</i>	<i>Subpanel Size AxB</i>	<i>Drawing Link</i>
<a href="#"><u>N1P1216L</u></a>	\$17.25	<a href="#"><u>N1P1216LPP</u></a>	\$19.75	14	13.00 x 10.50 [330 x 267]	<a href="#"><u>PDF</u></a>
<a href="#"><u>N1P1616</u></a>	\$21.00	<a href="#"><u>N1P1616PP</u></a>	\$26.50	14	13.00 x 14.50 [330 x 368]	<a href="#"><u>PDF</u></a>
<a href="#"><u>N1P1620</u></a>	\$25.00	<a href="#"><u>N1P1620PP</u></a>	\$29.00	14	17.00 x 14.50 [432 x 368]	<a href="#"><u>PDF</u></a>
<a href="#"><u>N1P1624</u></a>	\$31.00	<a href="#"><u>N1P1624PP</u></a>	\$35.50	14	21.00 x 14.50 [533 x 368]	<a href="#"><u>PDF</u></a>
<a href="#"><u>N1P2016</u></a>	\$25.50	<a href="#"><u>N1P2016PP</u></a>	\$29.50	14	13.00 x 18.50 [330 x 470]	<a href="#"><u>PDF</u></a>
<a href="#"><u>N1P2020</u></a>	\$34.00	<a href="#"><u>N1P2020PP</u></a>	\$39.00	14	17.00 x 18.50 [432 x 470]	<a href="#"><u>PDF</u></a>
<a href="#"><u>N1P2024</u></a>	\$38.50	<a href="#"><u>N1P2024PP</u></a>	\$44.00	14	21.00 x 18.50 [533 x 470]	<a href="#"><u>PDF</u></a>
<a href="#"><u>N1P2030</u></a>	\$83.00	<a href="#"><u>N1P2030PP</u></a>	\$95.00	14	26.00 x 18.50 [660 x 470]	<a href="#"><u>PDF</u></a>
<a href="#"><u>N1P2420</u></a>	\$39.00	<a href="#"><u>N1P2420PP</u></a>	\$45.00	14	17.00 x 22.50 [432 x 572]	<a href="#"><u>PDF</u></a>
<a href="#"><u>N1P2424</u></a>	\$72.00	<a href="#"><u>N1P2424PP</u></a>	\$83.00	14	21.00 x 22.50 [533 x 572]	<a href="#"><u>PDF</u></a>
<a href="#"><u>N1P2430</u></a>	\$96.00	<a href="#"><u>N1P2430PP</u></a>	\$110.00	14	26.00 x 22.50 [660 x 572]	<a href="#"><u>PDF</u></a>
<a href="#"><u>N1P2436</u></a>	\$98.00	<a href="#"><u>N1P2436PP</u></a>	\$113.00	14	32.00 x 22.50 [813 x 572]	<a href="#"><u>PDF</u></a>
<a href="#"><u>N1P3030</u></a>	\$116.00	<a href="#"><u>N1P3030PP</u></a>	\$133.00	14	26.00 x 28.50 [660 x 724]	<a href="#"><u>PDF</u></a>
<a href="#"><u>N1P3036</u></a>	\$141.00	<a href="#"><u>N1P3036PP</u></a>	\$162.00	14	32.00 x 28.50 [813 x 724]	<a href="#"><u>PDF</u></a>

Note: Dimensions in inches [millimeters].