

Ultimate Series NEMA 4, 12, and 13 Single-Door Wall-Mount



Application

Designed to house and protect electrical and electronic components from harsh, dirty environments. For use in installations where dust, dirt, oil, water or other contaminants are present. Streamlined styling, flush latching, and an attractive, durable finish complement any high-tech electronic equipment.



Construction

- Bodies and doors fabricated from 14-gauge steel
- Plasma welded seams
- Polyurethane poured-in-place gasket
- Collar studs provided for mounting optional subpanels
- Grounding provisions provided
- Concealed hinges
- Increased tub openings to accommodate larger size (optional) subpanels
- Optional subpanels must be ordered separately
- Swing-out panel kits WAJCDFK and WANADFK will not work with these enclosures
- Doors are interchangeable and easily removable (open to 90° to remove door)
- 1/4 turn, semi-flush oil-tight latches supplied to hold door securely closed
- Mounting holes in rear of enclosure body
- N412MFK/N412MFKSS mounting foot kit is available and is required to maintain the NEMA 4, 12, and 13 ratings
- Uses N41214 series latches

Finish

- ANSI 61 gray light-textured [N41212xxxxC] or RAL7035 gray textured [N41212xxxxCLG] inside and outside over phosphatized surfaces
- Painted steel subpanels are white polyester powder over phosphatized surfaces
- Galvanized and stainless subpanels are a conductive finish (unpainted)

Listings

- UL 508, 4, 12, and 13 [UL file E64791]
- Meets NEMA/EEMAC 4, 12, and 13 requirements
- Wall mounting brackets required to maintain UL/CSA external mounting requirements



Note: For current listings, please see www.automationdirect.com

Shipping Schedule

Same day 1 - 5 days 1 - 7 days 1 - 15 days 1 - 20 days
Color indicates shipping lead time in business days.

Ultimate Series NEMA 4, 12, and 13 Single-Door Wall-Mount

ANSI 61 Gray Light-Textured	Price	RAL7035 Gray Textured	Price	Enclosure Size HxWxD	C	E	Painted Steel Subpanel	Stainless Steel Subpanel	Galvanized Subpanel	Swing-Out Panel
N412121206C	\$250.00	N412121206CLG	\$250.00	12.00 x 12.00 x 6.92 [305 x 305 x 176]	6 [152]	—	NP1212C	—	NP1212CG	HFWNSP1212C
N412161206C	\$267.00	N412161206CLG	\$267.00	16.00 x 12.00 x 6.92 [406 x 305 x 176]	8 [203]	—	NP1612C	NP1612SSC	NP1612CG	HFWNSP1612C
N412161208C	\$280.00	N412161208CLG	\$280.00	16.00 x 12.00 x 8.92 [406 x 305 x 227]	8 [203]	—	NP1612C	NP1612SSC	NP1612CG	HFWNSP1612C
N412161210C	\$291.00	N412161210CLG	\$291.00	16.00 x 12.00 x 10.92 [406 x 305 x 277]	8 [203]	—	NP1612C	NP1612SSC	NP1612CG	HFWNSP1612C
N412161606C	\$287.00	N412161606CLG	\$287.00	16.00 x 16.00 x 6.92 [406 x 406 x 176]	8 [203]	—	NP1616C	NP1616SSC	NP1616CG	HFWNSP1616C
N412161608C	\$294.00	N412161608CLG	\$294.00	16.00 x 16.00 x 8.92 [406 x 406 x 227]	8 [203]	—	NP1616C	NP1616SSC	NP1616CG	HFWNSP1616C
N412161610C	\$314.00	N412161610CLG	\$314.00	16.00 x 16.00 x 10.92 [406 x 406 x 277]	8 [203]	—	NP1616C	NP1616SSC	NP1616CG	HFWNSP1616C
N412162006C	\$308.00	N412162006CLG	\$308.00	16.00 x 20.00 x 6.92 [406 x 508 x 176]	8 [203]	—	NP2016C	NP2016SSC	NP2016CG	HFWNSP1620C
N412162008C	\$334.00	N412162008CLG	\$334.00	16.00 x 20.00 x 8.92 [406 x 508 x 227]	8 [203]	—	NP2016C	NP2016SSC	NP2016CG	HFWNSP1620C
N412162010C	\$344.00	N412162010CLG	\$344.00	16.00 x 20.00 x 10.92 [406 x 508 x 277]	8 [203]	—	NP2016C	NP2016SSC	NP2016CG	HFWNSP1620C
N412201606C	\$311.00	N412201606CLG	\$311.00	20.00 x 16.00 x 6.92 [508 x 406 x 176]	10 [254]	—	NP2016C	NP2016SSC	NP2016CG	HFWNSP2016C
N412201608C	\$337.00	N412201608CLG	\$337.00	20.00 x 16.00 x 8.92 [508 x 406 x 227]	10 [254]	—	NP2016C	NP2016SSC	NP2016CG	HFWNSP2016C

Notes: Subpanels must be ordered separately.
Dimensions in inches [millimeters].
Letters in table correspond to letters on dimensional drawings.

Table continued on next page

Ultimate Series NEMA 4, 12, and 13 Single-Door Wall-Mount



Shipping Schedule				
Same day	1 - 5 days	1 - 7 days	1 - 15 days	1 - 20 days

Color indicates shipping lead time in business days.

Table continued from previous page

Ultimate Series NEMA 4, 12, and 13 Single-Door Wall-Mount										
ANSI 61 Gray Light-Textured	Price	RAL7035 Gray Textured	Price	Enclosure Size HxWxD	C	E	Painted Steel Subpanel	Stainless Steel Subpanel	Galvanized Subpanel	Swing-Out Panel
N412201610C	\$347.00	N412201610CLG	\$347.00	20.00 x 16.00 x 10.92 [508 x 406 x 277]	10 [254]	—	NP2016C	NP2016SSC	NP2016CG	HFWNSP2016C
N412202006C	\$342.00	N412202006CLG	\$342.00	20.00 x 20.00 x 6.92 [508 x 508 x 176]	10 [254]	—	NP2020C	NP2020SSC	NP2020CG	HFWNSP2020C
N412202008C	\$358.00	N412202008CLG	\$358.00	20.00 x 20.00 x 8.92 [508 x 508 x 227]	10 [254]	—	NP2020C	NP2020SSC	NP2020CG	HFWNSP2020C
N412202010C	\$365.00	N412202010CLG	\$365.00	20.00 x 20.00 x 10.92 [508 x 508 x 277]	10 [254]	—	NP2020C	NP2020SSC	NP2020CG	HFWNSP2020C
N412202012C	\$388.00	N412202012CLG	\$388.00	20.00 x 20.00 x 12.92 [508 x 508 x 328]	10 [254]	—	NP2020C	NP2020SSC	NP2020CG	HFWNSP2020C
N412202408C	\$374.00	N412202408CLG	\$374.00	20.00 x 24.00 x 8.92 [508 x 610 x 227]	10 [254]	—	NP2420C	NP2420SSC	NP2420CG	HFWNSP2024C
N412202410C	\$393.00	N412202410CLG	\$393.00	20.00 x 24.00 x 10.92 [508 x 610 x 277]	10 [254]	—	NP2420C	NP2420SSC	NP2420CG	HFWNSP2024C
N412241606C	\$338.00	N412241606CLG	\$338.00	24.00 x 16.00 x 6.92 [610 x 406 x 176]	12 [305]	—	NP2416C	NP2416SSC	NP2416CG	HFWNSP2416C
N412241608C	\$357.00	N412241608CLG	\$357.00	24.00 x 16.00 x 8.92 [610 x 406 x 227]	12 [305]	—	NP2416C	NP2416SSC	NP2416CG	HFWNSP2416C
N412241610C	\$361.00	N412241610CLG	\$361.00	24.00 x 16.00 x 10.92 [610 x 406 x 277]	12 [305]	—	NP2416C	NP2416SSC	NP2416CG	HFWNSP2416C
N412242006C	\$360.00	N412242006CLG	\$360.00	24.00 x 20.00 x 6.92 [610 x 508 x 176]	12 [305]	—	NP2420C	NP2420SSC	NP2420CG	HFWNSP2420C
N412242008C	\$377.00	N412242008CLG	\$377.00	24.00 x 20.00 x 8.92 [610 x 508 x 227]	12 [305]	—	NP2420C	NP2420SSC	NP2420CG	HFWNSP2420C
N412242010C	\$396.00	N412242010CLG	\$396.00	24.00 x 20.00 x 10.92 [610 x 508 x 277]	12 [305]	—	NP2420C	NP2420SSC	NP2420CG	HFWNSP2420C
N412242012C	\$423.00	N412242012CLG	\$423.00	24.00 x 20.00 x 12.92 [610 x 508 x 328]	12 [305]	—	NP2420C	NP2420SSC	NP2420CG	HFWNSP2420C
N412242406C	\$381.00	N412242406CLG	\$381.00	24.00 x 24.00 x 6.92 [610 x 610 x 176]	4 [102]	16 [406]	NP2424C	NP2424SSC	NP2424CG	HFWNSP2424C
N412242408C	\$407.00	N412242408CLG	\$407.00	24.00 x 24.00 x 8.92 [610 x 610 x 227]	4 [102]	16 [406]	NP2424C	NP2424SSC	NP2424CG	HFWNSP2424C
N412242410C	\$428.00	N412242410CLG	\$428.00	24.00 x 24.00 x 10.92 [610 x 610 x 277]	4 [102]	16 [406]	NP2424C	NP2424SSC	NP2424CG	HFWNSP2424C
N412242412C	\$452.00	N412242412CLG	\$452.00	24.00 x 24.00 x 12.92 [610 x 610 x 328]	4 [102]	16 [406]	NP2424C	NP2424SSC	NP2424CG	HFWNSP2424C
N412242416C	\$493.00	N412242416CLG	\$493.00	24.00 x 24.00 x 16.92 [610 x 610 x 430]	4 [102]	16 [406]	NP2424C	NP2424SSC	NP2424CG	HFWNSP2424C
N412242420C	\$557.00	N412242420CLG	\$557.00	24.00 x 24.00 x 20.92 [610 x 610 x 531]	4 [102]	16 [406]	NP2424C	NP2424SSC	NP2424CG	HFWNSP2424C
N412243008C	\$452.00	N412243008CLG	\$452.00	24.00 x 30.00 x 8.92 [610 x 762 x 227]	4 [102]	16 [406]	NP3024C	NP3024SSC	NP3024CG	—
N412243010C	\$470.00	N412243010CLG	\$470.00	24.00 x 30.00 x 10.92 [610 x 762 x 277]	4 [102]	16 [406]	NP3024C	NP3024SSC	NP3024CG	—
N412302008C	\$421.00	N412302008CLG	\$421.00	30.00 x 20.00 x 8.92 [762 x 508 x 227]	4 [102]	22 [559]	NP3020C	—	NP3020CG	HFWNSP3020C
N412302010C	\$446.00	N412302010CLG	\$446.00	30.00 x 20.00 x 10.92 [762 x 508 x 277]	4 [102]	22 [559]	NP3020C	—	NP3020CG	HFWNSP3020C
N412302408C	\$452.00	N412302408CLG	\$452.00	30.00 x 24.00 x 8.92 [762 x 610 x 227]	4 [102]	22 [559]	NP3024C	NP3024SSC	NP3024CG	HFWNSP3024C

Notes: Subpanels must be ordered separately.
Dimensions in inches [millimeters].
Letters in table correspond to letters on dimensional drawings.

Table continued on next page

Ultimate Series NEMA 4, 12, and 13 Single-Door Wall-Mount



Shipping Schedule					
Same day	1 - 5 days	1 - 7 days	1-10 days	1 - 15 days	1 - 20 days

Color indicates shipping lead time in business days.

Table continued from previous page


Ultimate Series NEMA 4, 12, and 13 Single-Door Wall-Mount										
ANSI 61 Gray Light-Textured	Price	RAL7035 Gray Textured	Price	Enclosure Size HxWxD	C	E	Painted Steel Subpanel	Stainless Steel Subpanel	Galvanized Subpanel	Swing-Out Panel
N412302410C	\$470.00	N412302410CLG	\$470.00	30.00 x 24.00 x 10.92 [762 x 610 x 277]	4 [102]	22 [559]	NP3024C	NP3024SSC	NP3024CG	HFWNSP3024C
N412302412C	\$502.00	N412302412CLG	\$502.00	30.00 x 24.00 x 12.92 [762 x 610 x 328]	4 [102]	22 [559]	NP3024C	NP3024SSC	NP3024CG	HFWNSP3024C
N412302420C	\$610.00	N412302420CLG	\$610.00	30.00 x 24.00 x 20.92 [762 x 610 x 531]	4 [102]	22 [559]	NP3024C	NP3024SSC	NP3024CG	HFWNSP3024C
N412303008C	\$505.00	N412303008CLG	\$505.00	30.00 x 30.00 x 8.92 [762 x 762 x 227]	4 [102]	22 [559]	NP3030C	NP3030SSC	NP3030CG	HFWNSP3030C
N412303010C	\$531.00	N412303010CLG	\$531.00	30.00 x 30.00 x 10.92 [762 x 762 x 277]	4 [102]	22 [559]	NP3030C	NP3030SSC	NP3030CG	HFWNSP3030C
N412303012C	\$561.00	N412303012CLG	\$561.00	30.00 x 30.00 x 12.92 [762 x 762 x 328]	4 [102]	22 [559]	NP3030C	NP3030SSC	NP3030CG	HFWNSP3030C
N412362408C	\$497.00	N412362408CLG	\$497.00	36.00 x 24.00 x 8.92 [914 x 610 x 227]	4 [102]	28 [711]	NP3624C	NP3624SSC	NP3624CG	HFWNSP3624C
N412362410C	\$522.00	N412362410CLG	\$522.00	36.00 x 24.00 x 10.92 [914 x 610 x 277]	4 [102]	28 [711]	NP3624C	NP3624SSC	NP3624CG	HFWNSP3624C
N412362412C	\$559.00	N412362412CLG	\$559.00	36.00 x 24.00 x 12.92 [914 x 610 x 328]	4 [102]	28 [711]	NP3624C	NP3624SSC	NP3624CG	HFWNSP3624C
N412363008C	\$558.00	N412363008CLG	\$558.00	36.00 x 30.00 x 8.92 [914 x 762 x 227]	4 [102]	28 [711]	NP3630C	NP3630SSC	NP3630CG	HFWNSP3630C
N412363010C	\$586.00	N412363010CLG	\$586.00	36.00 x 30.00 x 10.92 [914 x 762 x 277]	4 [102]	28 [711]	NP3630C	NP3630SSC	NP3630CG	HFWNSP3630C
N412363012C	\$620.00	N412363012CLG	\$620.00	36.00 x 30.00 x 12.92 [914 x 762 x 328]	4 [102]	28 [711]	NP3630C	NP3630SSC	NP3630CG	HFWNSP3630C
N412363016C	\$686.00	N412363016CLG	\$686.00	36.00 x 30.00 x 16.92 [914 x 762 x 430]	4 [102]	28 [711]	NP3630C	NP3630SSC	NP3630CG	HFWNSP3630C
N412363020C	\$752.00	N412363020CLG	\$752.00	36.00 x 30.00 x 20.92 [914 x 762 x 531]	4 [102]	28 [711]	NP3630C	NP3630SSC	NP3630CG	HFWNSP3630C
N412363608C	\$620.00	N412363608CLG	\$620.00	36.00 x 36.00 x 8.92 [914 x 914 x 227]	4 [102]	28 [711]	NP3636C	NP3636SSC	NP3636CG	HFWNSP3636C
N412363610C	\$651.00	N412363610CLG	\$651.00	36.00 x 36.00 x 10.92 [914 x 914 x 277]	4 [102]	28 [711]	NP3636C	NP3636SSC	NP3636CG	HFWNSP3636C
N412363612C	\$694.00	N412363612CLG	\$694.00	36.00 x 36.00 x 12.92 [914 x 914 x 328]	4 [102]	28 [711]	NP3636C	NP3636SSC	NP3636CG	HFWNSP3636C
N412402412C	\$646.00	N412402412CLG	\$646.00	40.00 x 24.00 x 12.92 [1016 x 610 x 328]	20 [508]	—	NP4024C	—	NP4024CG	—
N412423610C	\$725.00	N412423610CLG	\$725.00	42.00 x 36.00 x 10.92 [1067 x 914 x 277]	21 [533]	—	NP4236C	NP4236SSC	NP4236CG	—
N412423612C	\$755.00	N412423612CLG	\$755.00	42.00 x 36.00 x 12.92 [1067 x 914 x 328]	21 [533]	—	NP4236C	NP4236SSC	NP4236CG	—
N412482410C	\$646.00	N412482410CLG	\$646.00	48.00 x 24.00 x 10.92 [1219 x 610 x 277]	24 [610]	—	NP4824C	—	NP4824CG	—
N412482412C	\$658.00	N412482412CLG	\$658.00	48.00 x 24.00 x 12.92 [1219 x 610 x 328]	24 [610]	—	NP4824C	—	NP4824CG	—
N412483610C	\$789.00	N412483610CLG	\$789.00	48.00 x 36.00 x 10.92 [1219 x 914 x 277]	24 [610]	—	NP4836C	NP4836SSC	NP4836CG	—
N412483612C	\$822.00	N412483612CLG	\$822.00	48.00 x 36.00 x 12.92 [1219 x 914 x 328]	24 [610]	—	NP4836C	NP4836SSC	NP4836CG	—
N412483616C	\$901.00	N412483616CLG	\$901.00	48.00 x 36.00 x 16.92 [1219 x 914 x 430]	24 [610]	—	NP4836C	NP4836SSC	NP4836CG	—
N412603610C	\$919.00	N412603610CLG	\$919.00	60.00 x 36.00 x 10.92 [1524 x 914 x 277]	30 [762]	—	NP6036C	NP6036SSC	NP6036CG	—
N412603612C	\$957.00	N412603612CLG	\$958.00	60.00 x 36.00 x 12.92 [1524 x 914 x 328]	30 [762]	—	NP6036C	NP6036SSC	NP6036CG	—

Notes: Subpanels must be ordered separately.
Dimensions in inches [millimeters].
Letters in table correspond to letters on dimensional drawings.

Ultimate Series NEMA 4, 12, and 13 Single-Door Wall-Mount



Dimensions

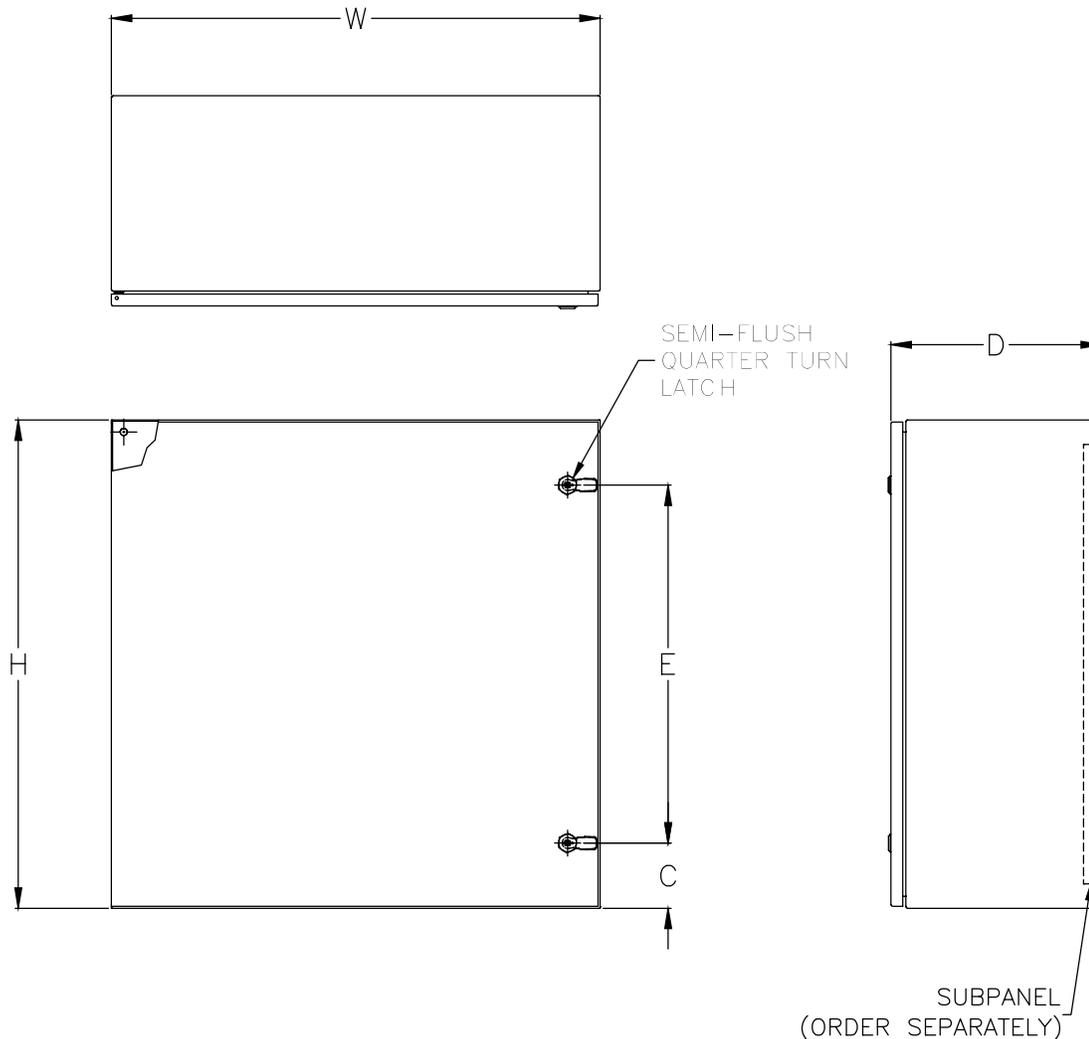

Notes: Enclosures include a 3-point latch when H=40 in [1016 mm] or more.
 Two Hinges provided when H<36 in [914 mm]. Three Hinges provided when H=36 in [914 mm] or greater.
 Four Hinges provided when H=48 in [1219 mm] or greater.
 For Enclosure sizes over 42 in [1067 mm] the Latch location is 2.25in [57.2mm].
 Enclosures smaller than 24 in [610 mm] have one latch.

Enclosure Subpanels





Subpanels for Ultimate Series Wall-Mount Enclosures

- 12-gauge steel
- Subpanels with dimensions 30 x 30 in [762 x 762 mm] and larger are flanged on all sides. Smaller subpanels are flanged on two sides
- Painted steel subpanels are white polyester powder over phosphatized surfaces
- Galvanized subpanels have a conductive finish (no paint)
- Panels listed fit all styles of N412 Ultimate Series wall-mount enclosures, including slope top and disconnect enclosures

Note: NPxxxxC subpanels will not fit in older NEMA 4/12 enclosures (purchased prior to 3-23-05) that do not have a C suffix. For example: Subpanel NP1212C will not fit enclosures N412121206 or N412121206SS.



Dimensions

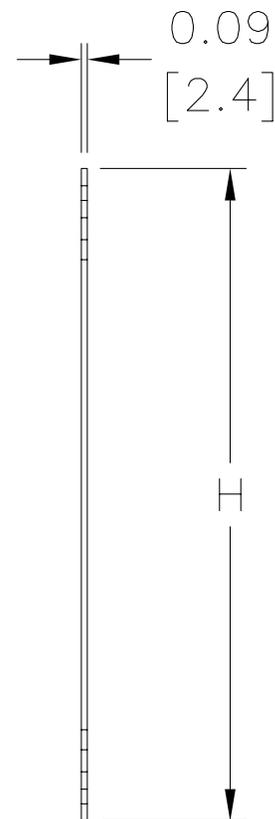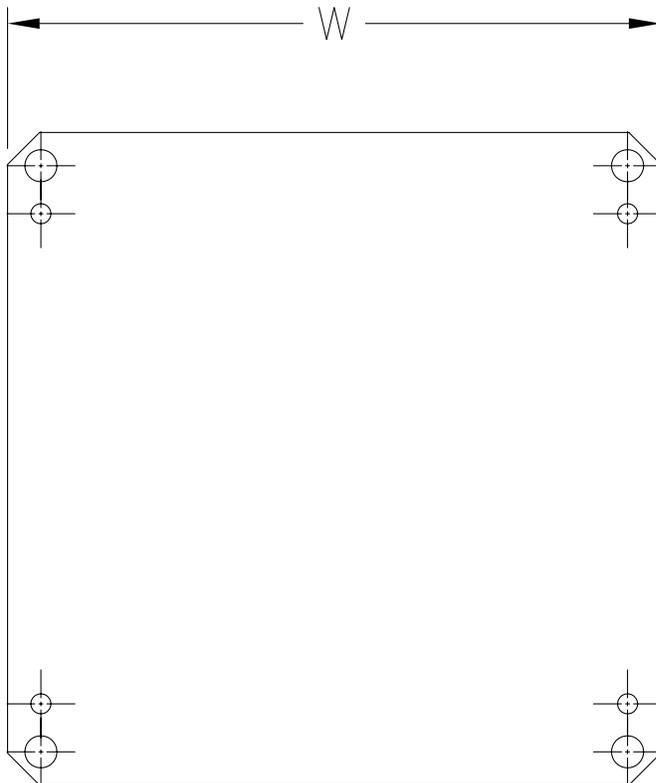

Enclosure Subpanels



Subpanels for Ultimate Series Wall-Mount Enclosures

Shipping Schedule

Same day 1 - 5 days 1 - 7 days 1 - 15 days 1 - 20 days

Color indicates shipping lead time in business days.

Subpanels for Ultimate Series Wall-Mount Enclosures


Painted Steel	Price	Galvanized	Price	304 Stainless Steel	Price	Nominal Enclosure Size HxW*	Subpanel Size HxW
NP1212C	\$15.50	NP1212CG	\$13.00	—	—	12 x 12	10.20 x 10.20 [259 x 259]
NP1612C	\$16.75	NP1612CG	\$16.75	NP1612SSC	\$87.00	16 x 12	14.20 x 10.20 [361 x 259]
NP1616C	\$40.50	NP1616CG	\$40.50	NP1616SSC	\$106.00	16 x 16	14.20 x 14.20 [361 x 361]
NP2016C	\$48.00	NP2016CG	\$48.00	NP2016SSC	\$128.00	16 x 20 20 x 16	18.20 x 14.20 [462 x 361]
NP2020C	\$58.00	NP2020CG	\$58.00	NP2020SSC	\$165.00	20 x 20	18.20 x 18.20 [462 x 462]
NP2416C	\$56.00	NP2416CG	\$56.00	NP2416SSC	\$159.00	24 x 16	22.20 x 14.20 [564 x 361]
NP2420C	\$56.00	NP2420CG	\$75.00	NP2420SSC	\$200.00	24 x 20	22.20 x 18.20 [564 x 462]
NP2424C	\$86.00	NP2424CG	\$86.00	NP2424SSC	\$233.00	24 x 24	22.20 x 22.20 [564 x 564]
NP3020C	\$90.00	NP3020CG	\$90.00	—	—	30 x 20	28.20 x 18.20 [716 x 462]
NP3024C	\$105.00	NP3024CG	\$90.00	NP3024SSC	\$306.00	30 x 24	28.20 x 22.20 [716 x 564]
NP3030C	\$147.00	NP3030CG	\$147.00	NP3030SSC	\$418.00	30 x 30	28.20 x 28.20 [716 x 716]
NP3624C	\$125.00	NP3624CG	\$125.00	NP3624SSC	\$357.00	24 x 36 36 x 24	34.20 x 22.20 [869 x 564]
NP3630C	\$167.00	NP3630CG	\$167.00	NP3630SSC	\$443.00	36 x 30	34.20 x 28.20 [869 x 716]
NP3636C	\$196.00	NP3636CG	\$196.00	NP3636SSC	\$535.00	36 x 36	34.20 x 34.20 [869 x 869]
NP4224C	\$244.00	—	—	—	—	24 x 42	40.20 x 22.20 [1021 x 564]
NP4024C	\$151.00	NP4024CG	\$151.00	—	—	40 x 24	38.20 x 22.20 [970 x 564]
NP4242C	\$418.00	—	—	—	—	42 x 42	40.20 x 40.20 [1021 x 1021]
NP4230C	\$225.00	—	—	—	—	30 x 42 42 x 32	40.20 x 28.20 [1021 x 716]
NP4236C	\$225.00	NP4236CG	\$225.00	NP4236SSC	\$676.00	36 x 42 42 x 36	40.20 x 34.20 [1021 x 869]
NP4824C	\$163.00	NP4824CG	\$163.00	—	—	24 x 48 48 x 24	46.20 x 22.20 [1173 x 564]
NP4830C	\$336.00	—	—	—	—	30 x 48	46.20 x 28.20 [1173 x 716]
NP4842C	\$562.00	—	—	—	—	42 x 48	46.20 x 40.20 [1173 x 1021]
NP4836C	\$254.00	NP4836CG	\$254.00	NP4836SSC	\$676.00	36 x 48 48 x 36	46.20 x 34.20 [1173 x 869]
NP4848C	\$625.00	—	—	—	—	48 x 48	46.20 x 46.20 [1173 x 1173]
NP6030C	\$446.00	—	—	—	—	30 x 60	58.20 x 28.20 [1478 x 716]
NP6036C	\$313.00	NP6036CG	\$313.00	NP6036SSC	\$965.00	36 x 30 60 x 36	58.20 x 34.20 [1478 x 869]
NP6042C	\$627.00	—	—	—	—	42 x 60	58.20 x 40.20 [1478 x 1021]

Notes: Dimensions in inches [millimeters].

Letters in table correspond to letters on dimensional drawing.

Disconnect enclosures will be up to 2 in [51 mm] wider than width dimensions in this table.

Swing-Out Panels for Ultimate Series Enclosures

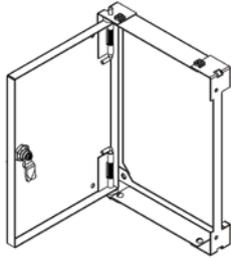

For N412 Ultimate Series Wall-Mount Enclosures except N412-1PTC, -3PTC, -SS1PTC, -SS3PTC, -SSA1PTC, and -SSA3PTC

- Maximum swing 107°
- Convenient access to sub enclosure is provided via 1/4 turn pull-tab
- On solid doors, the clearance from the swing panel face to the interior door face is 1.25in [31.8mm] on window doors (when the door is closed)
- The kit includes the swing panel, brackets and hardware necessary for a tub flange install. Swing out panels meet 1 with enclosure door open
- Painted steel subpanels are painted white polyester powder over phosphated surfaces
- Fabricated from 14-gauge steel
- Mounting hardware is furnished with each panel

Note: HFWNSPxxxxC swing-out panels will not fit in older NEMA 4/12 enclosures (purchased prior to 3-23-05) that do not have a C suffix. For example: Swing-out panel HFWNSP1212C will not fit enclosures N41212126 or N412121206SS.

Shipping Schedule

Same day 1 - 5 days 1 - 7 days 1 - 15 days 1 - 20 days


Color indicates shipping lead time in business days.

Swing-Out Panels for Ultimate Series Enclosures

Part Number	Price	Panel Size CxE	Overall Dimensions HxW	Enclosure Nominal Size
HFWNSP1212C	\$128.00	9.75 x 9.75 [248 x 248]	10.50 x 10.62 [267 x 270]	12 x 12
HFWNSP1612C	\$133.00	13.75 x 9.75 [349 x 248]	14.50 x 10.62 [368 x 270]	16 x 12
HFWNSP1616C	\$140.00	13.75 x 13.75 [349 x 349]	14.50 x 14.62 [368 x 37]	16 x 16
HFWNSP1620C	\$160.00	13.75 x 17.75 [349 x 451]	14.50 x 18.62 [368 x 473]	16 x 20
HFWNSP2016C	\$147.00	17.75 x 13.75 [451 x 349]	18.50 x 14.62 [470 x 371]	20 x 16
HFWNSP2020C	\$156.00	17.75 x 17.75 [451 x 451]	18.50 x 18.62 [470 x 473]	20 x 20
HFWNSP2024C	\$179.00	17.75 x 21.75 [451 x 552]	18.50 x 22.62 [470 x 575]	20 x 24
HFWNSP2416C	\$167.00	21.75 x 13.75 [552 x 349]	22.50 x 14.62 [572 x 371]	24 x 16
HFWNSP2420C	\$165.00	21.75 x 17.75 [552 x 451]	22.50 x 18.62 [572 x 473]	24 x 20
HFWNSP2424C	\$176.00	21.75 x 21.75 [552 x 552]	22.50 x 22.62 [572 x 575]	24 x 24
HFWNSP3020C	\$194.00	27.75 x 17.75 [705 x 451]	28.50 x 18.62 [724 x 473]	30 x 20
HFWNSP3024C	\$192.00	27.75 x 21.75 [705 x 552]	28.50 x 22.62 [724 x 575]	30 x 24
HFWNSP3030C	\$212.00	27.75 x 27.75 [705 x 705]	28.50 x 28.62 [724 x 727]	30 x 30
HFWNSP3624C	\$208.00	33.75 x 21.75 [857 x 552]	34.50 x 22.62 [876 x 575]	36 x 24
HFWNSP3630C	\$232.00	33.75 x 27.75 [857 x 705]	34.50 x 28.62 [876 x 727]	36 x 30
HFWNSP3636C	\$256.00	33.75 x 33.75 [857 x 857]	34.50 x 34.62 [876 x 879]	36 x 36

Notes: Dimensions in inches [millimeters].
 Letters in table correspond to letters on dimensional drawings.
 If used in a two-door enclosure, a center panel support must be ordered.

Dimensions

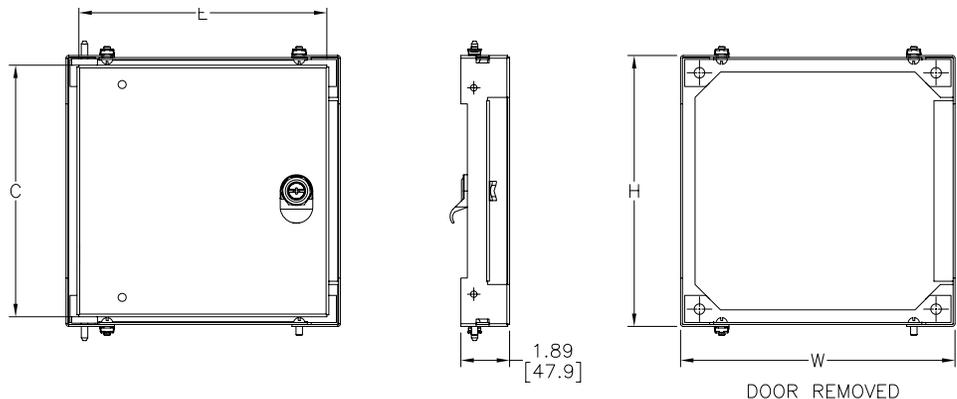

Enclosure Accessories – Strip Gasket



Shipping Schedule

Same day	1 - 5 days	1 - 7 days	1 - 15 days	1 - 20 days
----------	------------	------------	-------------	-------------

Color indicates shipping lead time in business days.

Strip Gasket



Strip Gasket	Price	Description	Wt. [oz]
<u>WGAS51634</u>	\$18.75	Wiegmann strip gasket, replacement, self-adhesive, microcell urethane foam, 5/16 inch thick x 0.75in [19 mm]ch wide x 10 ft long roll. For gasket replacement on Wiegmann wall-mount NEMA 12, 4 and 4X enclosures.	7
<u>WGAS3834</u>	\$19.25	Wiegmann strip gasket, replacement, self-adhesive, closed-cell sponge rubber, 3/8 inch thick x 0.75in [19 mm]ch wide x 10 ft long roll. For gasket replacement on Wiegmann floor-mount and freestanding NEMA 12, 4 and 4X enclosures.	7