

# Ultimate Series NEMA 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount with 1-Point Handle



## Application

The Wiegmann N412-SS stainless steel series, with its streamlined design, is a perfect fit for mounting electrical or high-tech electronic equipment in a variety of indoor and outdoor settings. It is typically used in the following areas where corrosion-resistant protection is needed: food processing plants, pharmaceutical manufacturing facilities, petrochemical plants, pulp and paper processing, and waste water treatment facilities.



## Construction

- Bodies and doors fabricated from 14-gauge type 304 or 316L stainless steel
- Print pocket is provided
- Doors are sealed with poured-in-place polyurethane gasket
- Concealed hinges
- Increased tub openings to accommodate larger size (optional) subpanels
- Collar studs for mounting optional subpanels
- Grounding provisions provided
- Optional subpanels must be ordered separately
- Swing-out panel kits WAJCDFK and WANADFK will not work with these enclosures
- Doors are interchangeable and easily removable (open to 90° to remove door)
- 1-point 316L stainless steel padlocking handle
- Mounting holes in rear of enclosure
- N412MFKSS mounting foot kit required to maintain NEMA 4X, 12, and 13 ratings
  - Mounting foot kit must be ordered separately
- Uses WAL3\_SS series handles

## Finish

- All exterior surfaces have a smooth-grained finish
- Painted steel subpanels are painted white polyester powder over phosphatized surfaces
- Galvanized and stainless subpanels are a conductive finish (unpainted)

## Listings

- UL 508, 4X, 12, and 13 [UL file E64791]
- Meets NEMA/EEMAC 4X, 12, and 13 requirements
- Wall mounting brackets required to maintain UL/CSA external mounting requirements



Note: For current listings, please see [www.automationdirect.com](http://www.automationdirect.com)

Shipping Schedule					
Same day	1 - 5 days	1 - 7 days	1-10 days	1 - 15 days	1 - 20 days
Color indicates shipping lead time in business days.					


Ultimate Series NEMA 4X, 12, and 13 Stainless Steel Single Door Wall-Mount with 1-Point Handle									
304 Stainless Steel	Price	316L StainlessSteel	Price	Enclosure Size HxWxD	C	Painted Steel Subpanel	Stainless Steel Subpanel	Galvanized Subpanel	Swing-Out Panel
<a href="#">N412121206SS1PTC</a>	\$865.00	<a href="#">N412121206SSA1PTC</a>	\$1,140.00	12.00 x 12.00 x 6.92 [305 x 305 x 176]	6 [152]	<a href="#">NP1212C</a>	—	<a href="#">NP1212CG</a>	<a href="#">HFWNSP1212C</a>
<a href="#">N412161206SS1PTC</a>	\$931.00	<a href="#">N412161206SSA1PTC</a>	\$1,192.00	16.00 x 12.00 x 6.92 [406 x 305 x 176]	6 [152]	<a href="#">NP1612C</a>	<a href="#">NP1612SSC</a>	<a href="#">NP1612CG</a>	<a href="#">HFWNSP1612C</a>
<a href="#">N412161208SS1PTC</a>	\$971.00	<a href="#">N412161208SSA1PTC</a>	\$1,556.00	16.00 x 12.00 x 8.92 [406 x 305 x 227]	8 [203]	<a href="#">NP1612C</a>	<a href="#">NP1612SSC</a>	<a href="#">NP1612CG</a>	<a href="#">HFWNSP1612C</a>
<a href="#">N412161606SS1PTC</a>	\$1,011.00	<a href="#">N412161606SSA1PTC</a>	\$1,599.00	16.00 x 16.00 x 6.92 [406 x 406 x 176]	8 [203]	<a href="#">NP1616C</a>	<a href="#">NP1616SSC</a>	<a href="#">NP1616CG</a>	<a href="#">HFWNSP1616C</a>
<a href="#">N412161608SS1PTC</a>	\$1,080.00	<a href="#">N412161608SSA1PTC</a>	\$1,724.00	16.00 x 16.00 x 8.92 [406 x 406 x 227]	8 [203]	<a href="#">NP1616C</a>	<a href="#">NP1616SSC</a>	<a href="#">NP1616CG</a>	<a href="#">HFWNSP1616C</a>
<a href="#">N412162008SS1PTC</a>	\$1,196.00	<a href="#">N412162008SSA1PTC</a>	\$1,591.00	16.00 x 20.00 x 8.92 [406 x 508 x 227]	8 [203]	<a href="#">NP2016C</a>	<a href="#">NP2016SSC</a>	<a href="#">NP2016CG</a>	<a href="#">HFWNSP1620C</a>
<a href="#">N412201606SS1PTC</a>	\$1,185.00	<a href="#">N412201606SSA1PTC</a>	\$1,554.00	20.00 x 16.00 x 6.92 [508 x 406 x 176]	10 [254]	<a href="#">NP2016C</a>	<a href="#">NP2016SSC</a>	<a href="#">NP2016CG</a>	<a href="#">HFWNSP1620C</a>
<a href="#">N412201608SS1PTC</a>	\$1,211.00	<a href="#">N412201608SSA1PTC</a>	\$1,591.00	20.00 x 16.00 x 8.92 [508 x 406 x 227]	10 [254]	<a href="#">NP2016C</a>	<a href="#">NP2016SSC</a>	<a href="#">NP2016CG</a>	<a href="#">HFWNSP2016C</a>
<a href="#">N412202006SS1PTC</a>	\$1,214.00	<a href="#">N412202006SSA1PTC</a>	\$1,596.00	20.00 x 20.00 x 6.92 [508 x 508 x 176]	10 [254]	<a href="#">NP2020C</a>	<a href="#">NP2020SSC</a>	<a href="#">NP2020CG</a>	<a href="#">HFWNSP2020C</a>
<a href="#">N412202008SS1PTC</a>	\$1,258.00	<a href="#">N412202008SSA1PTC</a>	\$1,947.00	20.00 x 20.00 x 8.89 [508 x 508 x 226]	10 [254]	<a href="#">NP2020C</a>	<a href="#">NP2020SSC</a>	<a href="#">NP2020CG</a>	<a href="#">HFWNSP2020C</a>
<a href="#">N412202012SS1PTC</a>	\$1,408.00	<a href="#">N412202012SSA1PTC</a>	\$2,264.00	20.00 x 20.00 x 12.92 [508 x 508 x 328]	10 [254]	<a href="#">NP2020C</a>	<a href="#">NP2020SSC</a>	<a href="#">NP2020CG</a>	<a href="#">HFWNSP2020C</a>

Notes: Subpanels must be ordered separately.  
Dimensions in inches [millimeters].  
Letters in table correspond to letters on dimensional drawings.

# Ultimate Series NEMA 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount with 1-Point Handle



## Dimensions

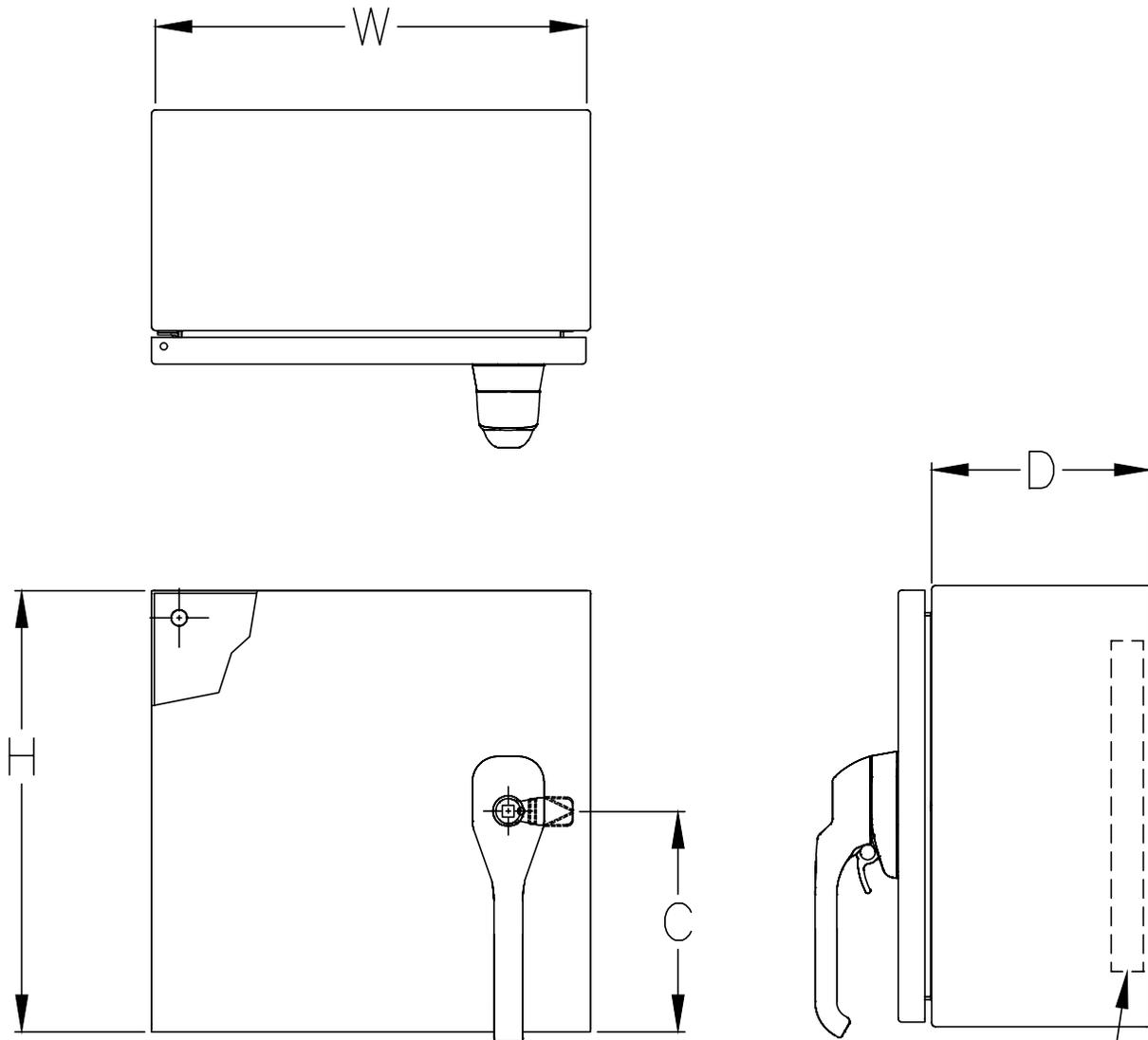

SUBPANEL  
(ORDER SEPARATELY)

Notes: Large print pocket (8 x 10 in [230 x 254 mm]) is furnished if H=20 in [508 mm] or more and W=20 in [508 mm] or more.

Otherwise small (6 x 6 in [152 x 152 mm]) print pocket is provided.

Two hinges provided when H=36 in [914 mm].

Three hinges provided when H=36 in [914 mm] or greater.

Four hinges provided when H=48 in [1219 mm] or greater.

# Enclosure Subpanels





## Subpanels for Ultimate Series Wall-Mount Enclosures

- 12-gauge steel
- Subpanels with dimensions 30 x 30 in [ 762 x 762 mm] and larger are flanged on all sides. Smaller subpanels are flanged on two sides
- Painted steel subpanels are white polyester powder over phosphatized surfaces
- Galvanized subpanels have a conductive finish (no paint)
- Panels listed fit all styles of N412 Ultimate Series wall-mount enclosures, including slope top and disconnect enclosures

Note: NPxxxxC subpanels will not fit in older NEMA 4/12 enclosures (purchased prior to 3-23-05) that do not have a C suffix. For example: Subpanel NP1212C will not fit enclosures N412121206 or N412121206SS.



## Dimensions

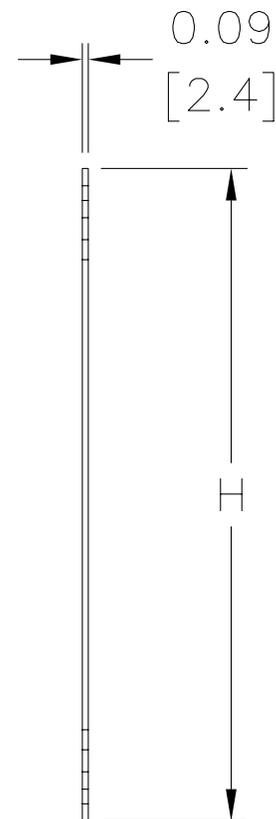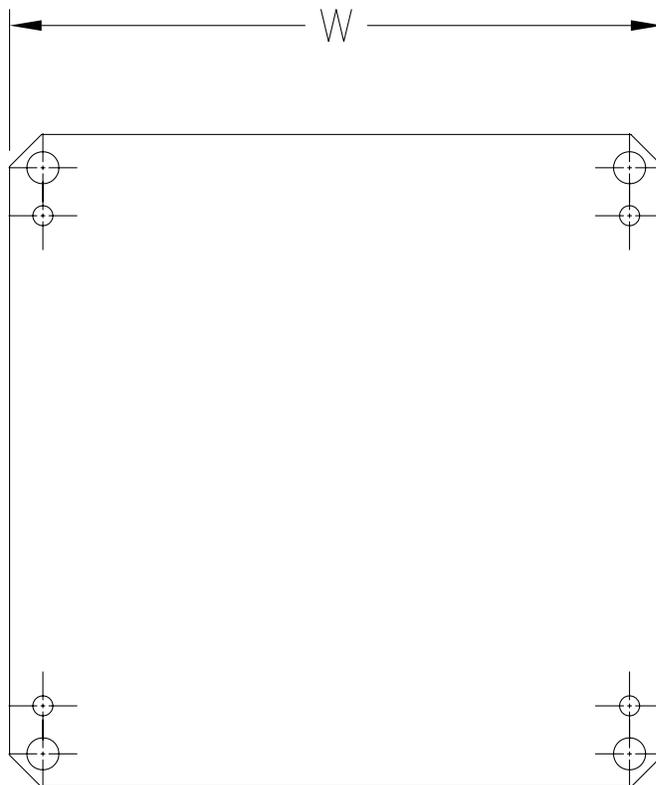

# Enclosure Subpanels



## Subpanels for Ultimate Series Wall-Mount Enclosures

### Shipping Schedule

Same day 1 - 5 days 1 - 7 days 1 - 15 days 1 - 20 days

Color indicates shipping lead time in business days.

### Subpanels for Ultimate Series Wall-Mount Enclosures


Painted Steel	Price	Galvanized	Price	304 Stainless Steel	Price	Nominal Enclosure Size HxW*	Subpanel Size HxW
<a href="#">NP1212C</a>	\$15.50	<a href="#">NP1212CG</a>	\$13.00	—	—	12 x 12	10.20 x 10.20 [259 x 259]
<a href="#">NP1612C</a>	\$16.75	<a href="#">NP1612CG</a>	\$16.75	<a href="#">NP1612SSC</a>	\$87.00	16 x 12	14.20 x 10.20 [361 x 259]
<a href="#">NP1616C</a>	\$40.50	<a href="#">NP1616CG</a>	\$40.50	<a href="#">NP1616SSC</a>	\$106.00	16 x 16	14.20 x 14.20 [361 x 361]
<a href="#">NP2016C</a>	\$48.00	<a href="#">NP2016CG</a>	\$48.00	<a href="#">NP2016SSC</a>	\$128.00	16 x 20 20 x 16	18.20 x 14.20 [462 x 361]
<a href="#">NP2020C</a>	\$58.00	<a href="#">NP2020CG</a>	\$58.00	<a href="#">NP2020SSC</a>	\$165.00	20 x 20	18.20 x 18.20 [462 x 462]
<a href="#">NP2416C</a>	\$56.00	<a href="#">NP2416CG</a>	\$56.00	<a href="#">NP2416SSC</a>	\$159.00	24 x 16	22.20 x 14.20 [564 x 361]
<a href="#">NP2420C</a>	\$56.00	<a href="#">NP2420CG</a>	\$75.00	<a href="#">NP2420SSC</a>	\$200.00	24 x 20	22.20 x 18.20 [564 x 462]
<a href="#">NP2424C</a>	\$86.00	<a href="#">NP2424CG</a>	\$86.00	<a href="#">NP2424SSC</a>	\$233.00	24 x 24	22.20 x 22.20 [564 x 564]
<a href="#">NP3020C</a>	\$90.00	<a href="#">NP3020CG</a>	\$90.00	—	—	30 x 20	28.20 x 18.20 [716 x 462]
<a href="#">NP3024C</a>	\$105.00	<a href="#">NP3024CG</a>	\$90.00	<a href="#">NP3024SSC</a>	\$306.00	30 x 24	28.20 x 22.20 [716 x 564]
<a href="#">NP3030C</a>	\$147.00	<a href="#">NP3030CG</a>	\$147.00	<a href="#">NP3030SSC</a>	\$418.00	30 x 30	28.20 x 28.20 [716 x 716]
<a href="#">NP3624C</a>	\$125.00	<a href="#">NP3624CG</a>	\$125.00	<a href="#">NP3624SSC</a>	\$357.00	24 x 36 36 x 24	34.20 x 22.20 [869 x 564]
<a href="#">NP3630C</a>	\$167.00	<a href="#">NP3630CG</a>	\$167.00	<a href="#">NP3630SSC</a>	\$443.00	36 x 30	34.20 x 28.20 [869 x 716]
<a href="#">NP3636C</a>	\$196.00	<a href="#">NP3636CG</a>	\$196.00	<a href="#">NP3636SSC</a>	\$535.00	36 x 36	34.20 x 34.20 [869 x 869]
<a href="#">NP4224C</a>	\$244.00	—	—	—	—	24 x 42	40.20 x 22.20 [1021 x 564]
<a href="#">NP4024C</a>	\$151.00	<a href="#">NP4024CG</a>	\$151.00	—	—	40 x 24	38.20 x 22.20 [970 x 564]
<a href="#">NP4242C</a>	\$418.00	—	—	—	—	42 x 42	40.20 x 40.20 [1021 x 1021]
<a href="#">NP4230C</a>	\$225.00	—	—	—	—	30 x 42 42 x 32	40.20 x 28.20 [1021 x 716]
<a href="#">NP4236C</a>	\$225.00	<a href="#">NP4236CG</a>	\$225.00	<a href="#">NP4236SSC</a>	\$676.00	36 x 42 42 x 36	40.20 x 34.20 [1021 x 869]
<a href="#">NP4824C</a>	\$163.00	<a href="#">NP4824CG</a>	\$163.00	—	—	24 x 48 48 x 24	46.20 x 22.20 [1173 x 564]
<a href="#">NP4830C</a>	\$336.00	—	—	—	—	30 x 48	46.20 x 28.20 [1173 x 716]
<a href="#">NP4842C</a>	\$562.00	—	—	—	—	42 x 48	46.20 x 40.20 [1173 x 1021]
<a href="#">NP4836C</a>	\$254.00	<a href="#">NP4836CG</a>	\$254.00	<a href="#">NP4836SSC</a>	\$676.00	36 x 48 48 x 36	46.20 x 34.20 [1173 x 869]
<a href="#">NP4848C</a>	\$625.00	—	—	—	—	48 x 48	46.20 x 46.20 [1173 x 1173]
<a href="#">NP6030C</a>	\$446.00	—	—	—	—	30 x 60	58.20 x 28.20 [1478 x 716]
<a href="#">NP6036C</a>	\$313.00	<a href="#">NP6036CG</a>	\$313.00	<a href="#">NP6036SSC</a>	\$965.00	36 x 30 60 x 36	58.20 x 34.20 [1478 x 869]
<a href="#">NP6042C</a>	\$627.00	—	—	—	—	42 x 60	58.20 x 40.20 [1478 x 1021]

Notes: Dimensions in inches [millimeters].

Letters in table correspond to letters on dimensional drawing.

Disconnect enclosures will be up to 2 in [51 mm] wider than width dimensions in this table.

# Swing-Out Panels for Ultimate Series Enclosures

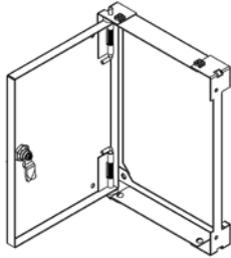

**For N412 Ultimate Series Wall-Mount Enclosures except N412-1PTC, -3PTC, -SS1PTC, -SS3PTC, -SSA1PTC, and -SSA3PTC**

- Maximum swing 107°
- Convenient access to sub enclosure is provided via 1/4 turn pull-tab
- On solid doors, the clearance from the swing panel face to the interior door face is 1.25in [31.8mm] on window doors (when the door is closed)
- The kit includes the swing panel, brackets and hardware necessary for a tub flange install. Swing out panels meet 1 with enclosure door open
- Painted steel subpanels are painted white polyester powder over phosphated surfaces
- Fabricated from 14-gauge steel
- Mounting hardware is furnished with each panel

Note: HFWNSPxxxxC swing-out panels will not fit in older NEMA 4/12 enclosures (purchased prior to 3-23-05) that do not have a C suffix. For example: Swing-out panel HFWNSP1212C will not fit enclosures N41212126 or N412121206SS.

## Shipping Schedule

Same day 1 - 5 days 1 - 7 days 1 - 15 days 1 - 20 days

Color indicates shipping lead time in business days.

## Swing-Out Panels for Ultimate Series Enclosures

Part Number	Price	Panel Size CxE	Overall Dimensions HxW	Enclosure Nominal Size
<a href="#">HFWNSP1212C</a>	\$128.00	9.75 x 9.75 [248 x 248]	10.50 x 10.62 [267 x 270]	12 x 12
<a href="#">HFWNSP1612C</a>	\$133.00	13.75 x 9.75 [349 x 248]	14.50 x 10.62 [368 x 270]	16 x 12
<a href="#">HFWNSP1616C</a>	\$140.00	13.75 x 13.75 [349 x 349]	14.50 x 14.62 [368 x 37]	16 x 16
<a href="#">HFWNSP1620C</a>	\$160.00	13.75 x 17.75 [349 x 451]	14.50 x 18.62 [368 x 473]	16 x 20
<a href="#">HFWNSP2016C</a>	\$147.00	17.75 x 13.75 [451 x 349]	18.50 x 14.62 [470 x 371]	20 x 16
<a href="#">HFWNSP2020C</a>	\$156.00	17.75 x 17.75 [451 x 451]	18.50 x 18.62 [470 x 473]	20 x 20
<a href="#">HFWNSP2024C</a>	\$179.00	17.75 x 21.75 [451 x 552]	18.50 x 22.62 [470 x 575]	20 x 24
<a href="#">HFWNSP2416C</a>	\$167.00	21.75 x 13.75 [552 x 349]	22.50 x 14.62 [572 x 371]	24 x 16
<a href="#">HFWNSP2420C</a>	\$165.00	21.75 x 17.75 [552 x 451]	22.50 x 18.62 [572 x 473]	24 x 20
<a href="#">HFWNSP2424C</a>	\$176.00	21.75 x 21.75 [552 x 552]	22.50 x 22.62 [572 x 575]	24 x 24
<a href="#">HFWNSP3020C</a>	\$194.00	27.75 x 17.75 [705 x 451]	28.50 x 18.62 [724 x 473]	30 x 20
<a href="#">HFWNSP3024C</a>	\$192.00	27.75 x 21.75 [705 x 552]	28.50 x 22.62 [724 x 575]	30 x 24
<a href="#">HFWNSP3030C</a>	\$212.00	27.75 x 27.75 [705 x 705]	28.50 x 28.62 [724 x 727]	30 x 30
<a href="#">HFWNSP3624C</a>	\$208.00	33.75 x 21.75 [857 x 552]	34.50 x 22.62 [876 x 575]	36 x 24
<a href="#">HFWNSP3630C</a>	\$232.00	33.75 x 27.75 [857 x 705]	34.50 x 28.62 [876 x 727]	36 x 30
<a href="#">HFWNSP3636C</a>	\$256.00	33.75 x 33.75 [857 x 857]	34.50 x 34.62 [876 x 879]	36 x 36

Notes: Dimensions in inches [millimeters].  
 Letters in table correspond to letters on dimensional drawings.  
 If used in a two-door enclosure, a center panel support must be ordered.

## Dimensions

