


# Ultimate Series NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Two-Door Wall-Mount

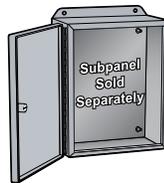

N412D243608SSC



## Application

Removable, interchangeable doors feature concealed hinges. Removable center post provides easy access to components and for installing subpanels. Designed for applications where dirt, dust, oil or water are present.

## Construction

### 304 stainless steel Construction

- Continuous welded seams
- Polyurethane poured-in-place gasket
- Concealed hinges
- Removable center post
- Grounding studs welded to doors and body
- Collar studs for mounting optional subpanels
- 3-point keylocking/padlocking handle included
- Uses WAL4 series handles

## Finish

- #3 intermediate polished

## Listings

- NEMA 3R, 4, 4X, 12, and 13
- UL508A, Type 3R, 4, 4X, 12, and 13
- cULus File E64791
- IEC 60529, IP66
- N412MFKSS mounting feet are required to maintain UL external mounting requirements



Note: For current listings, please see [www.automationdirect.com](http://www.automationdirect.com)

## Shipping Schedule

Same day	1 - 5 days	1 - 7 days	1 - 15 days	1 - 20 days
----------	------------	------------	-------------	-------------

Color indicates shipping lead time in business days.

## Ultimate Series NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Two-Door Wall-Mount

Part Number	Price	Enclosure Size HxWxD	Painted Steel Subpanel	Galvanized Subpanel	304 Stainless Steel
<b>N412D243608SSC</b>	\$3,099.00	24.00 x 36.00 x 8.92 [610 x 914 x 227]	<b>NP3624C</b>	<b>NP3624CG</b>	<b>NP3624SSC</b>
<b>N412D244208SSC</b>	\$3,512.00	24.00 x 42.00 x 8.92 [610 x 1067 x 227]	<b>NP4224C</b>	—	—
<b>N412D244808SSC</b>	\$3,570.00	24.00 x 48.00 x 8.92 [610 x 1219 x 227]	<b>NP4824C</b>	<b>NP4824CG</b>	—
<b>N412D304210SSC</b>	\$3,378.00	30.00 x 42.00 x 10.92 [762 x 1067 x 277]	<b>NP4230C</b>	—	—
<b>N412D304810SSC</b>	\$3,553.00	30.00 x 48.00 x 10.92 [762 x 1219 x 277]	<b>NP4830C</b>	—	—
<b>N412D306010SSC</b>	\$3,691.00	30.00 x 60.00 x 10.92 [762 x 1524 x 277]	<b>NP6030C</b>	—	—
<b>N412D364212SSC</b>	\$3,584.00	36.00 x 42.00 x 12.92 [914 x 1067 x 328]	<b>NP4236C</b>	<b>NP4236CG</b>	<b>NP4236SSC</b>
<b>N412D364812SSC</b>	\$3,745.00	36.00 x 48.00 x 12.92 [914 x 1219 x 328]	<b>NP4836C</b>	<b>NP4836CG</b>	<b>NP4836SSC</b>
<b>N412D366012SSC</b>	\$3,617.00	36.00 x 60.00 x 12.92 [914 x 1524 x 328]	<b>NP6036C</b>	<b>NP6036CG</b>	<b>NP6036SSC</b>
<b>N412D424212SSC</b>	\$3,672.00	42.00 x 42.00 x 12.92 [1067 x 1067 x 328]	<b>NP4242C</b>	—	—
<b>N412D424812SSC</b>	\$3,984.00	42.00 x 48.00 x 12.92 [1067 x 1219 x 328]	<b>NP4842C</b>	—	—
<b>N412D426012SSC</b>	\$4,184.00	42.00 x 60.00 x 12.92 [1067 x 1524 x 328]	<b>NP6042C</b>	—	—
<b>N412D484812SSC</b>	\$3,799.00	48.00 x 48.00 x 12.92 [1219 x 1219 x 328]	<b>NP4848C</b>	—	—

Note: Subpanels must be ordered separately.  
Dimensions in inches [millimeters].  
Letters in table correspond to letters on dimensional drawings.

# Ultimate Series NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Two-Door Wall-Mount



## Dimensions

