

NEMA 4, 4X, 12, and 13 Painted Stainless Steel Single-Door Wall-Mount with 3-Point Handle



Applications

SSN43PTW Series provides unmatched protection for housing electrical components in highly corrosive environments.

These enclosures are used in indoor and outdoor settings that are frequently wet or have constant exposure to water, other liquids, or contaminants.

Construction

- Bodies and doors fabricated from 14-gauge type 304 stainless steel
- Continuously-welded seams ground smooth
- A rolled lip around three sides of door and all sides of enclosure opening provided to exclude liquids and contaminants
- Quick and easy-to-operate 3-point padlocking handle installed
- Pull hinge pin to remove doors
- Doors are sealed with poured-in-place polyurethane gasket
- Collar studs for mounting optional subpanels Removable print pocket is included
- External mounting feet provided for mounting enclosures
- Grounding provisions provided
- Uses WAL3_SS series handles

Finish

- Painted white polyester powder inside and out over phosphatized surfaces

Listings

- UL 508, 4, 4X, 12, and 13 [UL File E64791]
- NEMA/EEMAC 4, 4X, 12, and 13



Note: For current listings, please see www.automationdirect.com

Shipping Schedule

Same day 1 - 5 days 1 - 7 days 1-10 days 1 - 15 days 1 - 20 days

Color indicates shipping lead time in business days.

NEMA 4, 4X, 12, and 13 Painted Stainless Steel Single-Door Wall-Mount Enclosures with 3-Point Handle


Part Number	Price	Enclosure Size HxWxD	Painted Subpanel	304 Stainless Subpanel	Galvanized Subpanel	Perforated Subpanel
SSN42424083PTW	\$1,554.00	24.00 x 24.00 x 9.03 [610 x 610 x 229]	NP2424	NP2424SS	NP2424G	NP2424PP
SSN42424123PTW	\$1,557.00	24.00 x 24.00 x 13.03 [610 x 610 x 331]	NP2424	NP2424SS	NP2424G	NP2424PP
SSN43024083PTW	\$1,557.00	30.00 x 24.00 x 9.03 [762 x 610 x 229]	NP3024	NP3024SS	NP3024G	NP3024PP
SSN43630123PTW	\$2,508.00	36.00 x 30.00 x 13.03 [914 x 762 x 331]	NP3630	NP3630SS	NP3630G	NP3630PP
SSN43636123PTW	\$2,529.00	36.00 x 36.00 x 13.03 [914 x 914 x 331]	NP3636	NP3636SS	NP3636G	NP3636PP
SSN44236123PTW	\$2,806.00	42.00 x 36.00 x 13.03 [1067 x 914 x 331]	NP4236	NP4236SS	NP4236G	NP4236PP
SSN44836123PTW	\$3,498.00	48.00 x 36.00 x 13.03 [1219 x 914 x 331]	NP4836	NP4836SS	NP4836G	NP4836PP
SSN44836163PTW	\$3,867.00	48.00 x 36.00 x 17.03 [1219 x 914 x 433]	NP4836	NP4836SS	NP4836G	NP4836PP
SSN46036123PTW	\$4,128.00	60.00 x 36.00 x 13.03 [1524 x 914 x 331]	NP6036	NP6036SS	NP6036G	NP6036PP

Note: Dimensions in inches [millimeters].

NEMA 4, 4X, 12, and 13 Painted Stainless Steel Single-Door Wall-Mount with 3-Point Handle



Dimensions

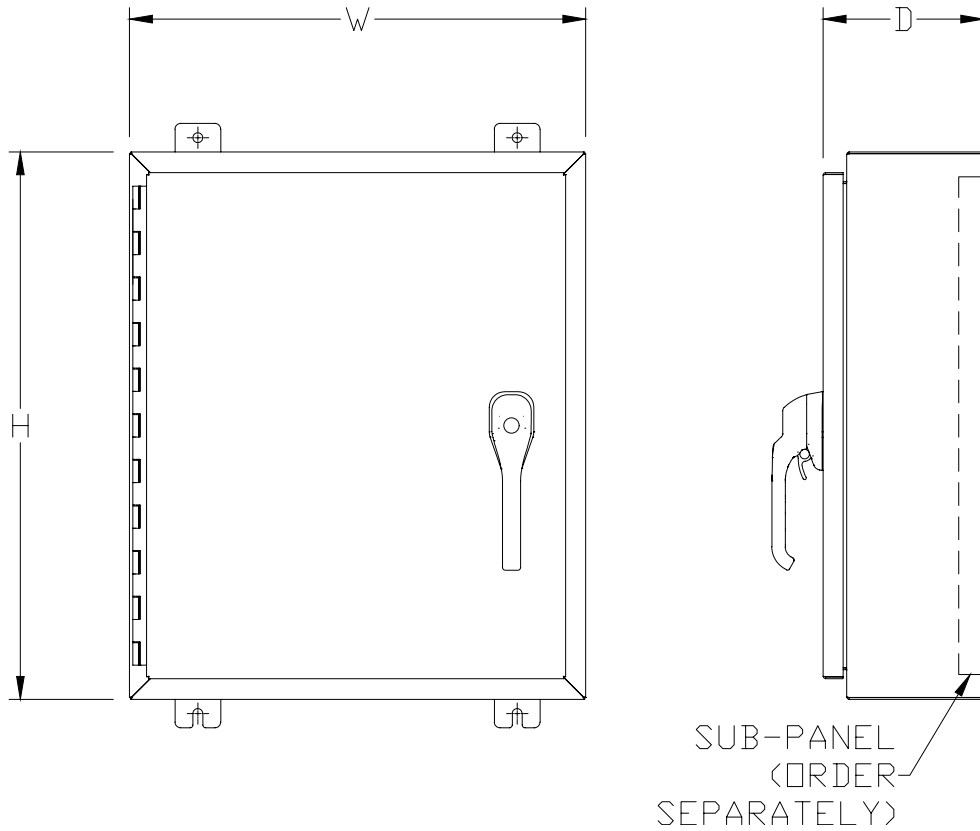

Enclosure Subpanels





Subpanels for Ultimate Series Wall-Mount Enclosures

- 12-gauge steel
- Subpanels with dimensions 30 x 30 in [762 x 762 mm] and larger are flanged on all sides. Smaller subpanels are flanged on two sides
- Painted steel subpanels are white polyester powder over phosphatized surfaces
- Galvanized subpanels have a conductive finish (no paint)
- Panels listed fit all styles of N412 Ultimate Series wall-mount enclosures, including slope top and disconnect enclosures

Note: NPxxxxC subpanels will not fit in older NEMA 4/12 enclosures (purchased prior to 3-23-05) that do not have a C suffix. For example: Subpanel NP1212C will not fit enclosures N412121206 or N412121206SS.



Dimensions

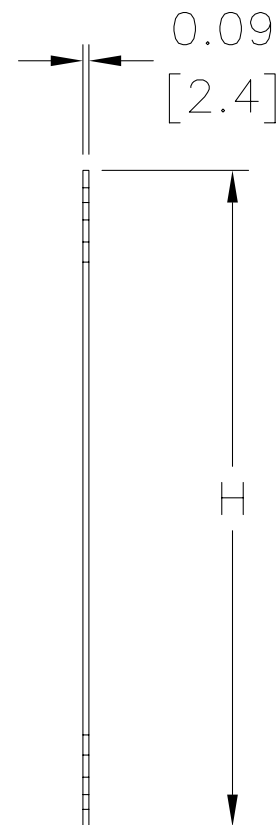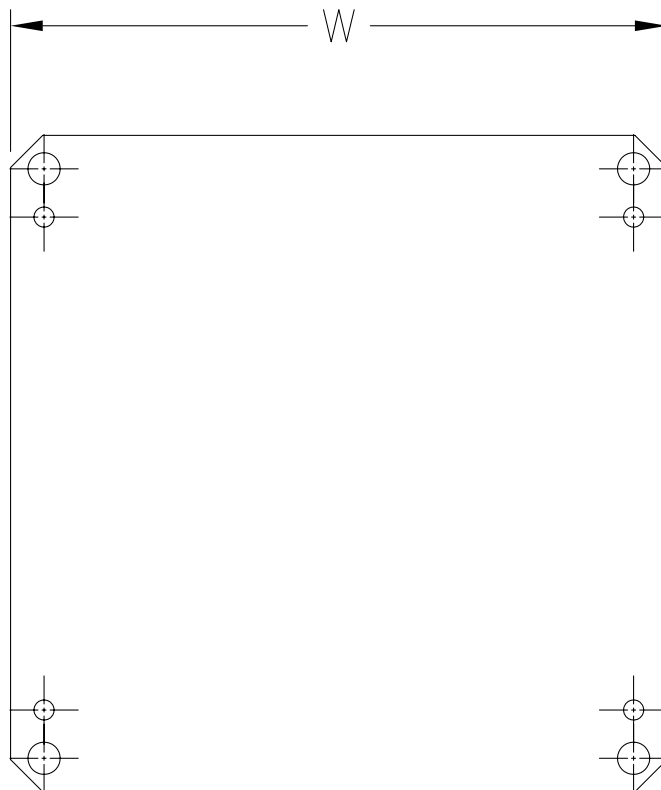

Enclosure Subpanels



Subpanels for Ultimate Series Wall-Mount Enclosures

Shipping Schedule

Same day 1 - 5 days 1 - 7 days 1 - 15 days 1 - 20 days

Color indicates shipping lead time in business days.

Subpanels for Ultimate Series Wall-Mount Enclosures

Painted Steel	Price	Galvanized	Price	304 Stainless Steel	Price	Nominal Enclosure Size HxW*	Subpanel Size HxW
NP1212C	\$15.50	NP1212CG	\$13.00	—	—	12 x 12	10.20 x 10.20 [259 x 259]
NP1612C	\$16.75	NP1612CG	\$16.75	NP1612SSC	\$87.00	16 x 12	14.20 x 10.20 [361 x 259]
NP1616C	\$40.50	NP1616CG	\$40.50	NP1616SSC	\$106.00	16 x 16	14.20 x 14.20 [361 x 361]
NP2016C	\$48.00	NP2016CG	\$48.00	NP2016SSC	\$128.00	16 x 20 20 x 16	18.20 x 14.20 [462 x 361]
NP2020C	\$58.00	NP2020CG	\$58.00	NP2020SSC	\$165.00	20 x 20	18.20 x 18.20 [462 x 462]
NP2416C	\$56.00	NP2416CG	\$56.00	NP2416SSC	\$159.00	24 x 16	22.20 x 14.20 [564 x 361]
NP2420C	\$56.00	NP2420CG	\$75.00	NP2420SSC	\$200.00	24 x 20	22.20 x 18.20 [564 x 462]
NP2424C	\$86.00	NP2424CG	\$86.00	NP2424SSC	\$233.00	24 x 24	22.20 x 22.20 [564 x 564]
NP3020C	\$90.00	NP3020CG	\$90.00	—	—	30 x 20	28.20 x 18.20 [716 x 462]
NP3024C	\$105.00	NP3024CG	\$90.00	NP3024SSC	\$306.00	30 x 24	28.20 x 22.20 [716 x 564]
NP3030C	\$147.00	NP3030CG	\$147.00	NP3030SSC	\$418.00	30 x 30	28.20 x 28.20 [716 x 716]
NP3624C	\$125.00	NP3624CG	\$125.00	NP3624SSC	\$357.00	24 x 36 36 x 24	34.20 x 22.20 [869 x 564]
NP3630C	\$167.00	NP3630CG	\$167.00	NP3630SSC	\$443.00	36 x 30	34.20 x 28.20 [869 x 716]
NP3636C	\$196.00	NP3636CG	\$196.00	NP3636SSC	\$535.00	36 x 36	34.20 x 34.20 [869 x 869]
NP4224C	\$244.00	—	—	—	—	24 x 42	40.20 x 22.20 [1021 x 564]
NP4024C	\$151.00	NP4024CG	\$151.00	—	—	40 x 24	38.20 x 22.20 [970 x 564]
NP4242C	\$418.00	—	—	—	—	42 x 42	40.20 x 40.20 [1021 x 1021]
NP4230C	\$225.00	—	—	—	—	30 x 42 42 x 32	40.20 x 28.20 [1021 x 716]
NP4236C	\$225.00	NP4236CG	\$225.00	NP4236SSC	\$676.00	36 x 42 42 x 36	40.20 x 34.20 [1021 x 869]
NP4824C	\$163.00	NP4824CG	\$163.00	—	—	24 x 48 48 x 24	46.20 x 22.20 [1173 x 564]
NP4830C	\$336.00	—	—	—	—	30 x 48	46.20 x 28.20 [1173 x 716]
NP4842C	\$562.00	—	—	—	—	42 x 48	46.20 x 40.20 [1173 x 1021]
NP4836C	\$254.00	NP4836CG	\$254.00	NP4836SSC	\$676.00	36 x 48 48 x 36	46.20 x 34.20 [1173 x 869]
NP4848C	\$625.00	—	—	—	—	48 x 48	46.20 x 46.20 [1173 x 1173]
NP6030C	\$446.00	—	—	—	—	30 x 60	58.20 x 28.20 [1478 x 716]
NP6036C	\$313.00	NP6036CG	\$313.00	NP6036SSC	\$965.00	36 x 30 60 x 36	58.20 x 34.20 [1478 x 869]
NP6042C	\$627.00	—	—	—	—	42 x 60	58.20 x 40.20 [1478 x 1021]

Notes: Dimensions in inches [millimeters].

Letters in table correspond to letters on dimensional drawing.

Disconnect enclosures will be up to 2 in [51 mm] wider than width dimensions in this table.