

MULTIPLEX™ SERIES ACTIVATION ACCESSORIES

Compatible with Walkerdut IPS, Pro Series and Flushduct

525 Series Service Fittings Ordering Information (continued)

LOCKING NIPPLES

 


1124-1

CAT. NO.	DESCRIPTION
1124-1	1" (25mm) IPS - 1" (25mm) long.
1124L-1	1" (25mm) IPS - 1 1/2" (38mm) long.
1124-1 1/4	1 1/4" (32mm) IPS - 1" (25mm) long.
1124L-1 1/4	1 1/4" (32mm) IPS - 1 1/2" (38mm) long.
1124-2	2" (51mm) IPS - 1" (25mm) long.
1124L-2	2" (51mm) IPS - 1 1/2" (38mm) long.


NOTE: IPS, Internal Pipe Size, is a trade size, not an actual size.

1124F -1 (25mm) Locking Nipple



For 1" (25mm) IPS opening; 5/8" (16mm) long. For use on Flushduct Infloor Raceway.

 455F-1 Outlet Flange



For 1 5/8" (241mm) diameter opening on Flushduct Infloor Raceway. Accepts 1" (25mm) locking nipple.

BLANKING PLATES



1043

NOTE: For IPS devices. 3 1/2" (89mm) diameter top plate.

CAT. NO.	DESCRIPTION
1043B, 1043S	Brass or stainless steel blanking plate with threaded base for 2" (51mm) IPS.
1043BPO, 1043SPO	Brass or stainless steel blanking plate only. Includes 1/4-20 screw.
1044B, 1044S	Brass or stainless steel blanking plate with threaded base for 3/4" (19.1mm) IPS.
1045B, 1045S	Brass or stainless steel blanking plate with threaded base for 1" (25mm) IPS.
1046B, 1046S	Brass or stainless steel blanking plate with threaded base for 1 1/4" (32mm) IPS.

B = Brass, S = Stainless Steel.


2" (51mm) IPS EXTENSIONS FOR AFTERSET INSERTS




424

NOTE: IPS, Internal Pipe Size, is a trade size, not an actual size.

CAT. NO.	DESCRIPTION
424-3/4	3/4" (19.1mm) 1 5/16" (33mm)
424-1	1" (25mm) 1 9/16" (40mm)

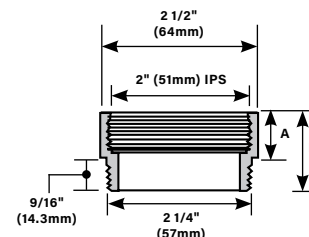


825SFCK Conversion Kit

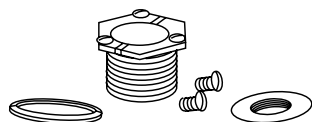


To attach service fitting to 800 Series floor boxes. Includes 825C Ring, 1124L-1 Locking Nipple, and 825P-1 Adapter.

431D505 Double Trim Plate

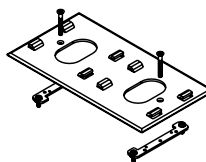


To attach two fittings to Walkerdut Pro Series Presets. Base of 525 fitting not needed.

430S505 Single Trim Plate

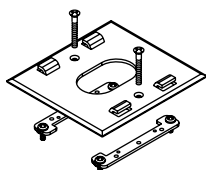

To attach fitting to Walkerdut Pro Series Preset. Base of 525 fitting not needed.

428B525 Flush Carpet Plate

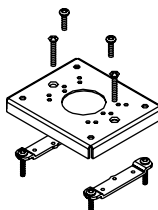

To attach to Walkerdut Pro Series Plate. Includes hardware.

MULTIPLEX™ SERIES ACTIVATION ACCESSORIES

Compatible with Walkerdut IPS, Pro Series and Flushduct



Multiplex Series Service Fittings are designed to be installed on the various types of infloor systems and can handle large capacity single and dual service power and/or communication requirements needed at the point-of-use.

CODE REFERENCE


cULus Listed Underfloor Raceway Fittings:

File E11912, Guide RQKX

Meets Article 390 of NEC

Multiplex Series Service Fittings Ordering Information


MP4 Single-Service Multiplex Service Fitting

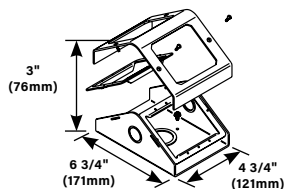

Single service fitting includes housing, base, two mounting frames, and mounting hardware. For use on 2" (51mm) IPS underfloor duct systems. Can also be installed on single preset in Walkerdut Pro Series System. Has 1/2" and 3/4" trade size concentric conduit knockouts on each end. Overall capacity is 55.3 cu. in. (906 cu cm). Fitting also provides 1" and 1 1/4" trade size concentric knockouts in baseplate.


trade size concentric conduit knockouts on each end. Overall capacity is 55.3 cu. in. (906 cu cm). Fitting also provides 1" and 1 1/4" trade size concentric knockouts in baseplate.

MP8-1 Dual-Service Multiplex Service Fitting

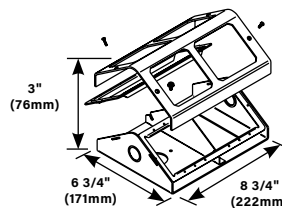

Same as MP8, except mounts on PK and N-R-G Presets, one No. 2, or one No. 4 duct. On Walkerdut Pro Series the fitting can be installed on any two-duct system. Overall capacity is 104.3 cu. in. (1709 cu cm). Has 1/2" and 3/4" trade size concentric knockouts on each end. Fitting also provides one 1" trade size knockout in baseplate.

MP8 Dual-service Multiplex Service Fitting

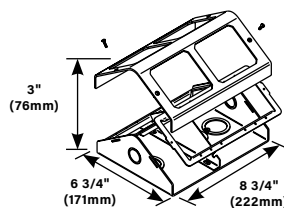


Dual service fitting includes housing, base, two mounting frames, divider, and mounting hardware. For use on two No. 2 ducts or one No. 2 and one No. 4 duct. On Walkerdut Pro Series the fitting can be installed on any two-duct system. Has 1/2" and 3/4" trade size concentric conduit knockouts on each end. Overall capacity is 104.3 cu. in. (1709 cu cm). Fitting also provides 1" and 1 1/4" trade size concentric knockouts and one 1" trade size knockout in baseplate.

and 3/4" trade size concentric conduit knockouts on each end. Overall capacity is 104.3 cu. in. (1709 cu cm). Fitting also provides 1" and 1 1/4" trade size concentric knockouts and one 1" trade size knockout in baseplate.


NOTE: Compatible with Walkerdut IPS and Pro Series duct.

 COLOR OPTIONS




Multiplex Series Service Fittings are available in a brushed aluminum finish unless otherwise indicated in the part number description.

 1124-1, 1124L-1, 1124F-1 (25mm) Locking Nipples



For 1" (25mm) IPS opening. 1124-1 is 1" (25mm) long. 1124L-1 is 1 1/2" (38mm) long. 1124F-1 is 5/8" (15.9mm) long and for use on Flushduct Infloor Raceway.

 1126A- Adapter



PART NUMBERS:

1126A-1/4 (6.4mm); **1126A-3/4** (19mm); **1126A-1** (25mm); **1126A-1 1/2** (38mm)

To change 2" (51mm) IPS preset to 1" (25mm). Suffix denotes opening size.

455F-1 Outlet Flange



For 1 5/8" (241mm) diameter opening on Flushduct Infloor Raceway. Accepts 1" (25mm) locking nipple. For use on Flushduct Infloor Raceway.