

UNIDUCT® 2800 SERIES RACEWAYS

Ordering Information


Uniduct® 2800 Series Raceway Wire Fill Capacities for Communications

	CABLE/WIRE SIZE	O.D. (Approx. Dia.)		40% FILL
		Inches	()	
UNSHIELDED TWISTED PAIR	4-pair, 24 AWG, Cat 3	0.190	(4.8)	4
	4-pair, 24 AWG, Cat 5e	0.210	(5.3)	3
	4-pair, 24 AWG, Cat 6	0.250	(6.3)	2
	4-pair, 24 AWG, Cat 6a*	0.354	(9.0)	1
	25-pair, 24 AWG	0.410	(10.4)	1
COAXIAL	RG6/U	0.270	(6.9)	2
FIBER	ZipCord	0.118 x 0.236	(3 x 6)	4
	Round 4 Strand Fiber	0.187	(4.8)	4
	Round 6 Strand Fiber	0.256	(6.5)	2

NOTE: For additional information, refer to the Technical Section.

* Category 6 augmented (6a) cable for 10 gigabit ethernet – max allowed cable diameter per addenda No. 11 ANSI TIA/EIA 568-B.2.

One-Piece Latching Raceway

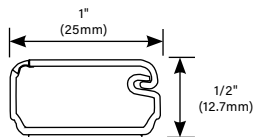


PART NUMBERS:

2800 (Ivory), **2800-WH** (White)
2800L8 (Ivory), **2800L8-WH** (White)
2800-FW (Fog White)
2800L8-FW (Fog White)


Co-extruded design, smooth ivory plastic finish with adhesive backing. 2800 available in 6' (1.8m) lengths, packed 120' (36.6m) per carton. 2800L8 available in 8' (2.44m) length, packed 160' (48.8m) per carton.

 PVC-1 PVC Raceway Cutter



Regular duty cutter. Ideal for use with small nonmetallic raceways.

Cover Clip

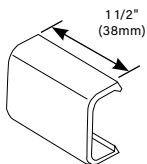


PART NUMBERS:

2806 (Ivory)
2806-WH (White)
2806-FW (Fog White)

Covers seam where two pieces of 2800 Series Raceway Cover come together.

Blank End Fitting

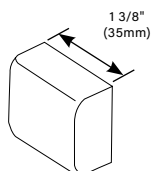


PART NUMBERS:

2810B (Ivory)
2810B-WH (White)
2810B-FW (Fog White)

Closes off end of 2800 Series Raceway.

NOTE: Device Boxes for Uniduct 2700 Series Raceway can be found on pages located at the end of this product section.

Flat Elbow

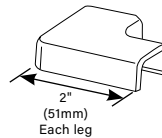


PART NUMBERS:

2811 (Ivory)
2811-WH (White)
2811-FW (Fog White)

Makes right angle turns in 2800 Series Raceway on same surface.

Radiused Flat Elbow

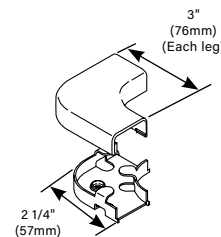


PART NUMBERS:

2811FO (Ivory)
2811FO-WH (White)
2811FO-FW (Fog White)

Makes right angle turns in 2800 Series Raceway on same surface. Maintains 1 1/4" (32mm) bend radius when installing UTP and fiber optic cable.

Tee

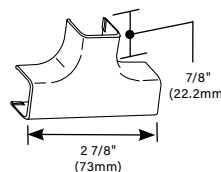


PART NUMBERS:

2815 (Ivory)
2815-WH (White)
2815-FW (Fog White)

For branching of 2800 Series Raceway running at right angles.

Radiused Tee

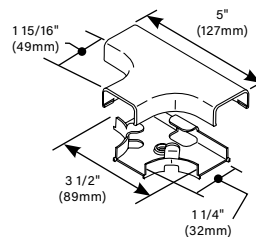


PART NUMBERS:

2815FO (Ivory)
2815FO-WH (White)
2815FO-FW (Fog White)

For branching of 2800 Series Raceway running at right angles. Maintains 1 1/4" (32mm) cable bend radius when installing UTP and fiber optic cable.

Internal Elbow

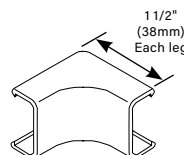


PART NUMBERS:

2817 (Ivory)
2817-WH (White)
2817-FW (Fog White)

For right angle turns around internal corners.

Radiused Internal Elbow

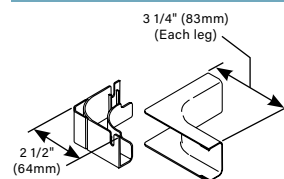

PART NUMBERS:

2817FO (Ivory)
2817FO-WH (White)
2817FO-FW (Fog White)

Makes right angle turns around internal corners of 2800 Series Raceway. Maintains 1 1/4" (32mm) bend radius when installing UTP and fiber optic cable.