

861 SERIES™ FLOOR BOXES


861 Series Floor Boxes Ordering Information

861 Wood Floor Box



Die-cast aluminum construction with three 1/2" (12.7mm) knockouts; two on the sides and one on the bottom. 18 cu. in. (295ml³) of capacity. Requires a 4" (102mm) diameter hole. Comes complete with a disposable cover, receptacle and cover sold separately.

Wood Floor Box Assembly

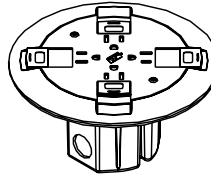


PART NUMBERS:

861QTCBK (Painted Black)
861QTCGY (Painted Gray)
861QTCBS (Brushed Brass)
861QTCAL (Brushed Aluminum)
861QTCAB (All Brass)
861QTCAA (All Aluminum)


Complete with prewired 15A quad receptacle can be wired as standard or isolated ground. Flush poke-thru-style cover is available in painted or brushed metal finishes. Slide covers match painted flange colors. Aluminum and brass covers shipped with black slide covers. Brass flange also available with nonmetallic brass-color (AB) slide holder. Die-cast aluminum construction with three 1/2" trade size knockouts: two on the sides and one on the bottom. 18 cu. in. (295 cu.cm) capacity. Requires a 4" (102mm) diameter hole and overall floor depth of 1" (25mm). Assembled with scrub water gasket. For use on tile, wood, or carpet floors.

861DB Wood Floor Box Assembly

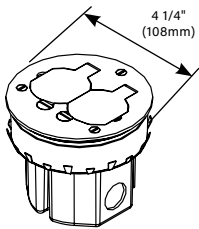

Complete with 20A duplex receptacle and brass cover plate. Die-cast aluminum construction with three 1/2" (12.7mm) knockouts; two on the sides and one on the bottom. 18 cu. in. (295ml³) of capacity. Requires a 4" (102mm) diameter hole.

Wood Floor Box Assembly

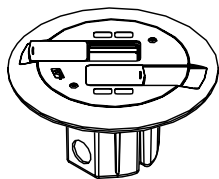


PART NUMBERS:

861AMDTCBK (Painted Black)
861AMDTCGY (Painted Gray)
861AMDTCBS (Brushed Brass)
861AMDTCAL (Brushed Aluminum)
861AMDTCAB (All brass)

All communication floor boxes accept up to four UTP connectors. Flush poke-thru-style flanges available in painted or brushed metal finishes. Slide covers match painted flange colors. Aluminum and brass flanges shipped with black slide cover. Brass flange also available with nonmetallic brass-color (AB) slide holder. Die-cast aluminum construction with three 1/2" trade size knockouts: two on the sides and one on the bottom. 18 cu. in. (295 cu.cm) capacity. Requires a 4" (102mm) diameter hole and overall floor depth of 1" (25mm). Includes two (2) Ortronics TracJack inserts, two (2) Ortronics Series II adapters and two Wiremold Open System adapters. Assembled with scrub water gasket. For use on tile, wood, or carpet floors. Modular jacks sold separately.

Furniture Feed Raised Floor Box Assembly

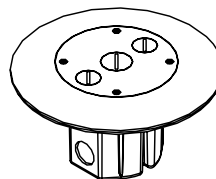

PART NUMBERS:

861FFTCBK (Painted Black)
861FFTCGY (Painted Gray)
861FFTCBS (Brushed Brass)
861FFTCAL (Brushed Aluminum)

Cover has two 1/2" trade size conduits and one 3/4" trade size threaded conduit opening for feeding cables and wires through floor. Flush flanges available in painted or brushed metal finishes. Die-cast aluminum construction with three 1/2" trade size knockouts; two on the sides and one on the bottom, 18 cu. in. (295 cu. cm) capacity. Requires a 4" (102mm) diameter hole.