

OMNIBOX™ SERIES FLOOR BOXES


Omnibox Series Cast Iron Floor Boxes Technical Specifications

CAT. NO.	CONDUIT OPENINGS	COMPARTMENT CAPACITY	ADJUSTMENT BEFORE POUR	ADJUSTMENT AFTER POUR
880CS1-1	(4)-1" (25mm)	48 cu. in. (787ml ³)	1 3/4" (44mm)	1/2" (12.7mm)
880CS2-1	(6)-1" (25mm)	94 cu. in. (1541ml ³) 45 cu. in. (738ml ³) 49 cu. in. (803ml ³)	1 3/4" (44mm)	1/2" (12.7mm)
880CS3-1	(8)-1" (25mm)	160 cu. in. (2622ml ³) 53 cu. in. (869ml ³) 54 cu. in. (885ml ³) 53 cu. in. (869ml ³)	1 3/4" (44mm)	1/2" (12.7mm)




Omnibox Series Cast Iron Floor Boxes Ordering Information

880CS1-1 One-Gang Cast-Iron Floor Box

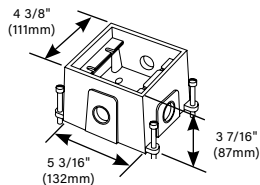


Fully adjustable.

Knockouts:

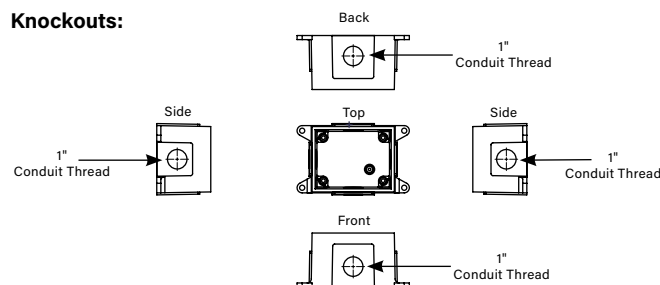


880CS2-1 Two-Gang Cast-Iron Floor Box

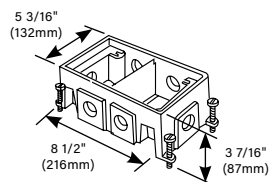


Fully adjustable.

Knockouts:

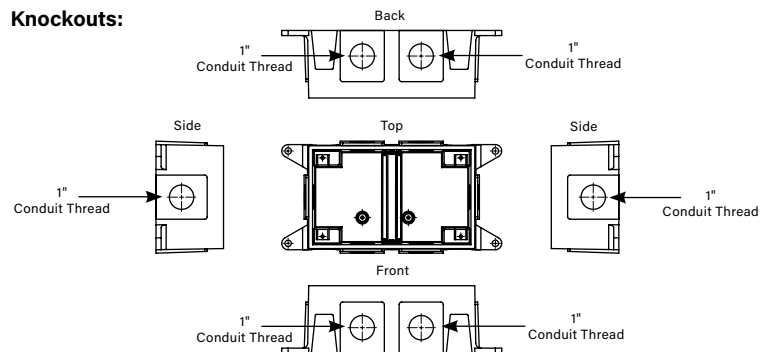

880CS3-1 Three-Gang Cast-Iron Floor Box

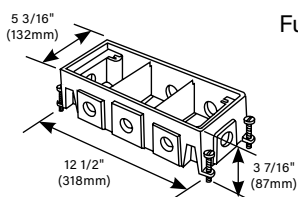

Fully adjustable.

Knockouts:

