


RC7 SERIES™ POKE-THRU DEVICES

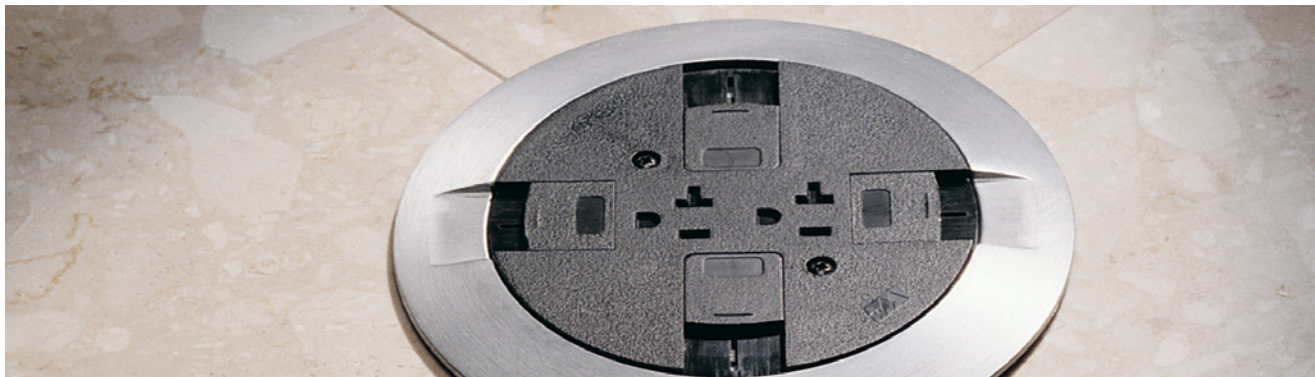

RC7 Series™ Surface Style Poke-Thru Devices provide one (1) 20A duplex power device and up to two (2) ports of communication.



Download this product's PEP ecopassport, environmental product declaration at www.legrand.us/resources-and-downloads. This declaration conforms with ISO 14025 and 14040 and is in alignment with EN 15804.

CODE REFERENCE

cULus Listed Metallic Outlet Boxes:
File E2961 Guide QCIT.

cULus Listed Nonmetallic Outlet Boxes & Fittings Classified for Fire Resistance:
File R8209 Guide CEYY.

Meets Article 300.21, 300.22(C) & 314 of NEC.




RC7 Series Poke-Thru Device.

HOLE DIAMETER

Minimum:	3 1/16" (78mm)
Maximum:	3 1/8" (79mm)


RC7 Series Poke-Thru Devices
Ordering Information

RC7STC Insert Assembly with Disposable Plate

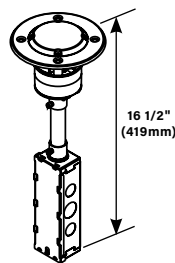

Complete with one piece disposable cover to protect the device during the construction process. Unit comes with a 3/4" conduit feed, junction box for power and two 1/2" openings for low voltage pass through. Use with the RC7CTC and RC7CFFTC covers.

Finished Flange & Slide Holder Assembly

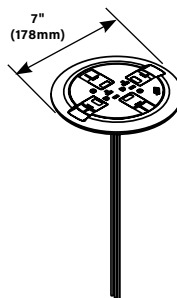

PART NUMBERS:

RC7CTCAA (All Aluminum)
RC7CTCAB (All Brass)
RC7CTCGY (Gray)
RC7CTCBK (Black)
RC7CTCAL (Aluminum)
RC7CTCBS (Brass)

Prewired TR 20A duplex receptacle can be wired as standard duplex or isolated ground. Aluminum and brass flanges shipped with black slide cover. Includes Wiremold Open System unloaded inserts.

NOTE: Includes two Cat 6 TechChoice discrete keystone connectors, two Ortronics TracJack adapters and two Wiremold Open System adapters.

COLOR OPTIONS



RC7 Series parts are available in gray "GY", black "BK", brushed aluminum "AL", brass "BS", brass-colored finish "AB" and an aluminum-colored finish "AA".

Custom color options are also available. Consult the factory for more information.