 


WORKSTATION POWER SOLUTIONS

Ordering Information

Work Station Power Solutions - Power Only Plug-In Outlet Center Units Ordering Information

Plug-In Outlet Center Unit



PART NUMBERS:

V20-C2 (6 Foot Cord)

G20-C2 (15 Foot Cord)


Six outlets, steel housing with ivory (V20-C2) or gray finish (G20-C2). 6' (1.8m) cord. Length 40" (1m). Receptacle center-to-center 6" (152mm).

NM20-C3 Plug-In Outlet Center Units



Six (3 duplex) outlets, nonmetallic housing with ivory finish. 6' (1.8m) cord, Length 36" (915mm). Receptacle center-to-center 12" (305mm).

 NM20-C4 Plug-In Outlet Center Units



Eight (4 duplex) outlets, nonmetallic housing with ivory finish. 6' (1.8m) cord. Length 48" (1.2m). Receptacle center-to-center 12" (305mm).

NM20-C5 Plug-In Outlet Center Units




Ten (5 duplex) outlets, nonmetallic housing with ivory finish. 6' (1.8m) cord, Length 60" (1.5m). Receptacle center-to-center 12" (305mm).

NM20-C6 Plug-In Outlet Center Units



Twelve (6 duplex) outlets, nonmetallic housing with ivory finish. 6' (1.8m) cord. Length 72" (1.8m). Receptacle center-to-center 12" (305mm).

Plug-In Outlet Center Units

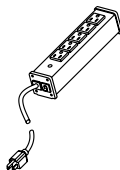


PART NUMBERS:

UL100BC (6 Foot Cord)

UL100BD (15 Foot Cord)

Five outlets, rugged gray aluminum housing, 15A. 6' (1.8m) (UL100BC) or 15' (4.6m) (UL100BD) 14/3 SJT black cord with NEMA5-15 plug. Length 9 1/4" (235mm). Receptacle center-to-center 1 1/4" (32mm). Snap-on, slide-off mounting.

Plug-In Outlet Center Units

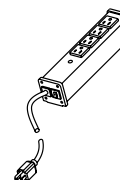


PART NUMBERS:

UL101BC (6 Foot Cord)

UL101BD (15 Foot Cord)

Four outlets, rugged gray aluminum housing, 15A. 6' (1.8m) (UL101BC) or 15' (4.6m) (UL101BD) 14/3 SJT black cord with NEMA5-15 plug. Length 9 1/4" (235mm). Receptacle center-to-center 1 1/4" (32mm). Snap-on, slide-off mounting.

Plug-In Outlet Center Units

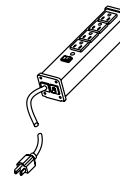


PART NUMBERS:

UL104BC (6 Foot Cord)

UL104BD (15 Foot Cord)

Four outlets, rugged gray aluminum housing, 15A, lighted switch. 6' (1.8m) (UL104BC) or 15' (4.6m) (UL104BD) 14/3 SJT black cord with NEMA5-15 plug. Length 9 1/4" (235mm). Receptacle center-to-center 1 1/4" (32mm). Snap-on, slide-off mounting.

Plug-In Outlet Center Units

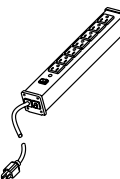

PART NUMBERS:

UL204BC (6 Foot Cord)

UL204BD (15 Foot Cord)

Seven outlets, rugged gray aluminum housing, 15A, lighted switch. 6' (1.8m) (UL204BC) or 15' (4.6m) (UL204BD) 14/3 SJT black cord with NEMA5-15 plug. Length 13" (330mm). Receptacle center-to-center 1 1/4" (32mm). Snap-on, slide-off mounting.