

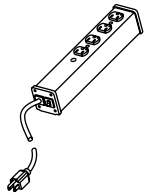
MEDICAL GRADE/SPECIAL USE POWER SOLUTIONS

Ordering Information

Special Use/Medical Grade Power Solutions – Power Only Plug-In Outlet Center Units

Ordering Information

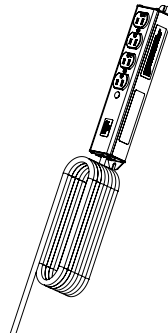
Plug-In Outlet Center Units


PART NUMBERS:

ULBH4-6 (6 Foot Cord)
ULBH4-15 (15 Foot Cord)

Four outlets. Rugged white aluminum housing. 6' (1.8m) (ULBH4-6) or 15' (4.6m) (ULBH4-15) 14/3 SJT white cord with NEMA5-15 plug. Length 10 3/4" (237mm). Receptacle center-to-center 1 1/2" (38mm). Snap-on, slide-off mounting. Not for use in critical care environments. Not for use where Article 517 of NEC requires Hospital Grade Outlets.

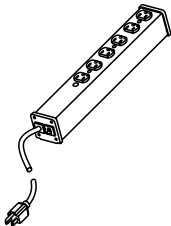
Plug-In Outlet Center Units


PART NUMBERS:

ULM4-6 (6 Foot Cord)
ULM4-15 (15 Foot Cord)

Four outlets. Rugged white aluminum housing. 6' (1.8m) (ULMH4-6) or 15' (4.6m) (ULMH4-15) 14/3 SJT white cord with NEMA5-15 plug. Length 10 3/4" (237mm). Receptacle center-to-center 1 1/2" (38mm). Snap-on, slide-off mounting. cTUVus Listed as Medical Electrical Equipment. **Suitable for use where Article 517 of NEC requires Hospital Grade Outlets.**

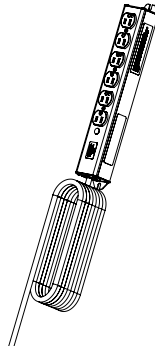
Plug-In Outlet Center Units


PART NUMBERS:

ULBH6-6 (6 Foot Cord)
ULBH6-15 (15 Foot Cord)

Six outlets. Rugged white aluminum housing. 6' (1.8m) (ULBH6-6) or 15' (4.6m) (ULBH6-15) 14/3 SJT white cord with NEMA5-15 plug. Length 13 1/4" (337mm). Receptacle center-to-center 1 1/2" (38mm). Snap-on, slide-off mounting. Not for use in critical care environments. Not for use where Article 517 of NEC requires Hospital Grade Outlets.

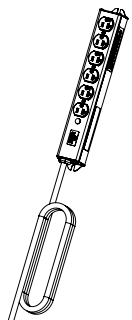
Plug-In Outlet Center Units


PART NUMBERS:

ULM6-6 (6 Foot Cord)
ULM6-15 (15 Foot Cord)

Six outlets. Rugged white aluminum housing. 6' (1.8m) (ULMH6-6) or 15' (4.6m) (ULMH6-15) 14/3 SJT white cord with NEMA5-15 plug. Length 13 1/4" (337mm). Receptacle center-to-center 1 1/2" (38mm). Snap-on, slide-off mounting. cTUVus Listed as Medical Electrical Equipment. **Suitable for use where Article 517 of NEC requires Hospital Grade Outlets.**

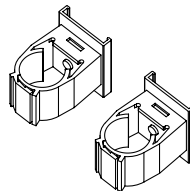
Plug-In Outlet Center Units


PART NUMBERS:

ULM620-6 (6 Foot Cord)
ULM620-15 (15 Foot Cord)

20A configuration. Four outlets, white finish. 6' (1.8m) (ULM620-6) or 15' (4.6m) (ULM620-15) cord. Length 10 3/4" (237mm). Receptacle center-to-center 1 1/2" (38mm). cTUVus Listed as Medical Electrical Equipment. **Suitable for use where Article 517 of the NEC requires Hospital Grade Outlets.**

IVPM-100 – IV Pole Mounting Clips



Easy-on, easy-off mounting clips to attach plug-in outlet center unit to 1" (25mm) diameter IV pole. Includes two (2) clips.

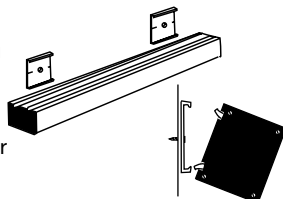
Mounting Information

MOUNTING TYPES

Each Plug-In Outlet Center unit has one of three different mounting types. Each mounting method has been designed to optimize the performance of the product. Complete mounting hardware and installation instructions are included with every unit.

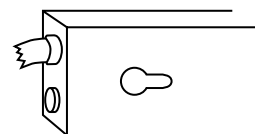
Snap-On/Slide-Off

Mount unit in any position. Catalog No. 8004 includes two aluminum mounting clips that snap onto mounting rails on the back of the unit. Screws also included. Used for all units with 2" (51mm) aluminum housing.



Keyhole Mounting

Mount unit in almost any position. Screws not included. Available on all plastic units and units with 3 1/2" (89mm) aluminum housing.



Spring Clip Mounting

Mount unit in any position. Catalog No. 8002 includes two spring steel mounting clips that snap onto the unit. Screws also included. Used for all units with 1 1/2" (38mm) narrow aluminum housing.

