


PLUGMOLD® 2000 SERIES™

Plugmold 2000 Series Ordering Information


Base and Cover

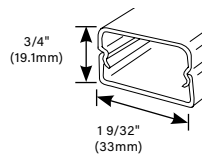

PART NUMBERS:
V2000BC (Ivory)
WH2000BC (White)
G2000BC (Gray)
BK2000BC (Black)
S2000BC (Stainless Steel)

2000B Base: .040" (1.0mm) steel; 2000C Cover: .025" (.6mm) steel. Packed ten 5' (1.5m) lengths of each per carton.


Raceway Base

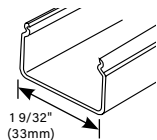

PART NUMBERS:
V2000B-5 (Ivory)
WH2000B-5 (White)
G2000B-5 (Gray)

.040" (1.0mm) steel. Packed twenty 5' (1.5m) lengths per carton.


Raceway Base

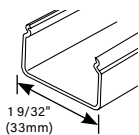

PART NUMBERS:
V2000B-10 (Ivory)
WH2000B-10 (White)

.040" (1.0mm) steel. Packed ten 10' (3.05m) lengths per carton.


Raceway Cover

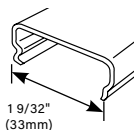

PART NUMBERS:
V2000C (Ivory)
WH2000C (White)
G2000C (Gray)

.025" (.6mm) steel. Packed twenty 5' (1.5m) lengths per carton. Has no receptacle hole cuts.

620 Raceway Base and Cover Cutter

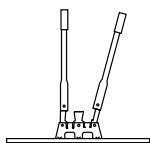


Portable cutter for both 2000 Base and Cover.

620BCK Replacement Blade Kit

Replacement blades and die set for 620 Cutter.


Pressure-Type Wire Connectors

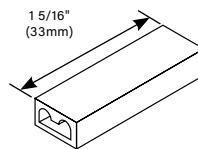

W30/W30G – This part comes with both 16-W30 and 8-W30G. W30 – For common connection of two, three, or four No. 12 or No.14 solid copper conductors. W30G – For connection of equipment grounding of two, three, or four No.12 or No. 14 AWG solid conductors. 300V maximum; 20A 105° C maximum.


NOTE: Not for use with aluminum conductors.

 2000WC Wire Clip (Plated)




Use when conductors bypass receptacles. Not UL Listed.

2001 Coupling (Galvanized Steel)

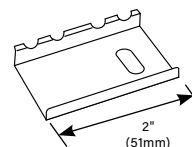


Joins lengths of 2000 Series Raceway Base.

2003 Supporting Clip

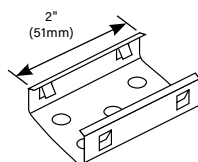


PART NUMBERS:
V2003 (Ivory)
2003 (Plated Finish)

Temporary support, while positioning lengths of raceway base. Use with 2000 Series Raceway.

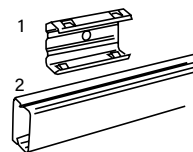

1. 2003 mounted on surface with No. 6 flathead screw.
2. Plugmold 2000 snaps into 2003 Supporting Clip.

2006 Cover Clip

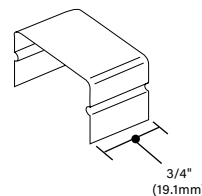

PART NUMBERS:
V2006 (Ivory)
WH2006 (White)
G2006 (Gray)
BK2006 (Black)
S2006 (Stainless Steel)

Covers seam where lengths of cover or base meet.