

#### ARCHITECTURAL & ENGINEERING SPECIFICATION

Complete EcoVantage® high efficiency 0.5 gpf manual actuated, wall mounted commercial urinal system with Z5755-U Omni-Flo top spud urinal, Z6003AV-EWS exposed, manually activated chrome-plated urinal flushometer for either left or right hand supply manufactured by Zurn.

#### PRODUCT FEATURES

- 0.5 gpf (gallons per flush)
- Wall mounted extended rim top spud urinal
- High efficiency siphon washout flush action
- Integral trap
- Vitreous china wall urinal construction
- Diaphragm- type flushometer complete with Zurn's Go Blue® TPE, chloramine resistant, dual seal diaphragm with a clog resistant filtered bypass
- ADA compliant, non-hold open, dual seal handle
- High pressure vacuum breaker
- Adjustable tailpiece
- Control stop with internal siphon guard protection, vandal resistant cap, sweat solder kit and cast wall flange with set screw
- Asymmetric backwall for reduced splash back
- Oversized footprint to make retrofit easy
- Vandal resistant outlet strainer included
- 50% water savings over standard 1.0 gpf system

#### COMPLIANCE AND CERTIFICATION:

Meets the American Disabilities Guidelines and ANSI A117.1 requirements when installed according to these requirements.

- Fixture - Complies with ASME A112.19.2 / CSA B45.1
- Flush Valve - Complies with ASSE 1037 / ASME A112.1037 / CSA B125.37



This product should be used with a WaterSense labeled counterpart with a compatible flush volume to ensure that the entire system meets the requirements for water efficiency and performance.



#### ZURN ONE SYSTEM PACKOUT INCLUDES:

##### FIXTURE - Z5755-U:

0.125 gpf [0.5 lpf] to 1.0 gpf [3.8 lpf] vitreous china, wall hung, integral trap, washdown urinal complete with 3/4" [19mm] top spud connection, concealed universal retrofit wall bracket, 2" [51mm] outlet connection and vandal resistant outlet strainer



##### FLUSH VALVE - Z6003AV-EWS:

Exposed, quiet diaphragm-type, chrome-plated flushometer valve with a polished exterior. Complete with Zurn's AquaVantage® TPE, chloramine resistant, dual seal diaphragm with a clog resistant, filtered bypass. The valve is ADA compliant with a non-hold open and no leak handle feature. Internal seals are made of chloramine resistant materials



The information contained in this document is subject to change without notice. Please contact Zurn for most up to date information.

Rough-in / Overview dimensions

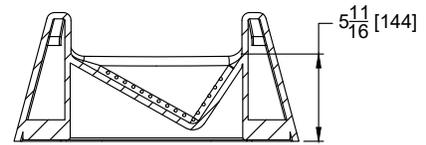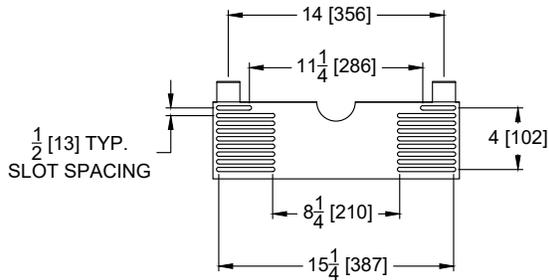

SECTION A-A

UNIVERSAL RETROFIT  
 BRACKET (UB)  
 Model 829800014

